 


 


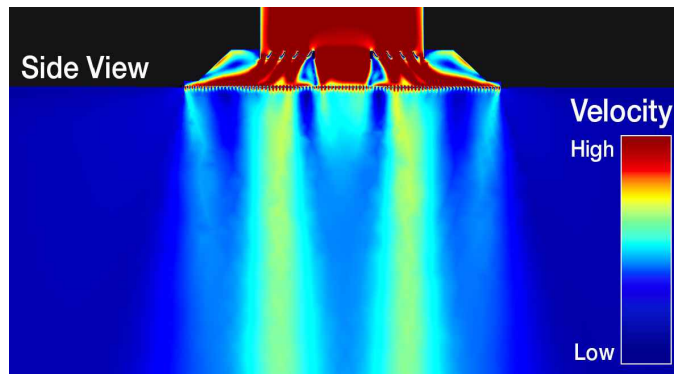










**Product Features:**

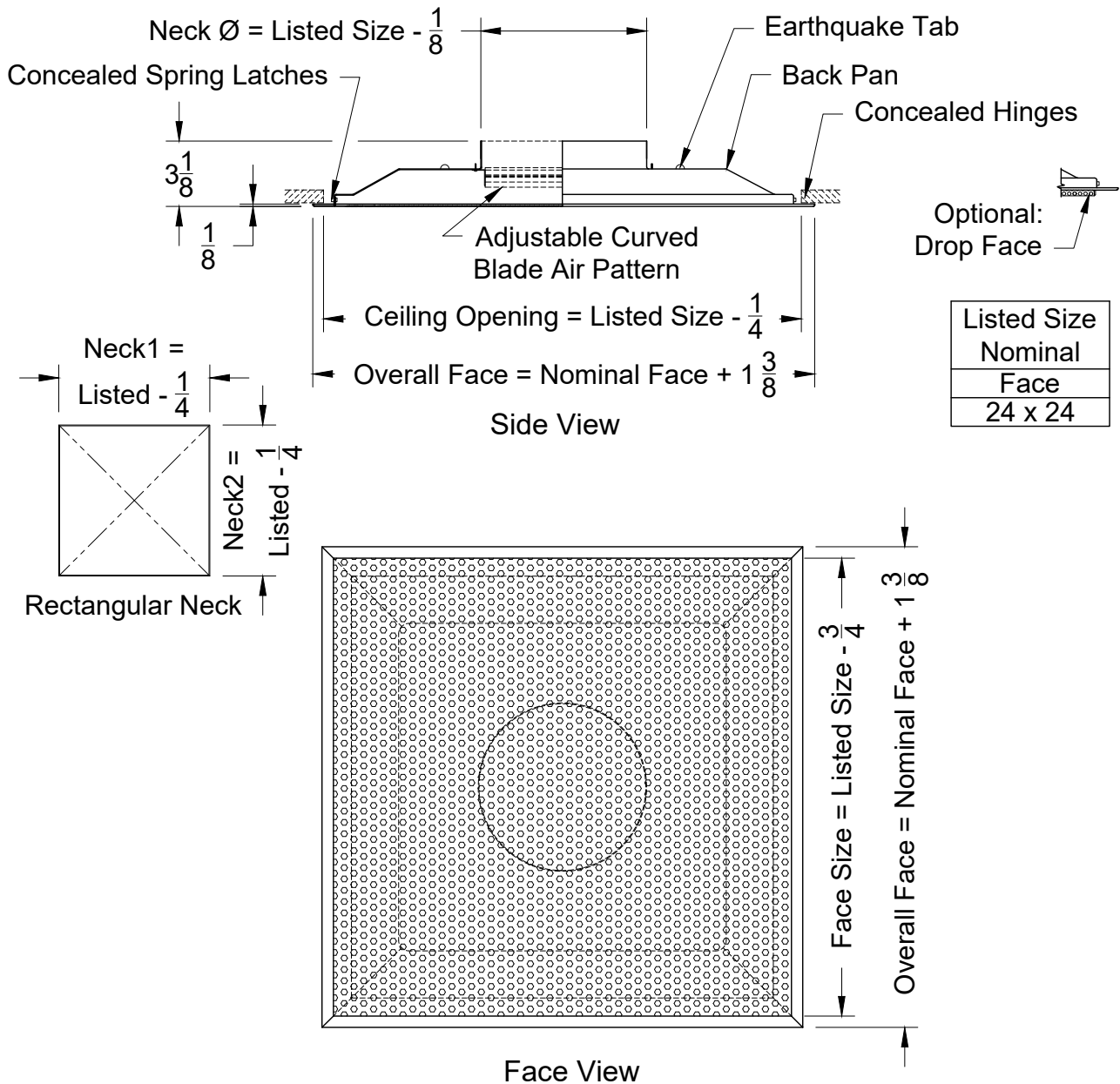
- Perforated diffusers provide a smooth continuous ceiling aesthetic
- Neck mounted pattern deflectors enable optimal mixing
- Deflectors allow for adjustable airflow patterns
- Utilizes a hinged and fully removable face panel for easy cleaning
- Available in steel, aluminum, aluminum face and drop face applications
- Available with round or square neck inlets
- Multiple border styles available for various ceiling applications
- Face panel uses 51% free area perforated metal

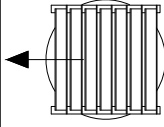
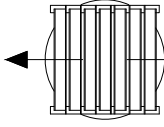
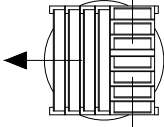
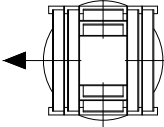
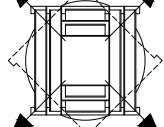
**Finishes**

01 - White <sup>1</sup>	03 - Black	<sup>1</sup> White Finish is suitable for a primer coat if field painting is required.
		
02 - Satin Silver	24 - Mill	
		
28 - Custom Color	22 - BBP	Black Back Pan White Face
		

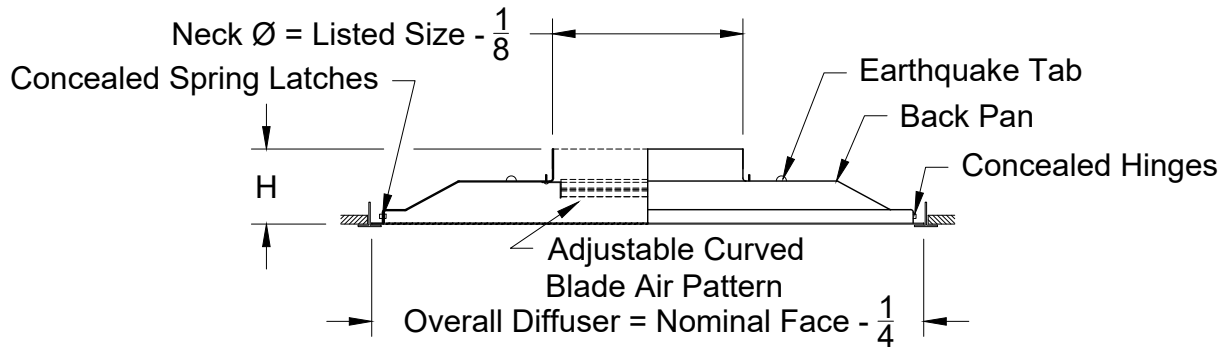
**CFD Throw Pattern Visualization**

**Optional Accessories:**

	Opposed Blade Damper D7 - Steel D7A - Aluminum
	TBPF - T-Bar Plaster Frame
	2"BC - 2" Beaded Inlet Collar
	BDS - Butterfly Damper
	L9 - Equalizing Grid (Square / Rect)
	G3 - Equalizing Grid (Round)
	RSD - Radial Shutter Damper
	EQS - Earthquake Straps
	FGBP - Fiberglass Backpan

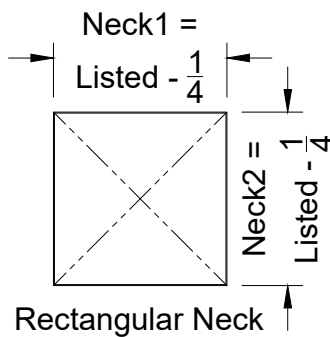


Air Pattern Options				Option:
1 Way	2 Way	3 Way	4 Way	Star Air Pattern
				

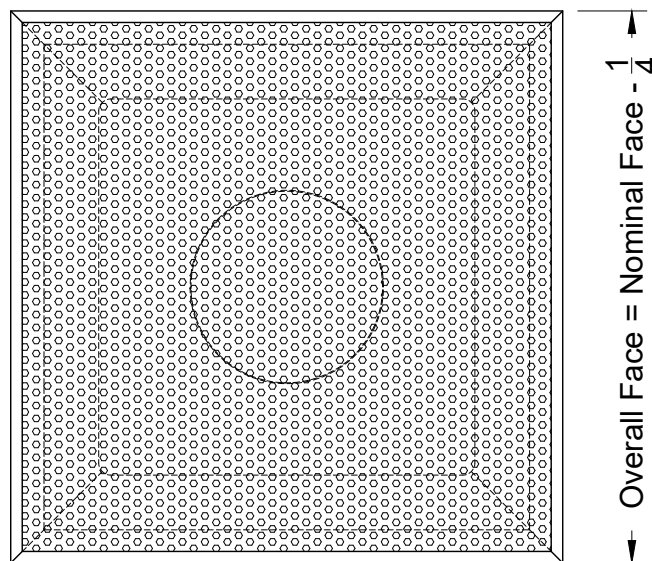
Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.



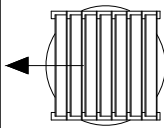
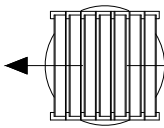
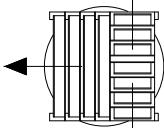
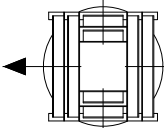
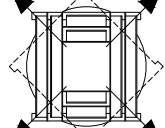
Side View



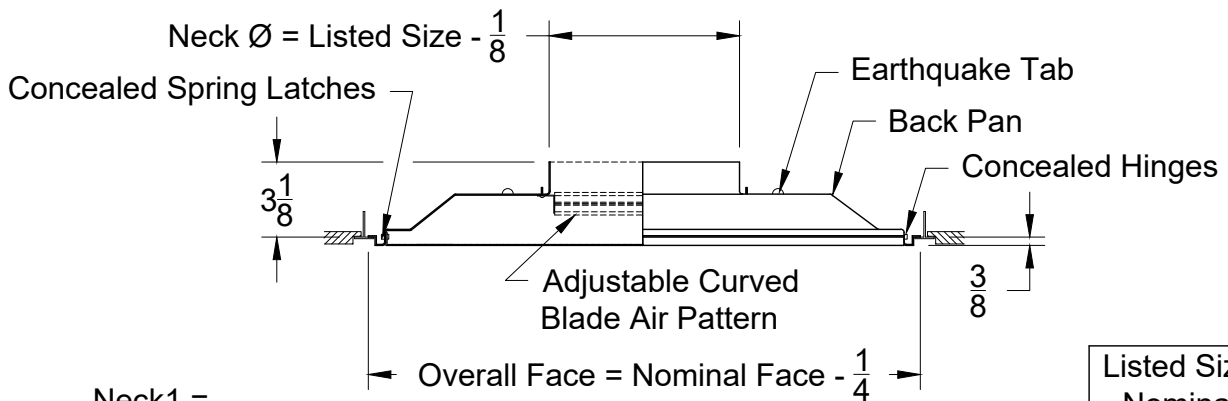
Listed Size Nominal Face	Height H	Neck Sizes
12 x 12	4 1/4	6 & 8
16 x 16	4 1/4	6 & 8
18 x 18	4 1/4	6, 8 & 10
20 x 20	4 1/4	6, 8 & 10
24 x 24	3 1/8	6 to 16



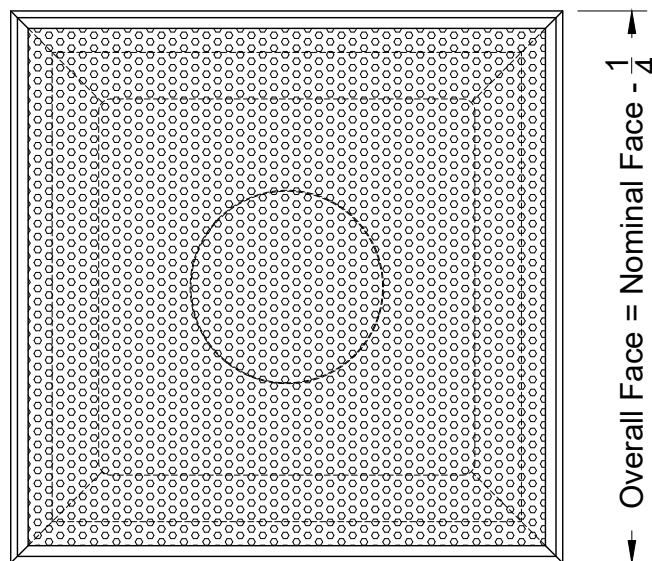
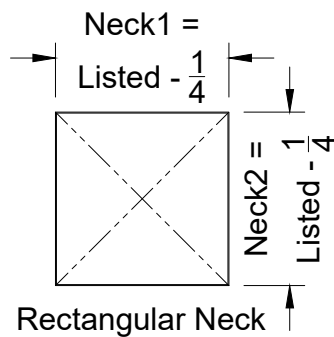
Face View

Air Pattern Options				Option: Star Air Pattern
1 Way	2 Way	3 Way	4 Way	
				

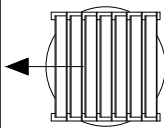
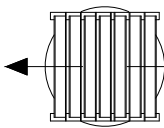
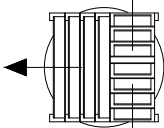
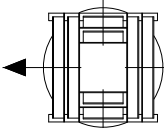
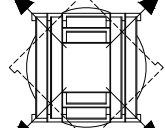
Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.



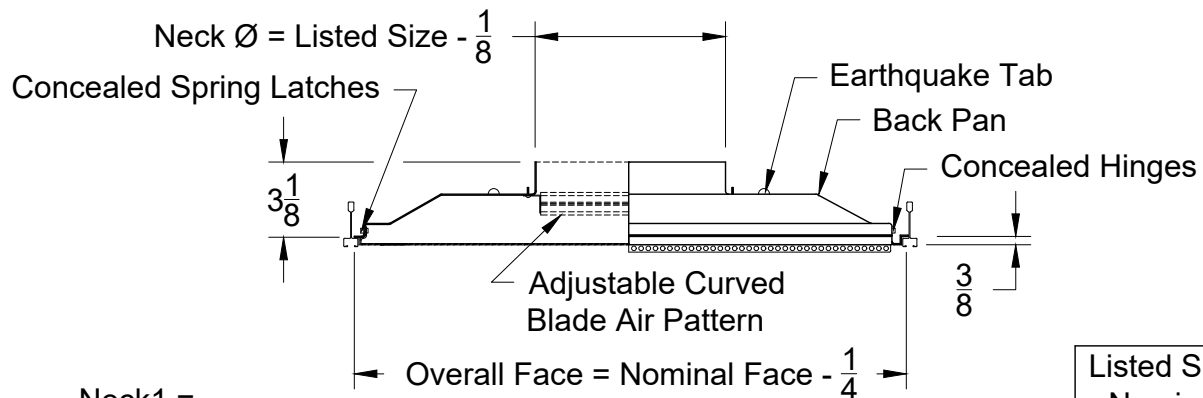
Listed Size
Nominal
Face
24 x 24



Face View

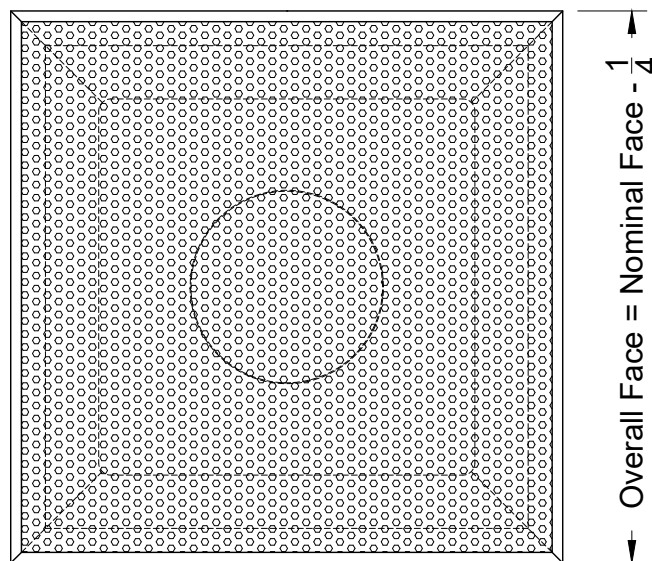
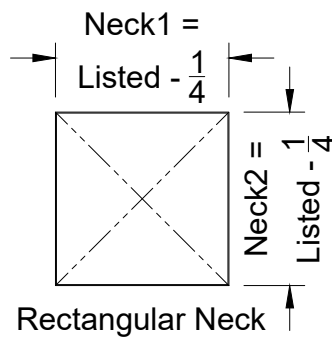
Air Pattern Options				Option:
1 Way	2 Way	3 Way	4 Way	Star Air Pattern
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

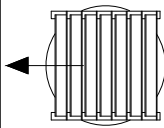
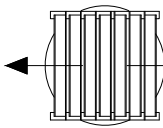
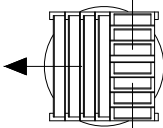
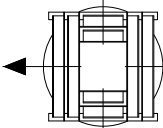
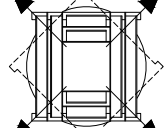


Side View

Listed Size
Nominal
Face
24 x 24



Face View

Air Pattern Options				Option:
1 Way	2 Way	3 Way	4 Way	Star Air Pattern
				

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.