 
**Product Features:**

- Perforated lay-in panels provide a smooth architectural ceiling
- Available in steel or aluminum
- 51% free area
- Good performance at lower return velocities
- Can be selected to fit any T-bar grid size
- Useful in non-ducted return applications

Finishes01 - White¹


03 - Black



¹ White Finish is suitable for a primer coat if field painting is required.


28 - Custom Color

**Optional Accessories:**

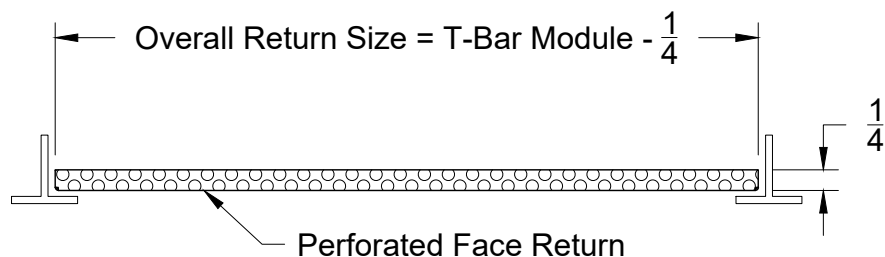

Side View



Listed Size
Nominal
Face
12 x 12
24 x 12
24 x 24
36 x 24
48 x 12
48 x 24

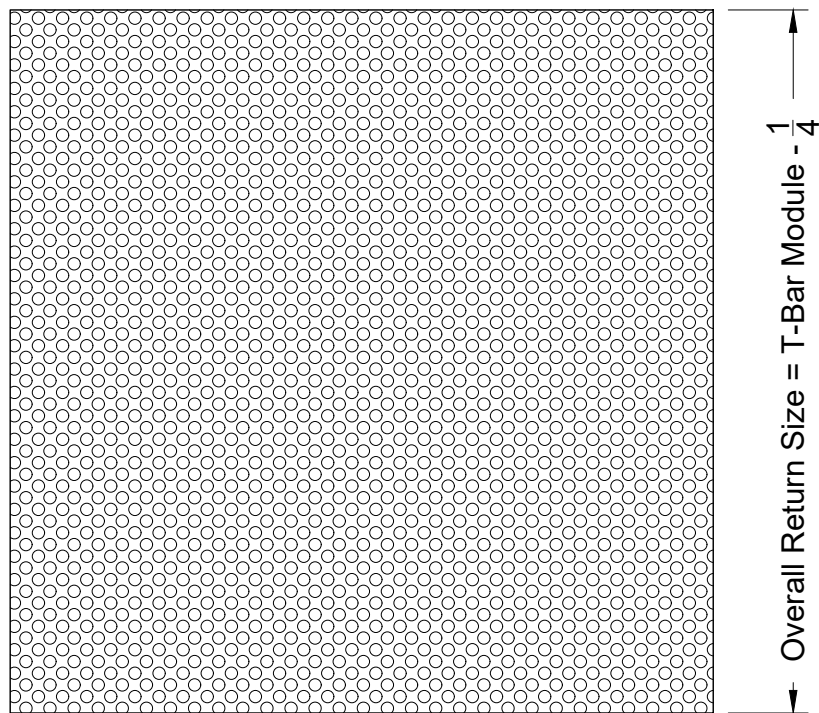

Face View

Perforated Face Return 3/16 Diameter Holes on 1/4 Staggered Centers


Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

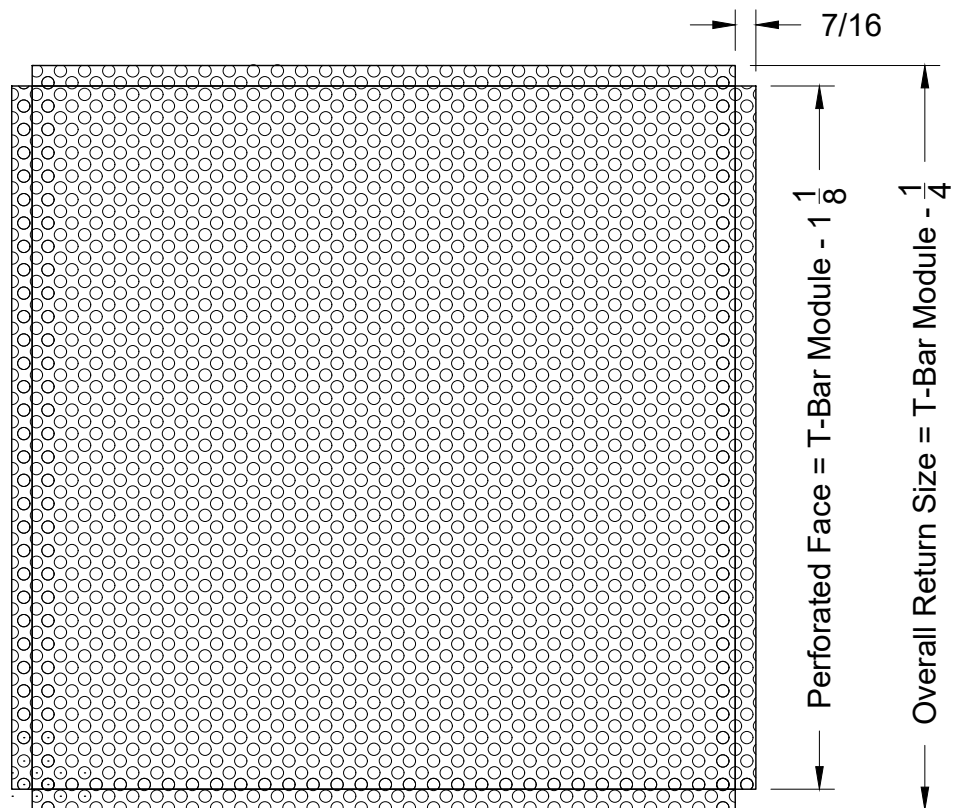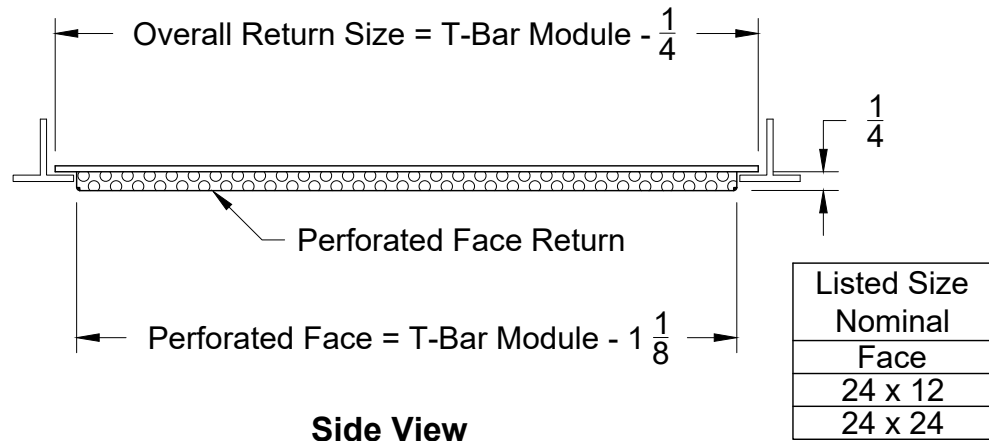


Face View

Perforated Face Return $\frac{3}{16}$ Diameter Holes on $\frac{1}{4}$ Staggered Centers

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a $\frac{1}{2}$ " sphere can not pass.

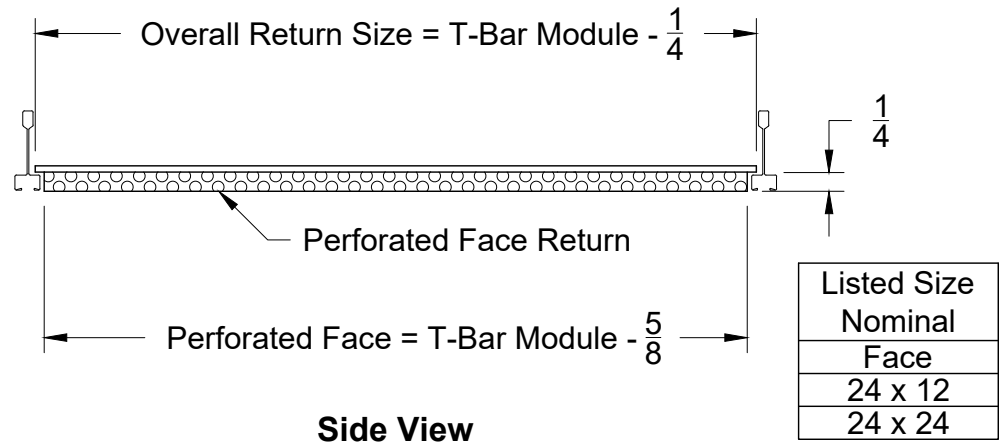

Side View

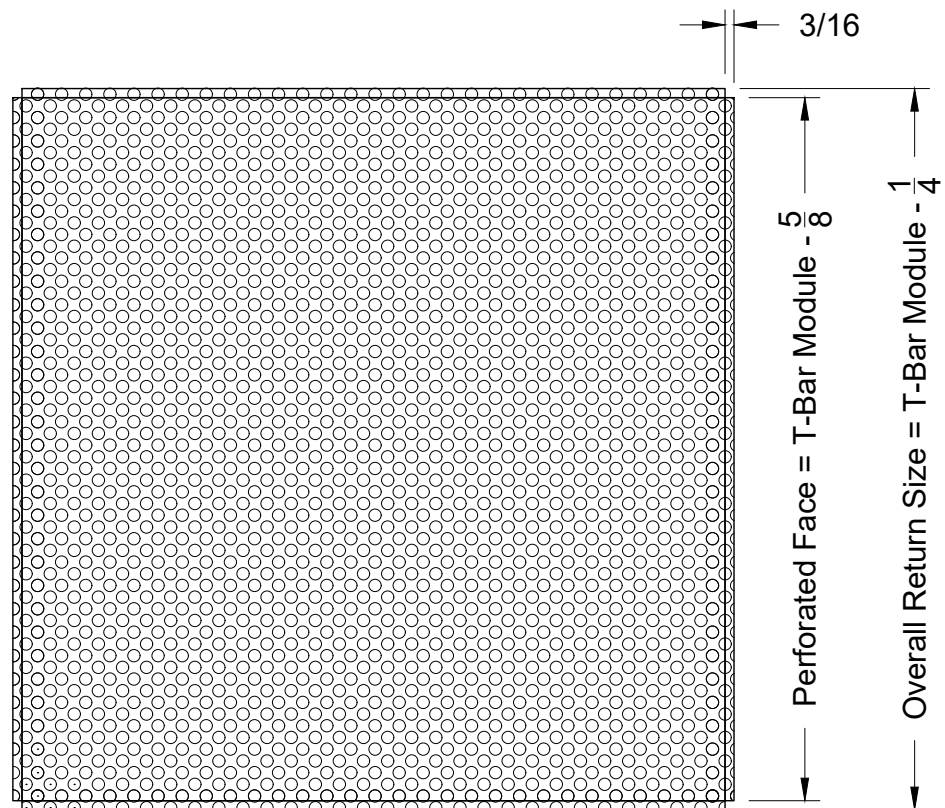

Face View

Perforated Face Return $\frac{3}{16}$ Diameter Holes on $\frac{1}{4}$ Staggered Centers

Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a $\frac{1}{2}$ " sphere can not pass.