



0 deg Blades



 
38 deg Blades

Product Features:

- Steel construction (HDRG41-S)
- Fixed 0° or 38° blade deflection
- Oversized units made in multiple sections with mullion strips
- Aluminum construction (HDRG41-AL)
- Largest single section size is 48x48"
- Built to withstand impacts and moderate abuse in high traffic areas
- Available in surface mount borders

Finishes

01 - White¹



03 - Black

 


¹ White Finish is suitable for a primer coat if field painting is required.

02 - Satin Silver




24 - Mill



28 - Custom Color



Product Pressure Drop Performance

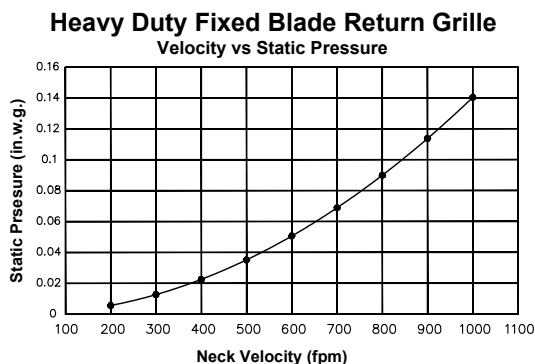

Optional Accessories:



 
OBD - Steel Opposed Blade Damper



OBDE - Extruded Aluminum Opposed Blade Damper




OBDA - Aluminum Opposed Blade Damper




L9 - Equalizing Grid (Square / Rect)



 PF - Sidewall Plaster Frame





TR - Square to Round Transition

 



TR-Deep - Deep Transition



FGBP - Fiberglass Backpan

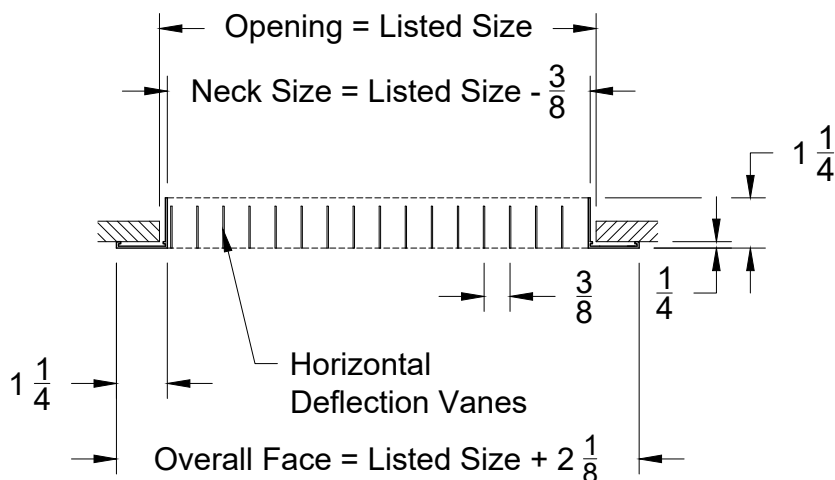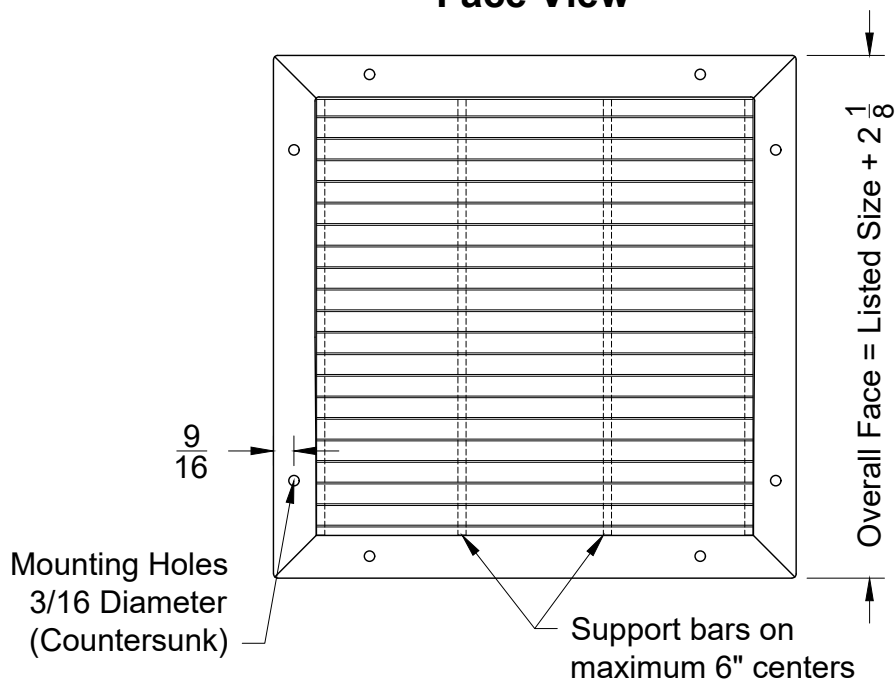Frame Details

Side View
Face View

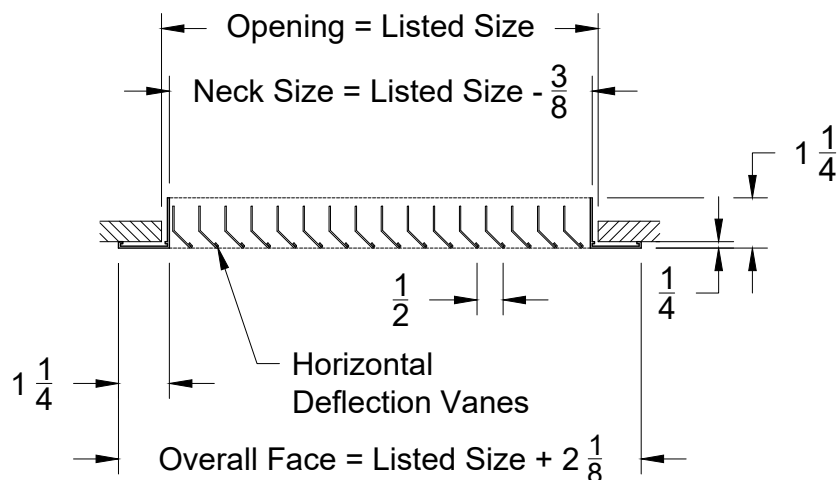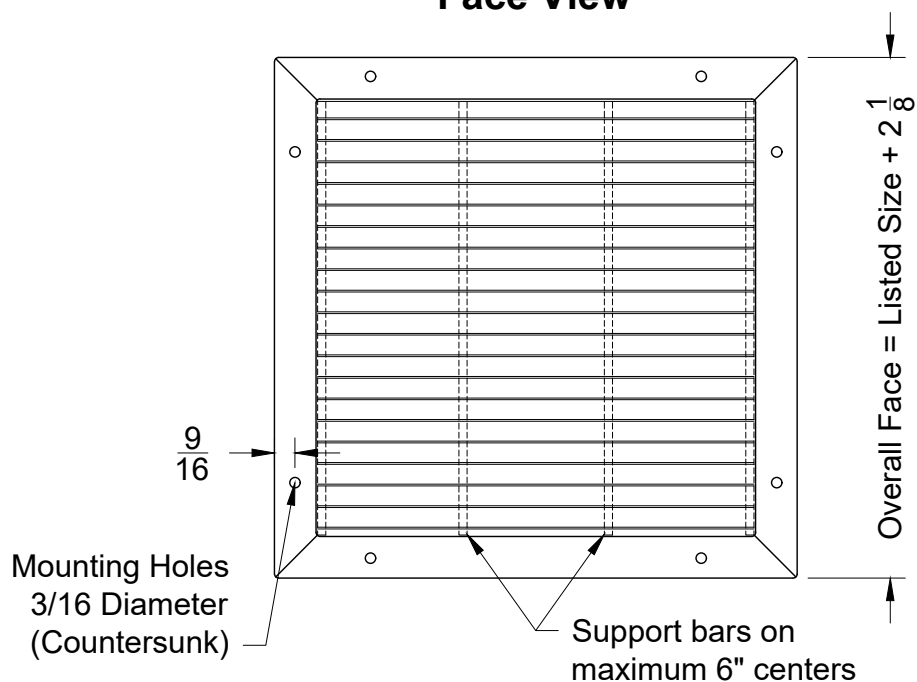
Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.

Frame Details

Side View
Face View


Note: This product complies with NFPA 90A-18 standard 4.3.7.3.2 and 4.3.8.3.2 and is constructed with openings through which a 1/2" sphere can not pass.