



Product Features:

- LADMC Mitered corners can come in 90 or 135 degree angles
- Can be used with hanger brackets for concealed mounting
- Available with standard for combo blade pattern controllers for horizontal or vertical applications
- Various frame types are available for different applications:
 - AA Frame – Exposed Flange
 - CC Frame – Concealed Tape and Spackle
 - FF Frame – Flush Channel Frame
- Combination frames are available when two different frames are required on a single linear

Finishes

20 - White/Black



 
03 - Black



02 - Satin Silver



24 - Mill




28 - Custom Color




¹ White Finish is suitable for a primer coat if field painting is required.

 Optional Accessories:




Standard Blades

 


Combo Blades


CFD Throw Pattern Visualization

Horizontal Throw

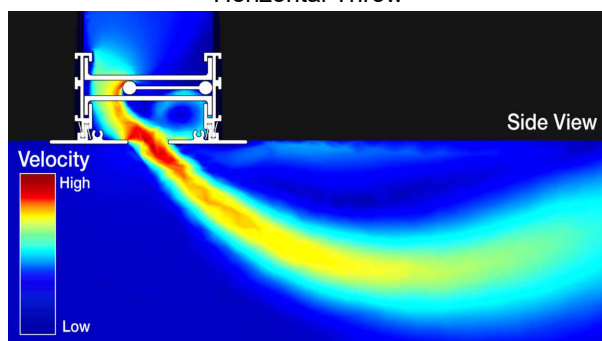


Vertical Throw

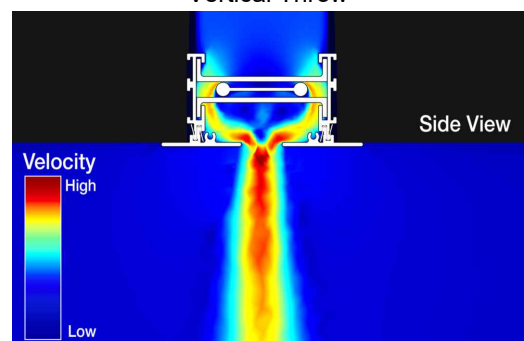


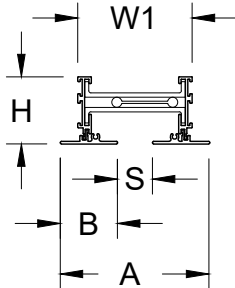


1 Slot

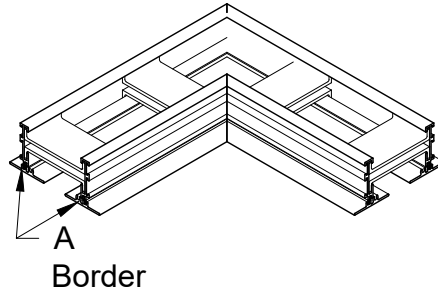


Mitered Corner 90°

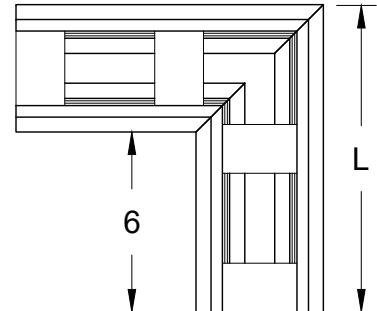


Mitered Corner 90° - Top View

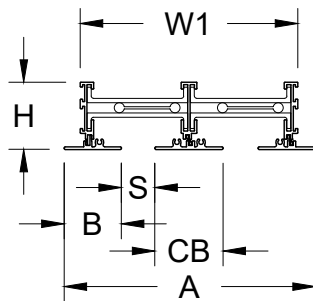

2 Slot

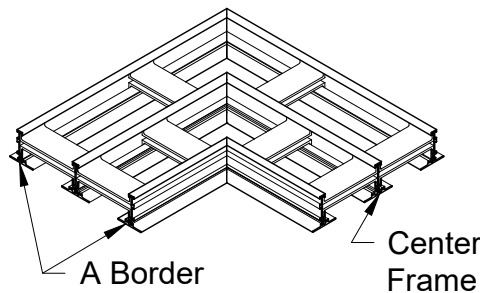


Mitered Corner 90°

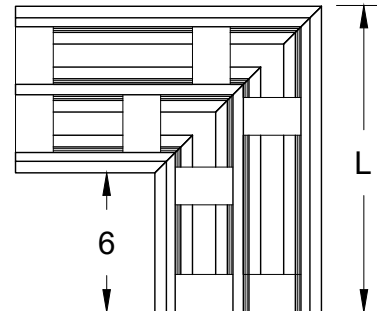


Mitered Corner 90° - Top View


Model 90°	Number	Slot	A Face	Neck	Height	Face	Neck	Center
	Slots	S	B	L	H	A	W-1	-
LADMC-10 AA 90	1	1	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 AA 90		1 1/2	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 AA 90		2	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 AA 90		2 1/2	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 AA 90		3	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	B	L	H	A	W-1	CB
LADMC-10 AA 90	2	1	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 AA 90		1 1/2	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 AA 90		2	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 AA 90		2 1/2	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 AA 90		3	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

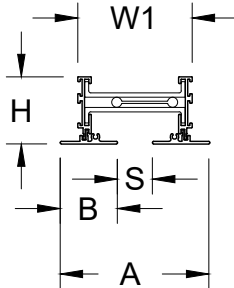


1 Slot

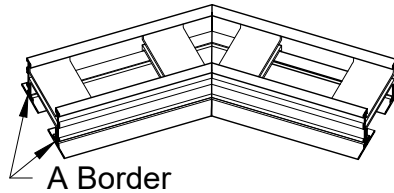


Mitered Corner 135°

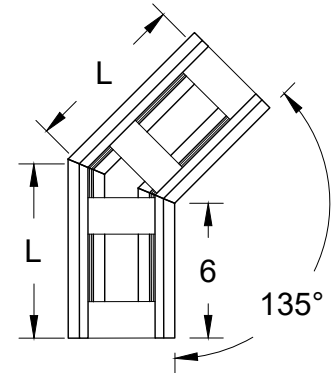


Mitered Corner 135° - Top View

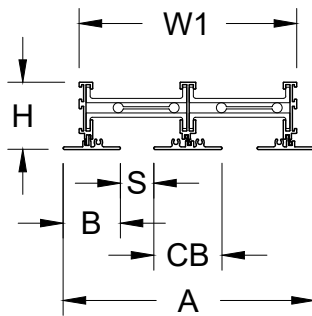

2 Slot


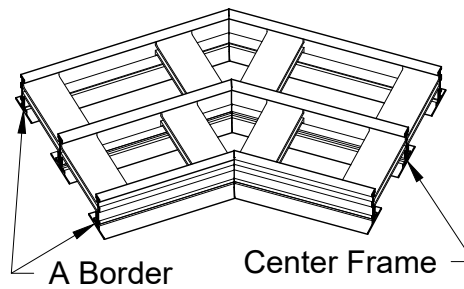


Mitered Corner 135°

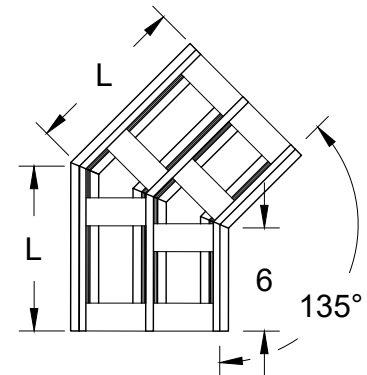


Mitered Corner 135° - Top View



Model 135°	Number	Slot	A Face	Neck	Height	Face	Neck	Center
	Slots	S	B	L	H	A	W-1	-
LADMC-10 AA 135	1	1	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 AA 135		1 1/2	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 AA 135		2	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 AA 135		2 1/2	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 AA 135		3	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	B	L	H	A	W-1	CB
LADMC-10 AA 135	2	1	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 AA 135		1 1/2	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 AA 135		2	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 AA 135		2 1/2	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 AA 135		3	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

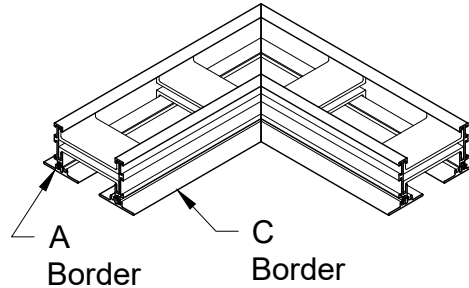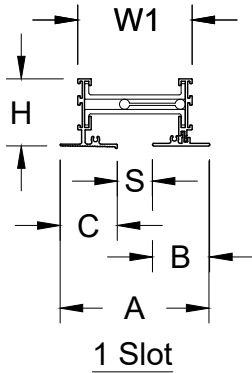


Mitered Corner 90°

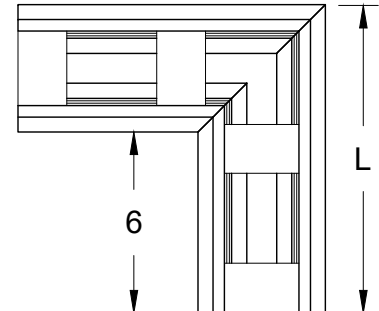

Mitered Corner 90° - Top View

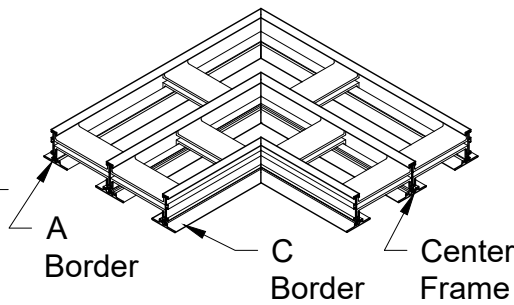
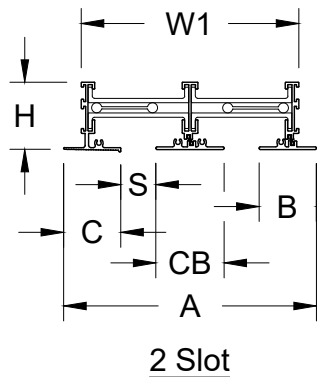


Mitered Corner 90°



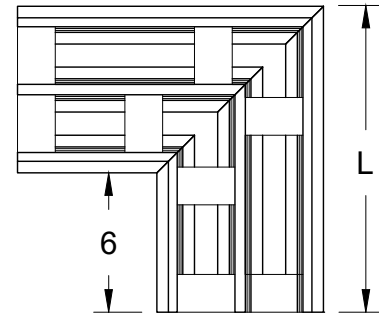


Mitered Corner 90° - Top View


Model 90°	Number	Slot	A Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	B	C	L	H	A	W-1	-
LADMC-10 AC 90	1	1	1 5/8	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 AC 90		1 1/2	1 5/8	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 AC 90		2	1 5/8	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 AC 90		2 1/2	2 1/8	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 AC 90		3	2 1/8	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	B	C	L	H	A	W-1	CB
LADMC-10 AC 90	2	1	1 5/8	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 AC 90		1 1/2	1 5/8	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 AC 90		2	1 5/8	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 AC 90		2 1/2	2 1/8	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 AC 90		3	2 1/8	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

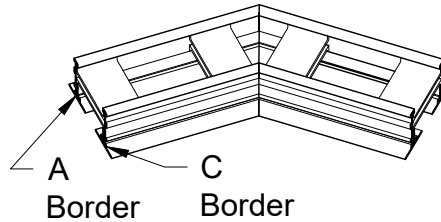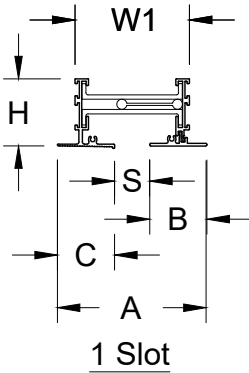



Mitered Corner 135°

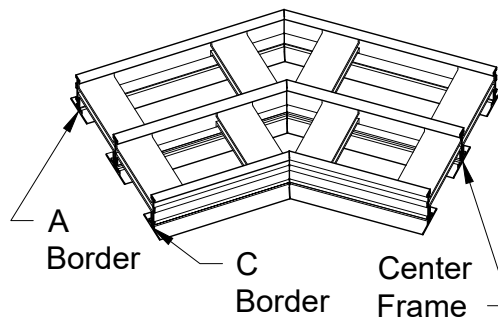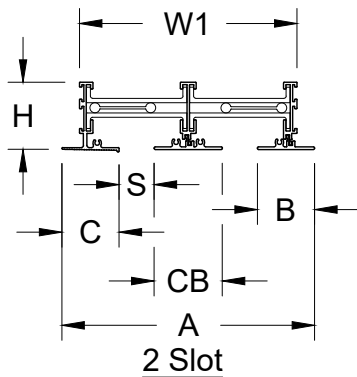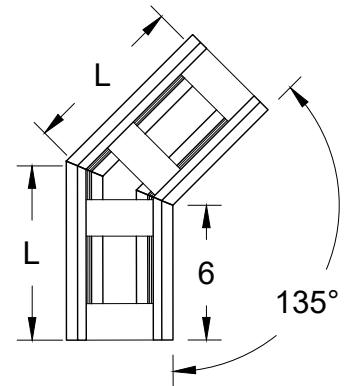


Mitered Corner 135°

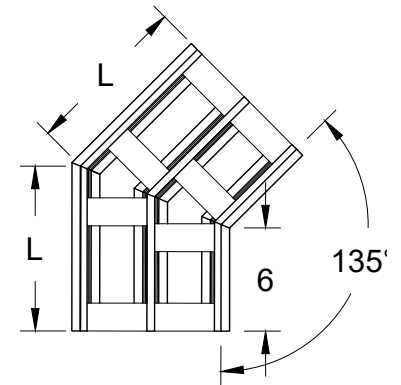



Model 135°	Number	Slot	A Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	B	C	L	H	A	W-1	-
LADMC-10 AC 135	1	1	1 5/8	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 AC 135		1 1/2	1 5/8	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 AC 135		2	1 5/8	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 AC 135		2 1/2	2 1/8	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 AC 135		3	2 1/8	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	B	C	L	H	A	W-1	CB
LADMC-10 AC 135	2	1	1 5/8	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 AC 135		1 1/2	1 5/8	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 AC 135		2	1 5/8	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 AC 135		2 1/2	2 1/8	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 AC 135		3	2 1/8	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

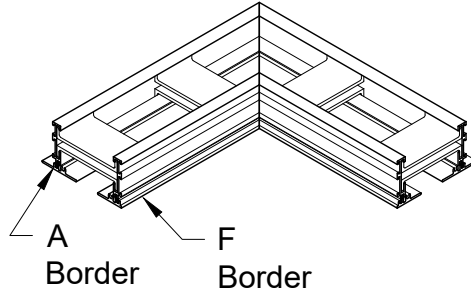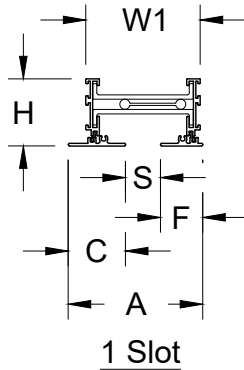


Mitered Corner 90°

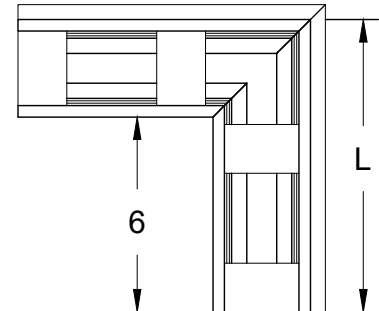

Mitered Corner 90° - Top View

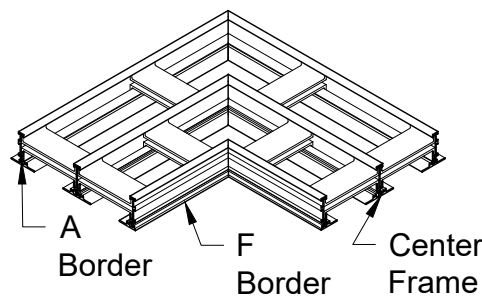
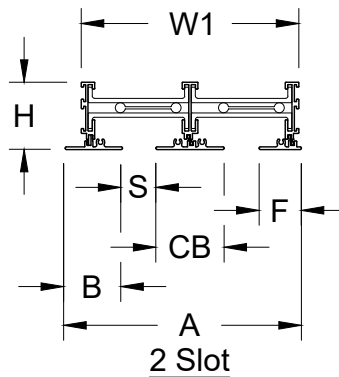


Mitered Corner 90°



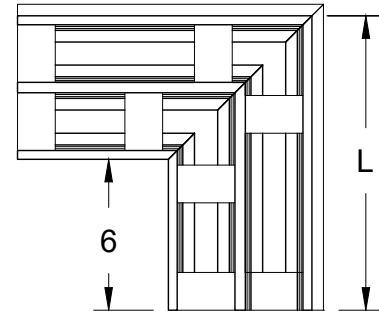


Mitered Corner 90° - Top View


Model 90°	Number	Slot	A Face	F Face	Neck	Height	Face	Neck	Center
	Slots	S	B	F	L	H	A	W-1	-
LADMC-10 AF 90	1	1	1 5/8	1 1/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 AF 90		1 1/2	1 5/8	1 1/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 AF 90		2	1 5/8	1 1/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 AF 90		2 1/2	2 1/8	1 5/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 AF 90		3	2 1/8	1 5/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	B	F	L	H	A	W-1	CB
LADMC-10 AF 90	2	1	1 5/8	1 1/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 AF 90		1 1/2	1 5/8	1 1/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 AF 90		2	1 5/8	1 1/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 AF 90		2 1/2	2 1/8	1 5/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 AF 90		3	2 1/8	1 5/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

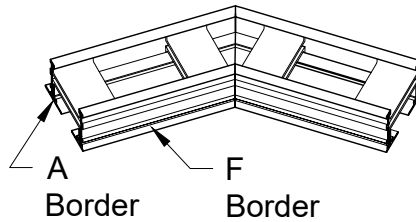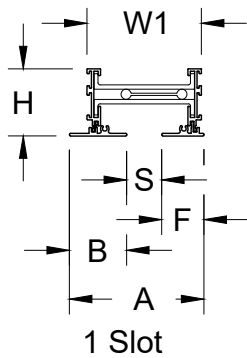







Mitered Corner 135°

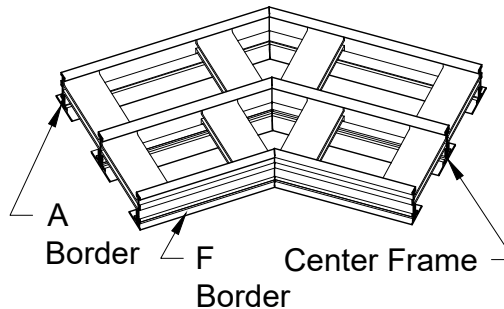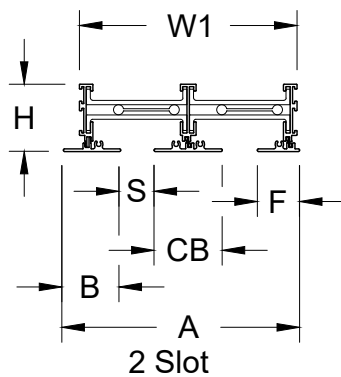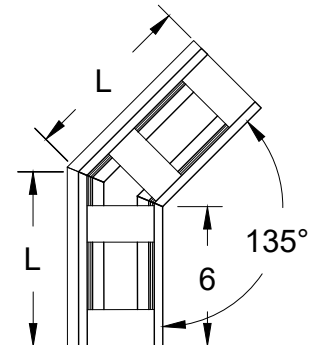



Mitered Corner 135°

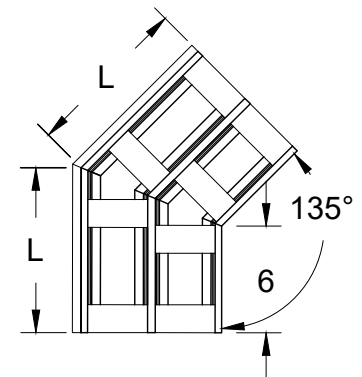


Model 135°	Number	Slot	A Face	F Face	Neck	Height	Face	Neck	Center
	Slots	S	B	F	L	H	A	W-1	-
LADMC-10 AF 135	1	1	1 5/8	1 1/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 AF 135		1 1/2	1 5/8	1 1/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 AF 135		2	1 5/8	1 1/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 AF 135		2 1/2	2 1/8	1 5/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 AF 135		3	2 1/8	1 5/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	B	F	L	H	A	W-1	CB
LADMC-10 AF 135	2	1	1 5/8	1 1/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 AF 135		1 1/2	1 5/8	1 1/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 AF 135		2	1 5/8	1 1/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 AF 135		2 1/2	2 1/8	1 5/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 AF 135		3	2 1/8	1 5/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

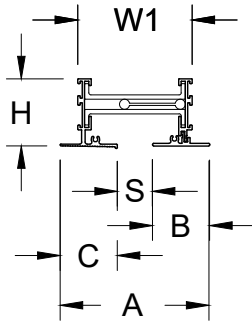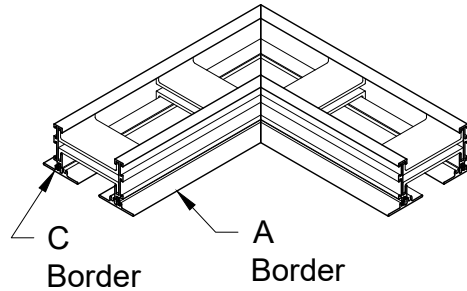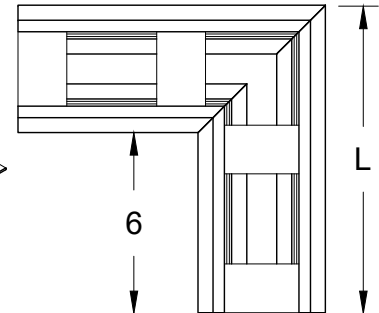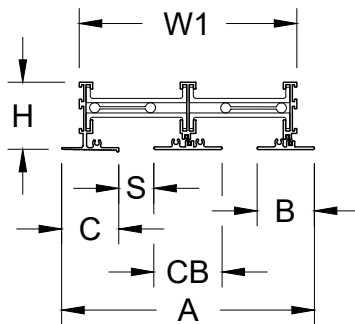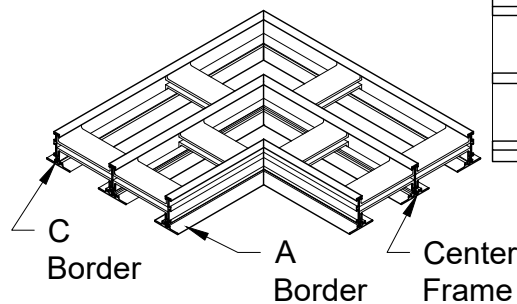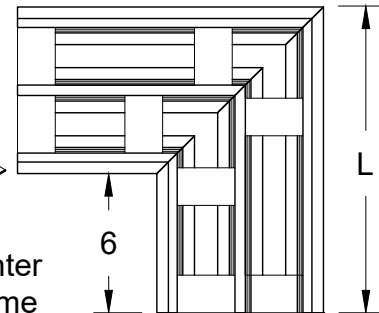
1 Slot

Mitered Corner 90°

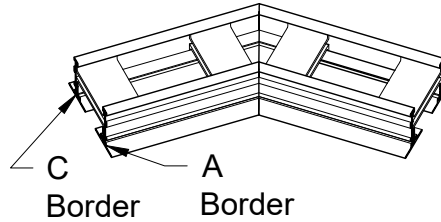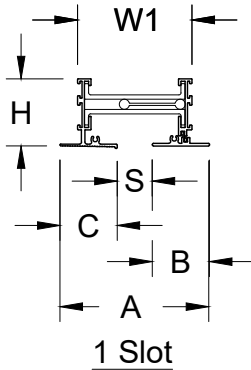Mitered Corner 90° - Top View

2 Slot

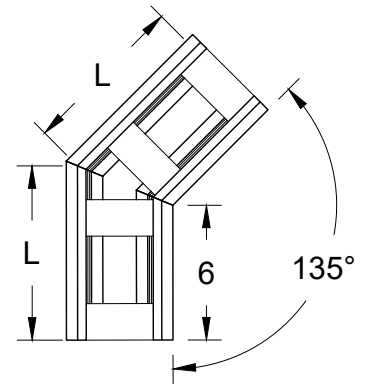Mitered Corner 90°

Mitered Corner 90° - Top View



Model 90°	Number	Slot	A Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	B	C	L	H	A	W-1	-
LADMC-10 CA 90	1	1	1 5/8	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 CA 90		1 1/2	1 5/8	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 CA 90		2	1 5/8	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 CA 90		2 1/2	2 1/8	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 CA 90		3	2 1/8	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	B	C	L	H	A	W-1	CB
LADMC-10 CA 90	2	1	1 5/8	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 CA 90		1 1/2	1 5/8	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 CA 90		2	1 5/8	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 CA 90		2 1/2	2 1/8	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 CA 90		3	2 1/8	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16




Mitered Corner 135°



Mitered Corner 135° - Top View





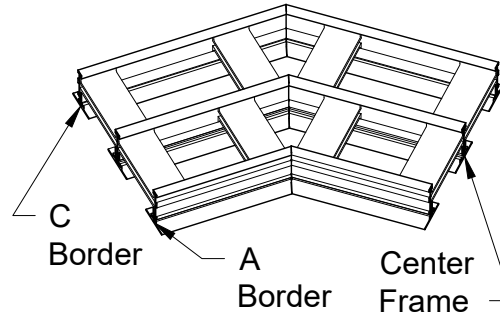
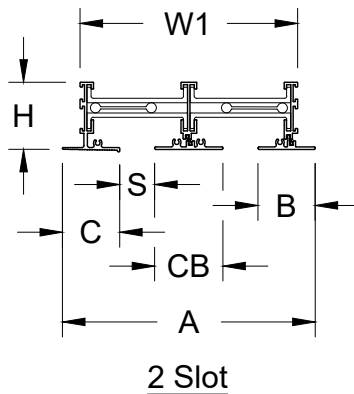


Mitered Corner 135°

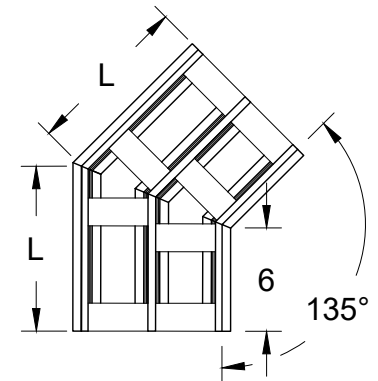


Mitered Corner 135° - Top View


Model 135°	Number	Slot	A Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	B	C	L	H	A	W-1	-
LADMC-10 CA 135	1	1	1 5/8	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 CA 135		1 1/2	1 5/8	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 CA 135		2	1 5/8	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 CA 135		2 1/2	2 1/8	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 CA 135		3	2 1/8	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	B	C	L	H	A	W-1	CB
LADMC-10 CA 135	2	1	1 5/8	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 CA 135		1 1/2	1 5/8	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 CA 135		2	1 5/8	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 CA 135		2 1/2	2 1/8	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 CA 135		3	2 1/8	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

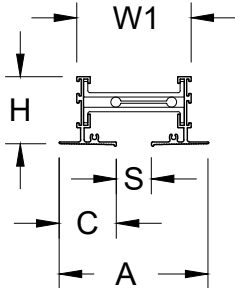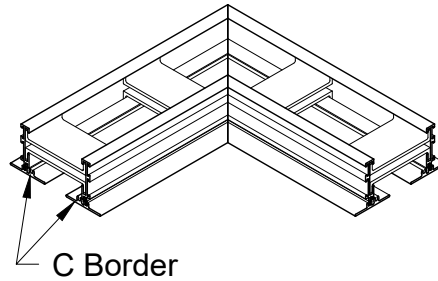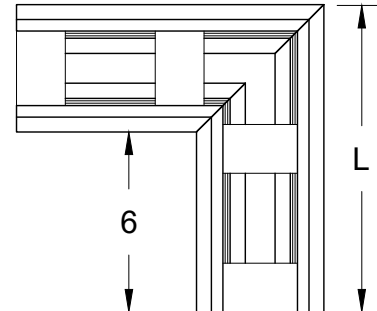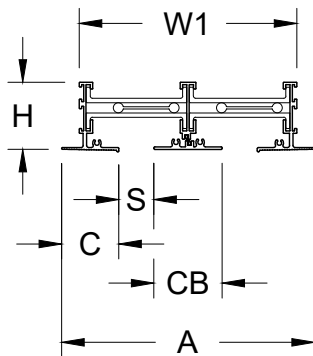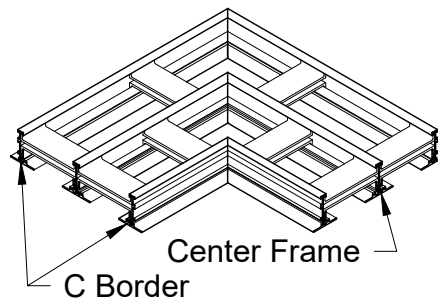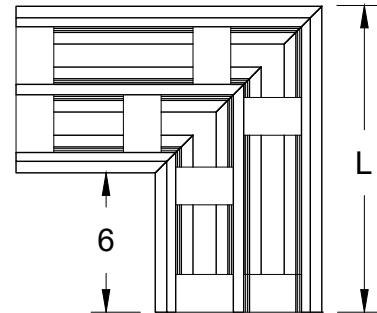
1 Slot

Mitered Corner 90°

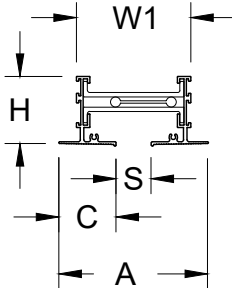Mitered Corner 90° - Top View

2 Slot

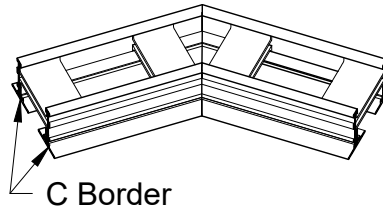Mitered Corner 90°

Mitered Corner 90° - Top View


Model 90°	Number	Slot	C Face	Neck	Height	Face	Neck	Center
	Slots	S	C	L	H	A	W-1	-
LADMC-10 CC 90	1	1	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 CC 90		1 1/2	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 CC 90		2	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 CC 90		2 1/2	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 CC 90		3	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	C	L	H	A	W-1	CB
LADMC-10 CC 90	2	1	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 CC 90		1 1/2	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 CC 90		2	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 CC 90		2 1/2	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 CC 90		3	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16




1 Slot




Mitered Corner 135°

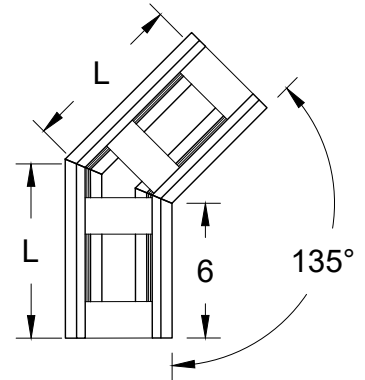


Mitered Corner 135° - Top View

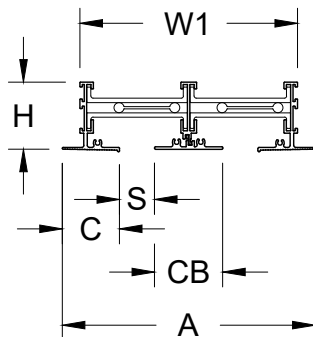

2 Slot


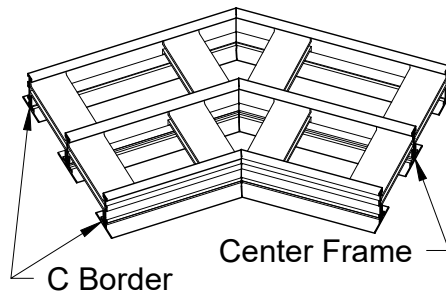


Mitered Corner 135°

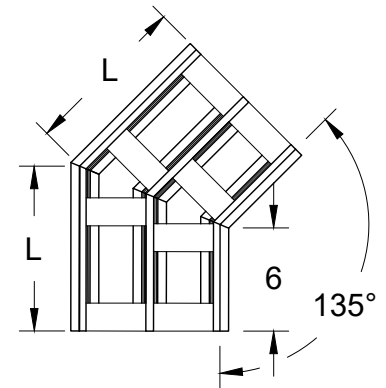


Mitered Corner 135° - Top View



Model 135°	Number	Slot	C Face	Neck	Height	Face	Neck	Center
	Slots	S	C	L	H	A	W-1	-
LADMC-10 CC 135	1	1	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 CC 135		1 1/2	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 CC 135		2	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 CC 135		2 1/2	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 CC 135		3	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	C	L	H	A	W-1	CB
LADMC-10 CC 135	2	1	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 CC 135		1 1/2	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 CC 135		2	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 CC 135		2 1/2	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 CC 135		3	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

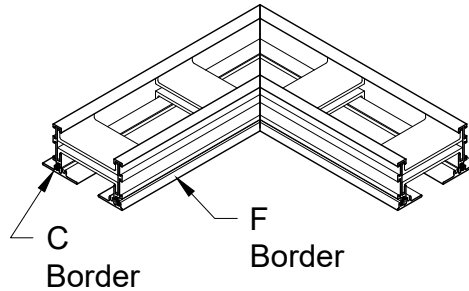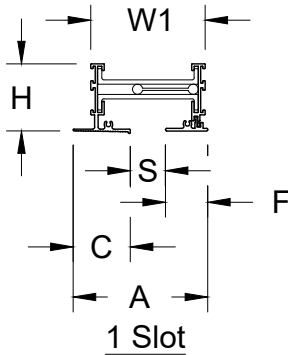


Mitered Corner 90°

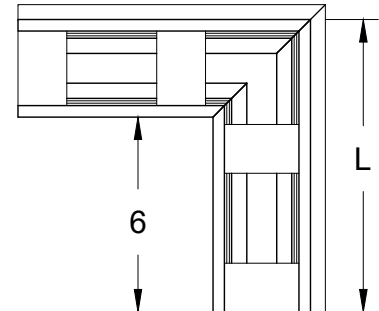

Mitered Corner 90° - Top View

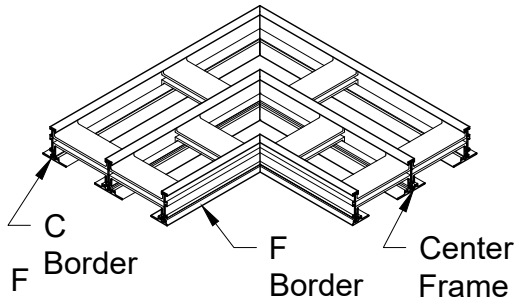
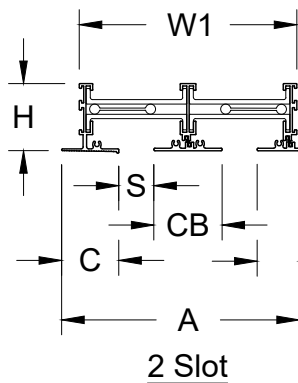


Mitered Corner 90°

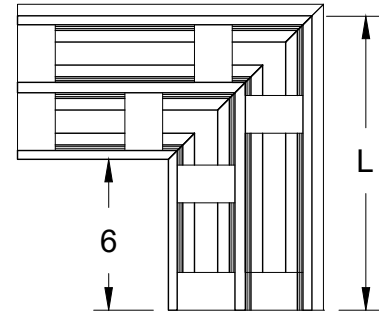


Mitered Corner 90° - Top View



Model 90°	Number	Slot	F Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	F	C	L	H	A	W-1	-
LADMC-10 CF 90	1	1	1 1/8	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 CF 90		1 1/2	1 1/8	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 CF 90		2	1 1/8	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 CF 90		2 1/2	1 5/8	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 CF 90		3	1 5/8	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	F	C	L	H	A	W-1	CB
LADMC-10 CF 90	2	1	1 1/8	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 CF 90		1 1/2	1 1/8	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 CF 90		2	1 1/8	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 CF 90		2 1/2	1 5/8	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 CF 90		3	1 5/8	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

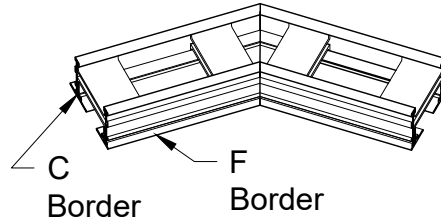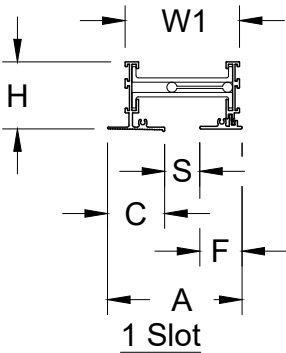


Mitered Corner 135°

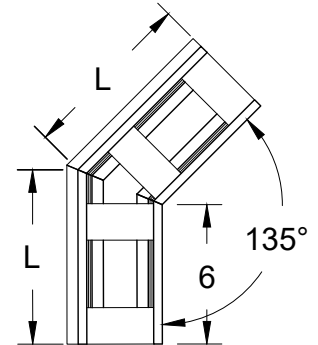

Mitered Corner 135° - Top View

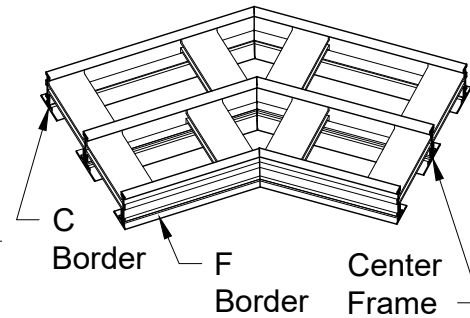
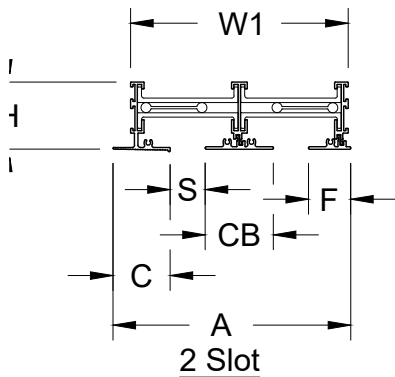


Mitered Corner 135°

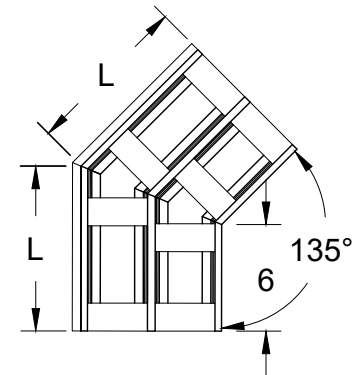


Mitered Corner 135° - Top View



Model 135°	Number	Slot	F Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	F	C	L	H	A	W-1	-
LADMC-10 CF 135	1	1	1 1/8	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 CF 135		1 1/2	1 1/8	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 CF 135		2	1 1/8	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 CF 135		2 1/2	1 5/8	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 CF 135		3	1 5/8	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	F	C	L	H	A	W-1	CB
LADMC-10 CF 135	2	1	1 1/8	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 CF 135		1 1/2	1 1/8	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 CF 135		2	1 1/8	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 CF 135		2 1/2	1 5/8	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 CF 135		3	1 5/8	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

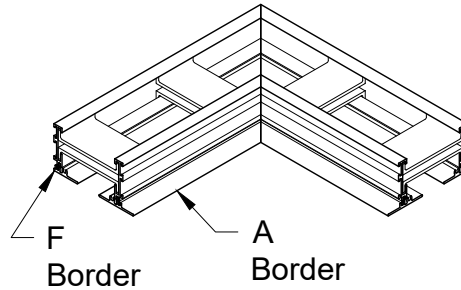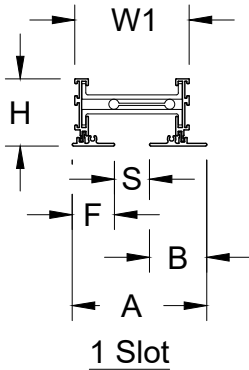


Mitered Corner 90°

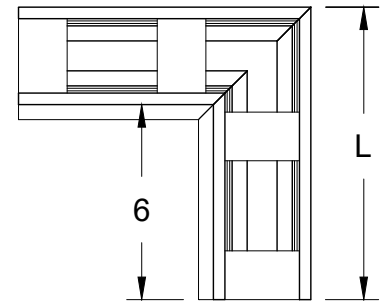

Mitered Corner 90° - Top View

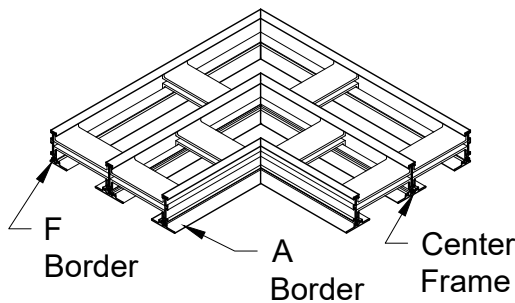
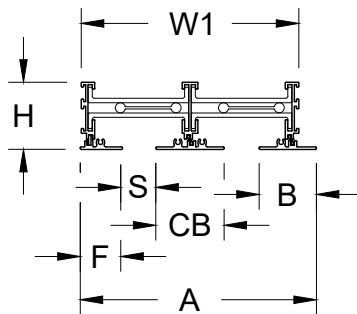


Mitered Corner 90°

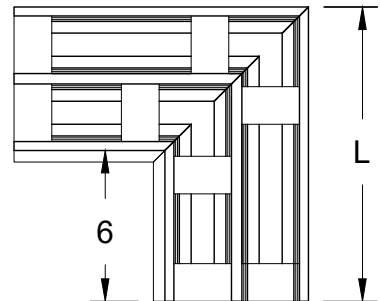


Mitered Corner 90° - Top View



Model 90°	Number	Slot	F Face	A Face	Neck	Height	Face	Neck	Center
	Slots	S	F	B	L	H	A	W-1	-
LADMC-10 FA 90	1	1	1 1/8	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 FA 90		1 1/2	1 1/8	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 FA 90		2	1 1/8	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 FA 90		2 1/2	1 5/8	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 FA 90		3	1 5/8	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	F	B	L	H	A	W-1	CB
LADMC-10 FA 90	2	1	1 1/8	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 FA 90		1 1/2	1 1/8	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 FA 90		2	1 1/8	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 FA 90		2 1/2	1 5/8	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 FA 90		3	1 5/8	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

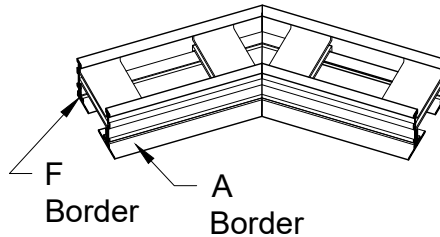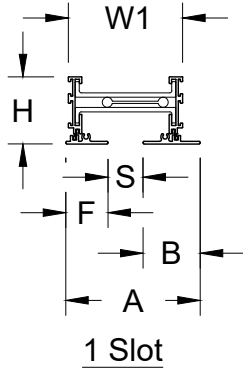


Mitered Corner 135°

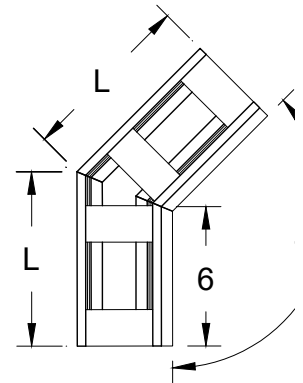

Mitered Corner 135° - Top View

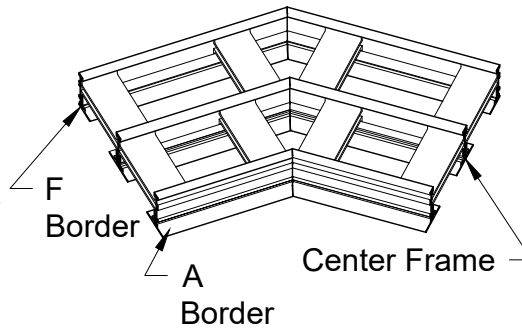
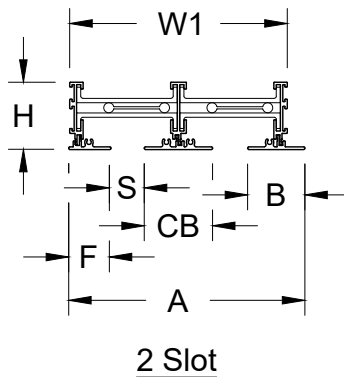


Mitered Corner 135°

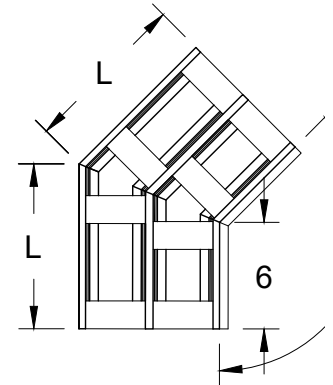


Mitered Corner 135° - Top View



Model 135°	Number	Slot	F Face	A Face	Neck	Height	Face	Neck	Center
	Slots	S	F	B	L	H	A	W-1	-
LADMC-10 FA 135	1	1	1 1/8	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 FA 135		1 1/2	1 1/8	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 FA 135		2	1 1/8	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 FA 135		2 1/2	1 5/8	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 FA 135		3	1 5/8	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	F	B	L	H	A	W-1	CB
LADMC-10 FA 135	2	1	1 1/8	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 FA 135		1 1/2	1 1/8	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 FA 135		2	1 1/8	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 FA 135		2 1/2	1 5/8	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 FA 135		3	1 5/8	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

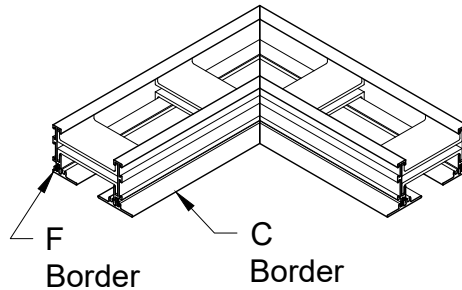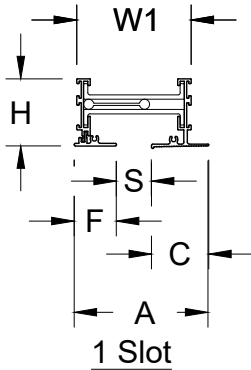


Mitered Corner 90°

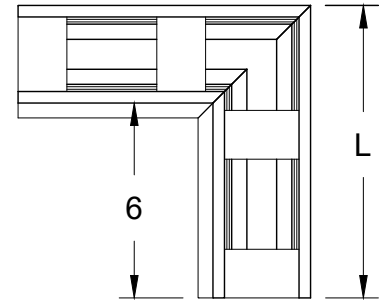

Mitered Corner 90° - Top View

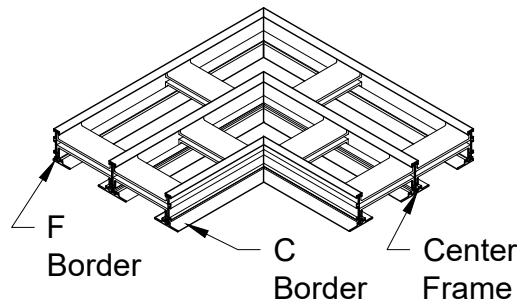
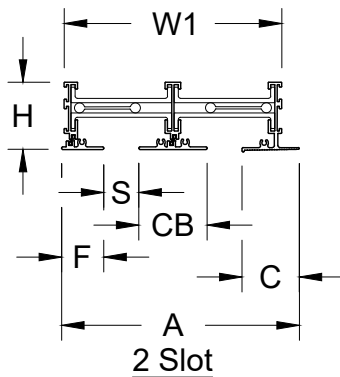


Mitered Corner 90°

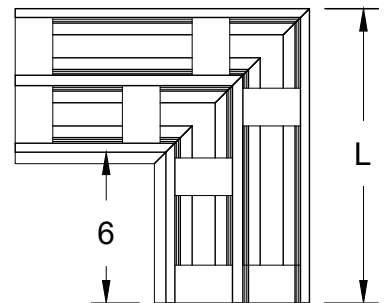


Mitered Corner 90° - Top View



Model 90°	Number	Slot	F Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	F	C	L	H	A	W-1	-
LADMC-10 FC 90	1	1	1 1/8	1 5/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 FC 90		1 1/2	1 1/8	1 5/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 FC 90		2	1 1/8	1 5/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 FC 90		2 1/2	1 5/8	2 1/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 FC 90		3	1 5/8	2 1/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	F	C	L	H	A	W-1	CB
LADMC-10 FC 90	2	1	1 1/8	1 5/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 FC 90		1 1/2	1 1/8	1 5/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 FC 90		2	1 1/8	1 5/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 FC 90		2 1/2	1 5/8	2 1/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 FC 90		3	1 5/8	2 1/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

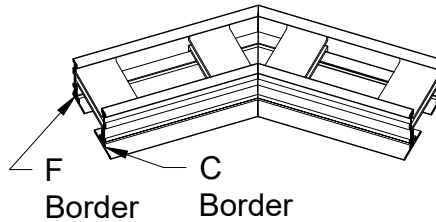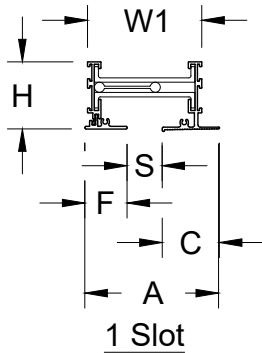


Mitered Corner 135°

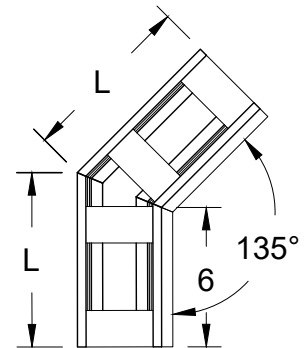

Mitered Corner 135° - Top View

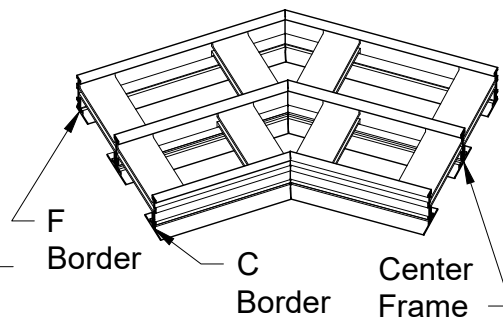
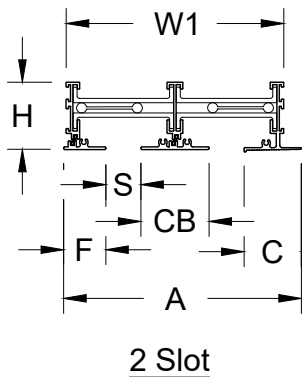


Mitered Corner 135°

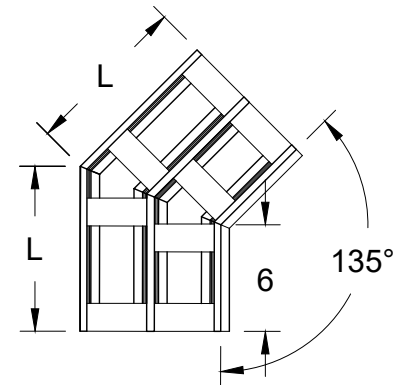


Mitered Corner 135° - Top View



Model 135°	Number	Slot	F Face	C Face	Neck	Height	Face	Neck	Center
	Slots	S	F	C	L	H	A	W-1	-
LADMC-10 FC 135	1	1	1 1/8	1 5/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 FC 135		1 1/2	1 1/8	1 5/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 FC 135		2	1 1/8	1 5/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 FC 135		2 1/2	1 5/8	2 1/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 FC 135		3	1 5/8	2 1/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	F	C	L	H	A	W-1	CB
LADMC-10 FC 135	2	1	1 1/8	1 5/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 FC 135		1 1/2	1 1/8	1 5/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 FC 135		2	1 1/8	1 5/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 FC 135		2 1/2	1 5/8	2 1/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 FC 135		3	1 5/8	2 1/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16

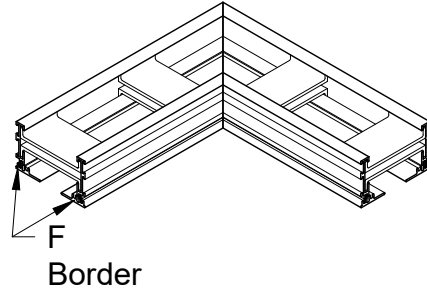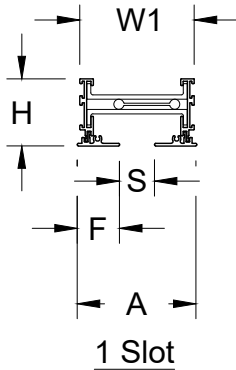


Mitered Corner 90°

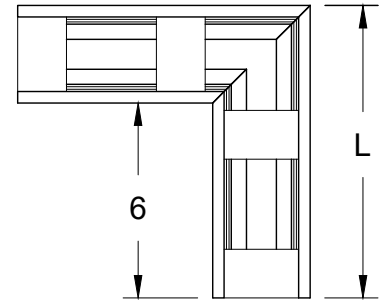

Mitered Corner 90° - Top View

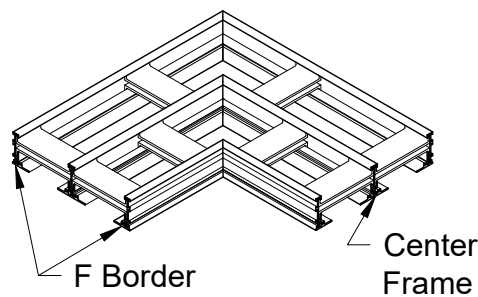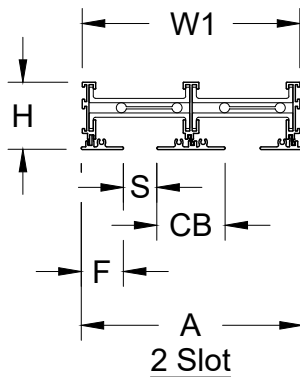


Mitered Corner 90°

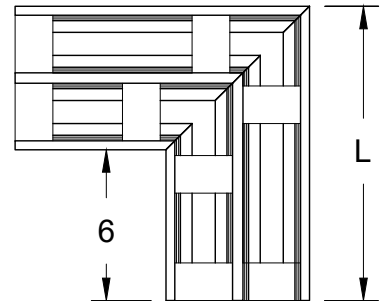


Mitered Corner 90° - Top View


Model 90°	Number	Slot	F Face	Neck	Height	Face	Neck	Center
	Slots	S	F	L	H	A	W-1	-
LADMC-10 FF 90	1	1	1 1/8	9 1/4	1 15/16	4 1/4	3 1/4	0
LADMC-15 FF 90		1 1/2	1 1/8	9 3/4	1 15/16	4 3/4	3 3/4	0
LADMC-20 FF 90		2	1 1/8	10 1/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 FF 90		2 1/2	1 5/8	11 3/4	2 9/16	6 3/4	5 3/4	0
LADMC-30 FF 90		3	1 5/8	12 1/4	2 9/16	7 1/4	6 1/4	0
Model 90°	Slots	S	F	L	H	A	W-1	CB
LADMC-10 FF 90	2	1	1 1/8	12 3/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 FF 90		1 1/2	1 1/8	13 3/16	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 FF 90		2	1 1/8	14 3/16	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 FF 90		2 1/2	1 5/8	17 3/16	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 FF 90		3	1 5/8	18 3/16	2 9/16	13 3/16	12 3/16	2 15/16

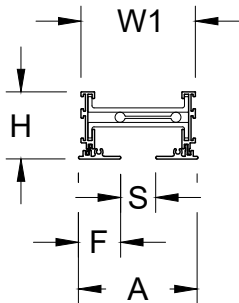


1 Slot

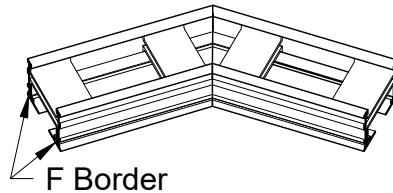


Mitered Corner 135°

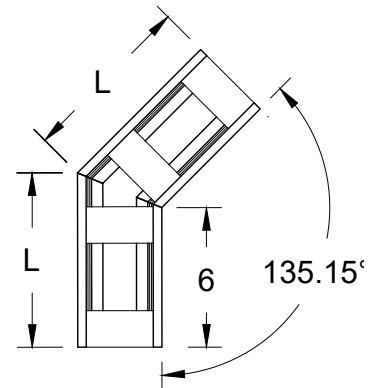


Mitered Corner 135° - Top View

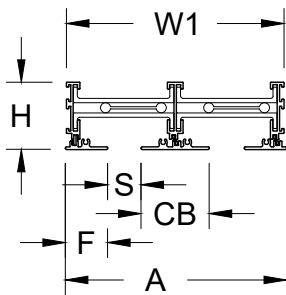

2 Slot

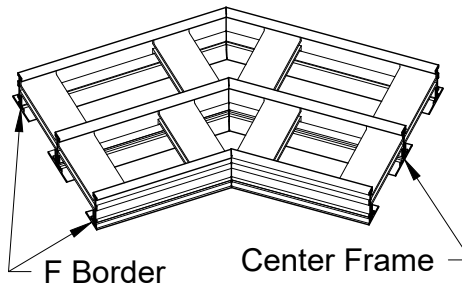

Mitered Corner 135°

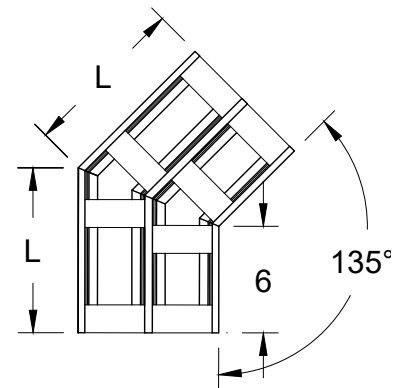

Mitered Corner 135° - Top View

Model 135°	Number	Slot	F Face	Neck	Height	Face	Neck	Center
	Slots	S	F	L	H	A	W-1	-
LADMC-10 FF 135	1	1	1 1/8	7 3/8	1 15/16	4 1/4	3 1/4	0
LADMC-15 FF 135		1 1/2	1 1/8	7 9/16	1 15/16	4 3/4	3 3/4	0
LADMC-20 FF 135		2	1 1/8	7 3/4	1 15/16	5 1/4	4 1/4	0
LADMC-25 FF 135		2 1/2	1 5/8	8 3/8	2 9/16	6 3/4	5 3/4	0
LADMC-30 FF 135		3	1 5/8	8 9/16	2 9/16	7 1/4	6 1/4	0
Model 135°	Slots	S	F	L	H	A	W-1	CB
LADMC-10 FF 135	2	1	1 1/8	8 9/16	1 15/16	7 3/16	6 3/16	1 15/16
LADMC-15 FF 135		1 1/2	1 1/8	9	1 15/16	8 3/16	7 3/16	1 15/16
LADMC-20 FF 135		2	1 1/8	9 3/8	1 15/16	9 3/16	8 3/16	1 15/16
LADMC-25 FF 135		2 1/2	1 5/8	10 5/8	2 9/16	12 3/16	11 3/16	2 15/16
LADMC-30 FF 135		3	1 5/8	11 1/16	2 9/16	13 3/16	12 3/16	2 15/16