 


Product Features:

- Available with 1", 1/2" or 3/16" wide frames
- LSDMC Mitered corners can come in 90, 135 degrees
- Can be used with hanger brackets for concealed mounting
- Available with 7/32" or 1/8" thick bars
- Mitered corners can also come in 90 degree Vertical Inside (VI) /Vertical Outside (VO)
- Various frame types are available for different applications
- Available with 1/2" or 1/4" bar spacing

Finishes

01 - White¹



03 - Black



¹ White Finish is suitable for a primer coat if field painting is required.

 
02 - Satin Silver



04 - Clear Anodized




24 - Mill




28 - Custom Color




CFD Throw Pattern Visualization

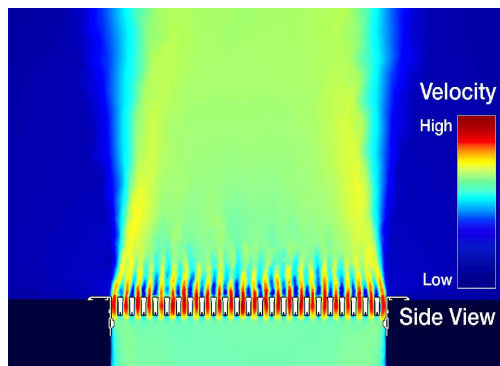


Optional Accessories:

 



L9 - Equalizing Grid

 

DA - Opposed Blade Damper Aluminum


 


PP - Pencil Proof Core
17/64" Pencil Proof Bars

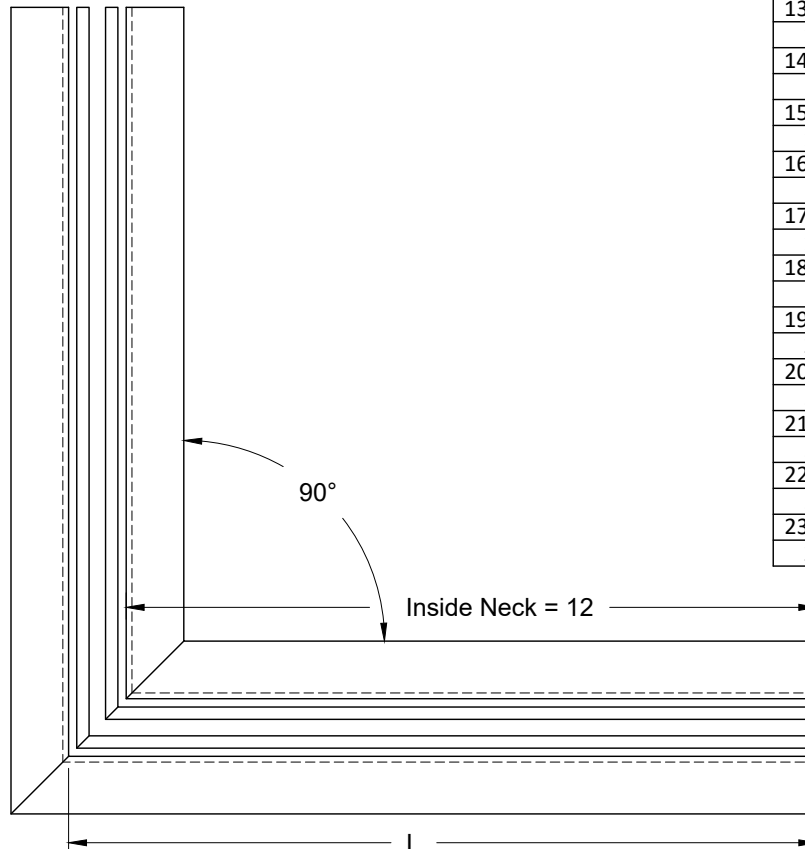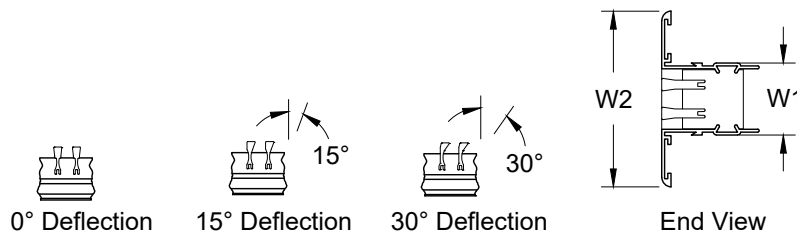


Mitered Face View

90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	13
2	1 3/4	3 9/16	13 1/2
2 1/2	2 1/4	4 1/16	14
3	2 3/4	4 9/16	14 1/2
3 1/2	3 1/4	5 1/16	15
4	3 3/4	5 9/16	15 1/2
4 1/2	4 1/4	6 1/16	16
5	4 3/4	6 9/16	16 1/2
5 1/2	5 1/4	7 1/16	17
6	5 3/4	7 9/16	17 1/2
6 1/2	6 1/4	8 1/16	18
7	6 3/4	8 9/16	18 1/2
7 1/2	7 1/4	9 1/16	19
8	7 3/4	9 9/16	19 1/2
8 1/2	8 1/4	10 1/16	20
9	8 3/4	10 9/16	20 1/2
9 1/2	9 1/4	11 1/16	21
10	9 3/4	11 9/16	21 1/2
10 1/2	10 1/4	12 1/16	22
11	10 3/4	12 9/16	22 1/2
11 1/2	11 1/4	13 1/16	23
12	11 3/4	13 9/16	23 1/2
12 1/2	12 1/4	14 1/16	23 1/2
13	12 3/4	14 9/16	24
13 1/2	13 1/4	15 1/16	24 1/2
14	13 3/4	15 9/16	25
14 1/2	14 1/4	16 1/16	25 1/2
15	14 3/4	16 9/16	26
15 1/2	15 1/4	17 1/16	26 1/2
16	15 3/4	17 9/16	27
16 1/2	16 1/4	18 1/16	27 1/2
17	16 3/4	18 9/16	28
17 1/2	17 1/4	19 1/16	28 1/2
18	17 3/4	19 9/16	29
18 1/2	18 1/4	20 1/16	29 1/2
19	18 3/4	20 9/16	30
19 1/2	19 1/4	21 1/16	30 1/2
20	19 3/4	21 9/16	31
20 1/2	20 1/4	22 1/16	31 1/2
21	20 3/4	22 9/16	32
21 1/2	21 1/4	23 1/16	32 1/2
22	21 3/4	23 9/16	33
22 1/2	22 1/4	24 1/16	33 1/2
23	22 3/4	24 9/16	34
23 1/2	23 1/4	25 1/16	34 1/2
24	23 3/4	25 9/16	35

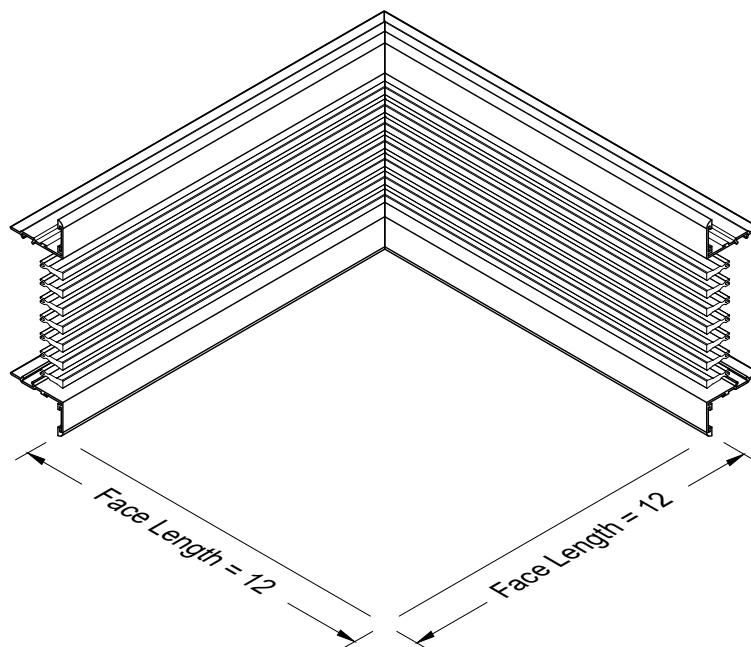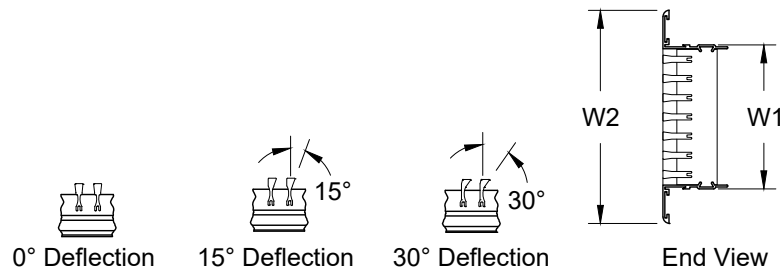


LBGMC-1-12A 90 Vertical Inside - Mitered Face View

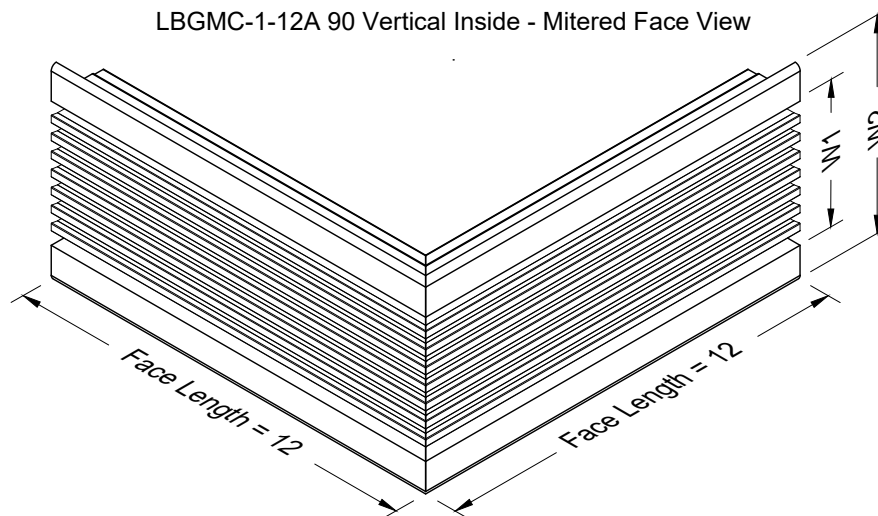


LBGMC-1-12A 90 Vertical Outside - Mitered Face View



Listed Width	Neck W1	Face W2
1 1/2	1 1/4	3 1/16
2	1 3/4	3 9/16
2 1/2	2 1/4	4 1/16
3	2 3/4	4 9/16
3 1/2	3 1/4	5 1/16
4	3 3/4	5 9/16
4 1/2	4 1/4	6 1/16
5	4 3/4	6 9/16
5 1/2	5 1/4	7 1/16
6	5 3/4	7 9/16
6 1/2	6 1/4	8 1/16
7	6 3/4	8 9/16
7 1/2	7 1/4	9 1/16
8	7 3/4	9 9/16
8 1/2	8 1/4	10 1/16
9	8 3/4	10 9/16
9 1/2	9 1/4	11 1/16
10	9 3/4	11 9/16
10 1/2	10 1/4	12 1/16
11	10 3/4	12 9/16
11 1/2	11 1/4	13 1/16
12	11 3/4	13 9/16
12 1/2	12 1/4	14 1/16
13	12 3/4	14 9/16
13 1/2	13 1/4	15 1/16
14	13 3/4	15 9/16
14 1/2	14 1/4	16 1/16
15	14 3/4	16 9/16
15 1/2	15 1/4	17 1/16
16	15 3/4	17 9/16
16 1/2	16 1/4	18 1/16
17	16 3/4	18 9/16
17 1/2	17 1/4	19 1/16
18	17 3/4	19 9/16
18 1/2	18 1/4	20 1/16
19	18 3/4	20 9/16
19 1/2	19 1/4	21 1/16
20	19 3/4	21 9/16
20 1/2	20 1/4	22 1/16
21	20 3/4	22 9/16
21 1/2	21 1/4	23 1/16
22	21 3/4	23 9/16
22 1/2	22 1/4	24 1/16
23	22 3/4	24 9/16
23 1/2	23 1/4	25 1/16
24	23 3/4	25 9/16

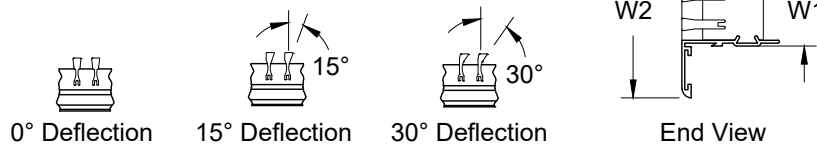


135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	12 7/16
2	1 3/4	3 9/16	12 5/8
2 1/2	2 1/4	4 1/16	12 13/16
3	2 3/4	4 9/16	13 1/16
3 1/2	3 1/4	5 1/16	13 1/4
4	3 3/4	5 9/16	13 7/16
4 1/2	4 1/4	6 1/16	13 11/16
5	4 3/4	6 9/16	13 7/8
5 1/2	5 1/4	7 1/16	14 1/16
6	5 3/4	7 9/16	14 1/4
6 1/2	6 1/4	8 1/16	14 1/2
7	6 3/4	8 9/16	14 11/16
7 1/2	7 1/4	9 1/16	14 7/8
8	7 3/4	9 9/16	15 1/8
8 1/2	8 1/4	10 1/16	15 5/16
9	8 3/4	10 9/16	15 1/2
9 1/2	9 1/4	11 1/16	15 3/4
10	9 3/4	11 9/16	15 15/16
10 1/2	10 1/4	12 1/16	16 1/8
11	10 3/4	12 9/16	16 3/8
11 1/2	11 1/4	13 1/16	16 9/16
12	11 3/4	13 9/16	16 3/4
12 1/2	12 1/4	14 1/16	16 15/16
13	12 3/4	14 9/16	17 1/8
13 1/2	13 1/4	15 1/16	17 5/16
14	13 3/4	15 9/16	17 1/2
14 1/2	14 1/4	16 1/16	17 11/16
15	14 3/4	16 9/16	17 7/8
15 1/2	15 1/4	17 1/16	18 1/16
16	15 3/4	17 9/16	18 1/4
16 1/2	16 1/4	18 1/16	18 7/16
17	16 3/4	18 9/16	18 5/8
17 1/2	17 1/4	19 1/16	18 13/16
18	17 3/4	19 9/16	19
18 1/2	18 1/4	20 1/16	19 3/16
19	18 3/4	20 9/16	19 3/8
19 1/2	19 1/4	21 1/16	19 9/16
20	19 3/4	21 9/16	19 3/4
20 1/2	20 1/4	22 1/16	19 15/16
21	20 3/4	22 9/16	20 1/8
21 1/2	21 1/4	23 1/16	20 5/16
22	21 3/4	23 9/16	20 1/2
22 1/2	22 1/4	24 1/16	20 11/16
23	22 3/4	24 9/16	20 7/8
23 1/2	23 1/4	25 1/16	21 1/16
24	23 3/4	25 9/16	21 1/4

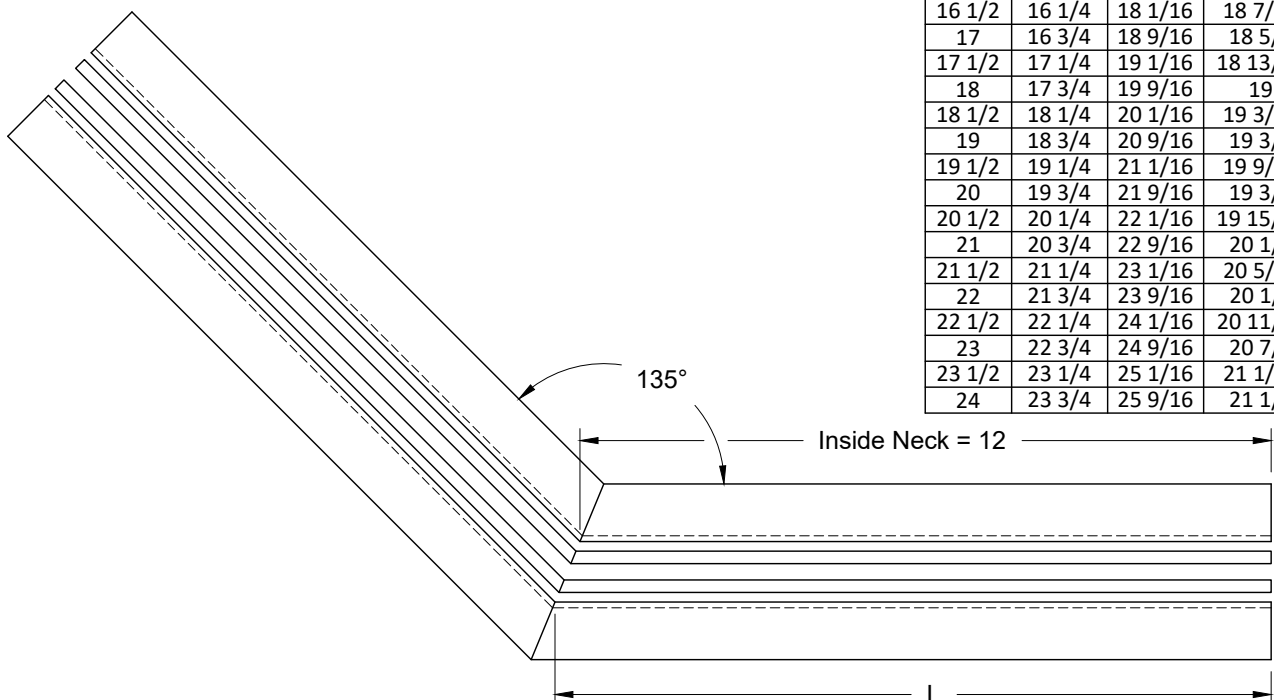

Mitered Face View

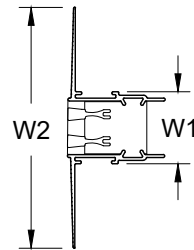
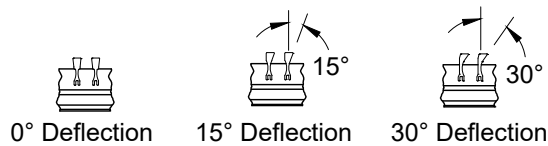


End View

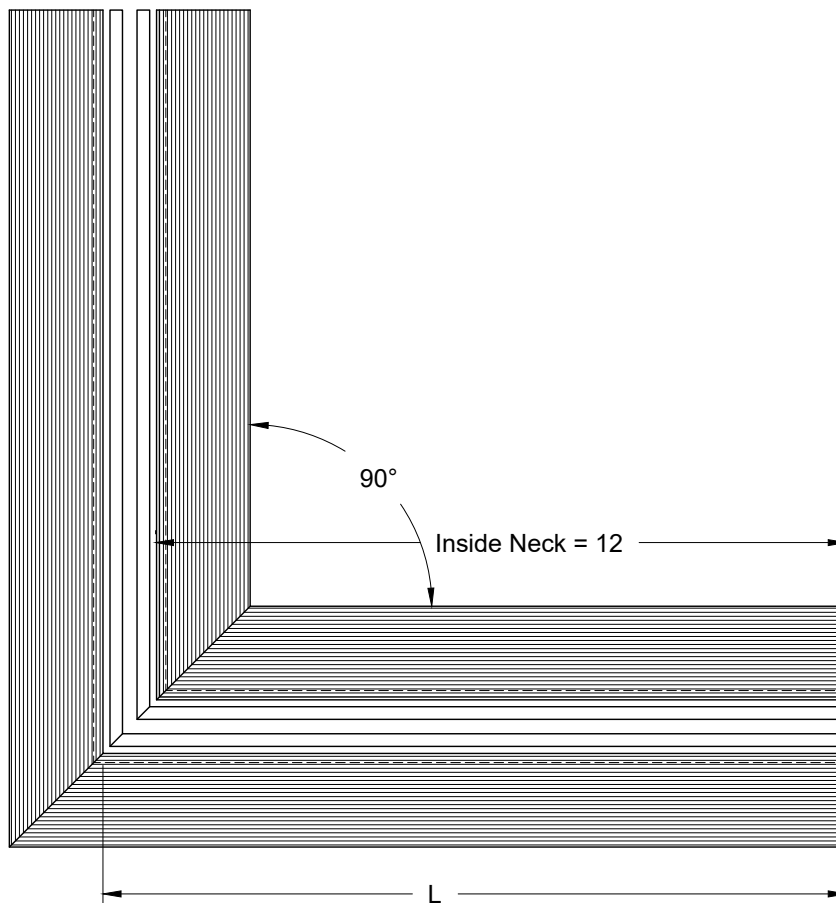


Mitered Face View


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	4 3/16	13 1/16
2	1 3/4	4 11/16	13 9/16
2 1/2	2 1/4	5 3/16	14 1/16
3	2 3/4	5 11/16	14 9/16
3 1/2	3 1/4	6 3/16	15 1/16
4	3 3/4	6 11/16	15 9/16
4 1/2	4 1/4	7 3/16	16 1/16
5	4 3/4	7 11/16	16 9/16
5 1/2	5 1/4	8 3/16	17 1/16
6	5 3/4	8 11/16	17 9/16
6 1/2	6 1/4	9 3/16	18 1/16
7	6 3/4	9 11/16	18 9/16
7 1/2	7 1/4	10 3/16	19 1/16
8	7 3/4	10 11/16	19 9/16
8 1/2	8 1/4	11 3/16	20 1/16
9	8 3/4	11 11/16	20 9/16
9 1/2	9 1/4	12 3/16	21 1/16
10	9 3/4	12 11/16	21 9/16
10 1/2	10 1/4	13 3/16	22 1/16
11	10 3/4	13 11/16	22 9/16
11 1/2	11 1/4	14 3/16	23 1/16
12	11 3/4	14 11/16	23 9/16
12 1/2	12 1/4	15 3/16	23 9/16
13	12 3/4	15 11/16	24 1/16
13 1/2	13 1/4	16 3/16	24 9/16
14	13 3/4	16 11/16	25 1/16
14 1/2	14 1/4	17 3/16	25 9/16
15	14 3/4	17 11/16	26 1/16
15 1/2	15 1/4	18 3/16	26 9/16
16	15 3/4	18 11/16	27 1/16
16 1/2	16 1/4	19 3/16	27 9/16
17	16 3/4	19 11/16	28 1/16
17 1/2	17 1/4	20 3/16	28 9/16
18	17 3/4	20 11/16	29 1/16
18 1/2	18 1/4	21 3/16	29 9/16
19	18 3/4	21 11/16	30 1/16
19 1/2	19 1/4	22 3/16	30 9/16
20	19 3/4	22 11/16	31 1/16
20 1/2	20 1/4	23 3/16	31 9/16
21	20 3/4	23 11/16	32 1/16
21 1/2	21 1/4	24 3/16	32 9/16
22	21 3/4	24 11/16	33 1/16
22 1/2	22 1/4	25 3/16	33 9/16
23	22 3/4	25 11/16	34 1/16
23 1/2	23 1/4	26 3/16	34 9/16
24	23 3/4	26 11/16	35 1/16

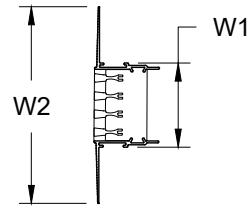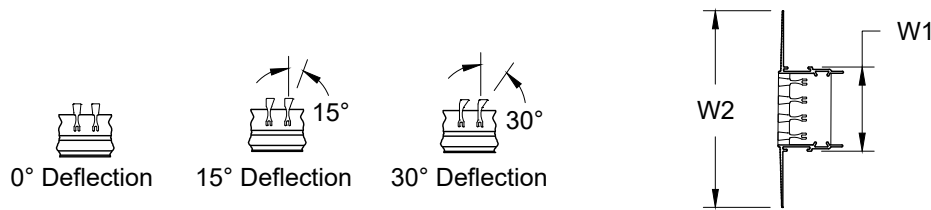

End View


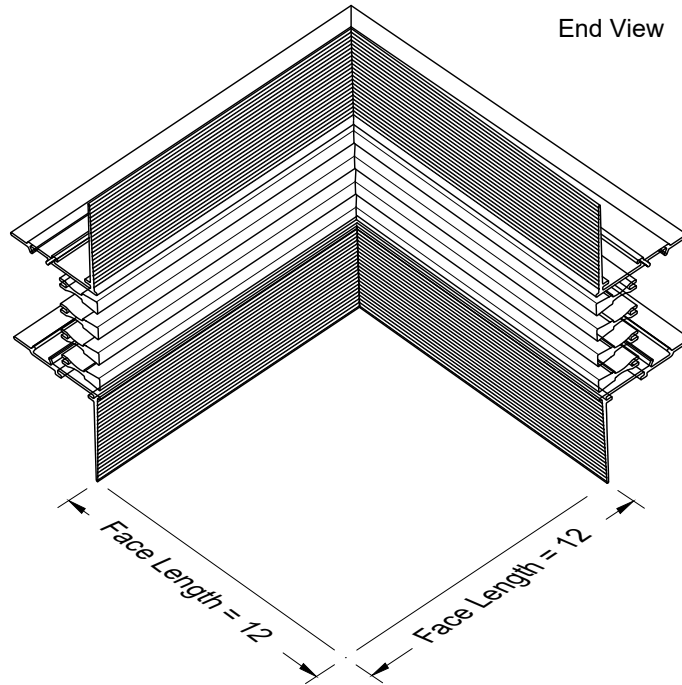


LBGMC-1-12A TS 90 Vertical Inside - Mitered Face View

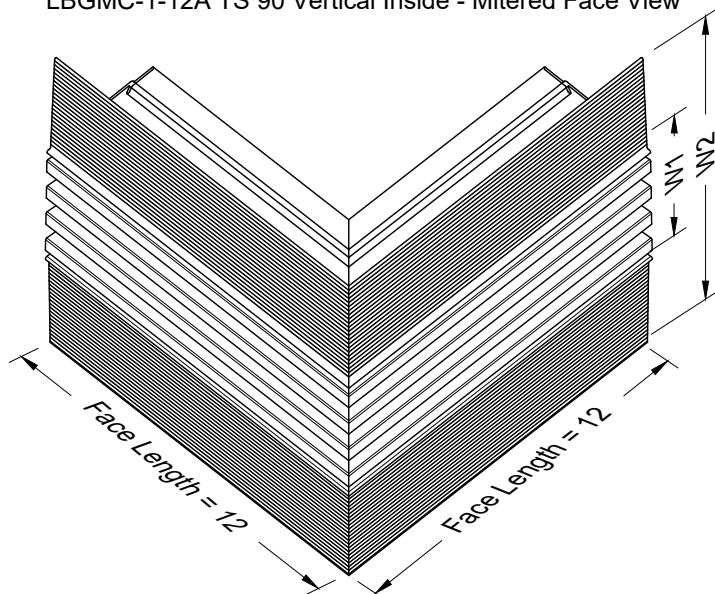



LBGMC-100-12A TS 90 Vertical Outside - Mitered Face View

90° Vertical Inside		
Listed Width	Neck W1	Face W2
1 1/2	1 1/4	4 3/16
2	1 3/4	4 11/16
2 1/2	2 1/4	5 3/16
3	2 3/4	5 11/16
3 1/2	3 1/4	6 3/16
4	3 3/4	6 11/16
4 1/2	4 1/4	7 3/16
5	4 3/4	7 11/16
5 1/2	5 1/4	8 3/16
6	5 3/4	8 11/16
6 1/2	6 1/4	9 3/16
7	6 3/4	9 11/16
7 1/2	7 1/4	10 3/16
8	7 3/4	10 11/16
8 1/2	8 1/4	11 3/16
9	8 3/4	11 11/16
9 1/2	9 1/4	12 3/16
10	9 3/4	12 11/16
10 1/2	10 1/4	13 3/16
11	10 3/4	13 11/16
11 1/2	11 1/4	14 3/16
12	11 3/4	14 11/16
12	11 3/4	14 11/16
12 1/2	12 1/4	15 3/16
13	12 3/4	15 11/16
13 1/2	13 1/4	16 3/16
14	13 3/4	16 11/16
14 1/2	14 1/4	17 3/16
15	14 3/4	17 11/16
15 1/2	15 1/4	18 3/16
16	15 3/4	18 11/16
16 1/2	16 1/4	19 3/16
17	16 3/4	19 11/16
17 1/2	17 1/4	20 3/16
18	17 3/4	20 11/16
18 1/2	18 1/4	21 3/16
19	18 3/4	21 11/16
19 1/2	19 1/4	22 3/16
20	19 3/4	22 11/16
20 1/2	20 1/4	23 3/16
21	20 3/4	23 11/16
21 1/2	21 1/4	24 3/16
22	21 3/4	24 11/16
22 1/2	22 1/4	25 3/16
23	22 3/4	25 11/16
23 1/2	23 1/4	26 3/16
24	23 3/4	26 11/16

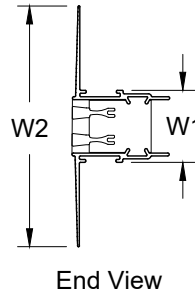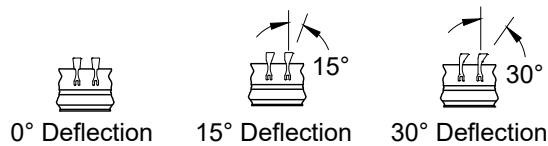



Listed Width	135 Degree		
	Neck W1	Face W2	Face L
1 1/2	1 1/4	4 3/16	12 7/16
2	1 3/4	4 11/16	12 5/8
2 1/2	2 1/4	5 3/16	12 7/8
3	2 3/4	5 11/16	13 1/16
3 1/2	3 1/4	6 3/16	13 1/4
4	3 3/4	6 11/16	13 1/2
4 1/2	4 1/4	7 3/16	13 11/16
5	4 3/4	7 11/16	13 7/8
5 1/2	5 1/4	8 3/16	14 1/8
6	5 3/4	8 11/16	14 5/16
6 1/2	6 1/4	9 3/16	14 1/2
7	6 3/4	9 11/16	14 11/16
7 1/2	7 1/4	10 3/16	14 15/16
8	7 3/4	10 11/16	15 1/8
8 1/2	8 1/4	11 3/16	15 5/16
9	8 3/4	11 11/16	15 9/16
9 1/2	9 1/4	12 3/16	15 3/4
10	9 3/4	12 11/16	15 15/16
10 1/2	10 1/4	13 3/16	16 3/16
11	10 3/4	13 11/16	16 3/8
11 1/2	11 1/4	14 3/16	16 9/16
12	11 3/4	14 11/16	16 13/16
12 1/2	12 1/4	15 3/16	16 15/16
13	12 3/4	15 11/16	17 1/8
13 1/2	13 1/4	16 3/16	17 5/16
14	13 3/4	16 11/16	17 1/2
14 1/2	14 1/4	17 3/16	17 11/16
15	14 3/4	17 11/16	17 7/8
15 1/2	15 1/4	18 3/16	18 1/16
16	15 3/4	18 11/16	18 1/4
16 1/2	16 1/4	19 3/16	18 7/16
17	16 3/4	19 11/16	18 5/8
17 1/2	17 1/4	20 3/16	18 13/16
18	17 3/4	20 11/16	19
18 1/2	18 1/4	21 3/16	19 3/16
19	18 3/4	21 11/16	19 3/8
19 1/2	19 1/4	22 3/16	19 9/16
20	19 3/4	22 11/16	19 3/4
20 1/2	20 1/4	23 3/16	19 15/16
21	20 3/4	23 11/16	20 1/8
21 1/2	21 1/4	24 3/16	20 5/16
22	21 3/4	24 11/16	20 1/2
22 1/2	22 1/4	25 3/16	20 11/16
23	22 3/4	25 11/16	20 7/8
23 1/2	23 1/4	26 3/16	21 1/16
24	23 3/4	26 11/16	21 1/4

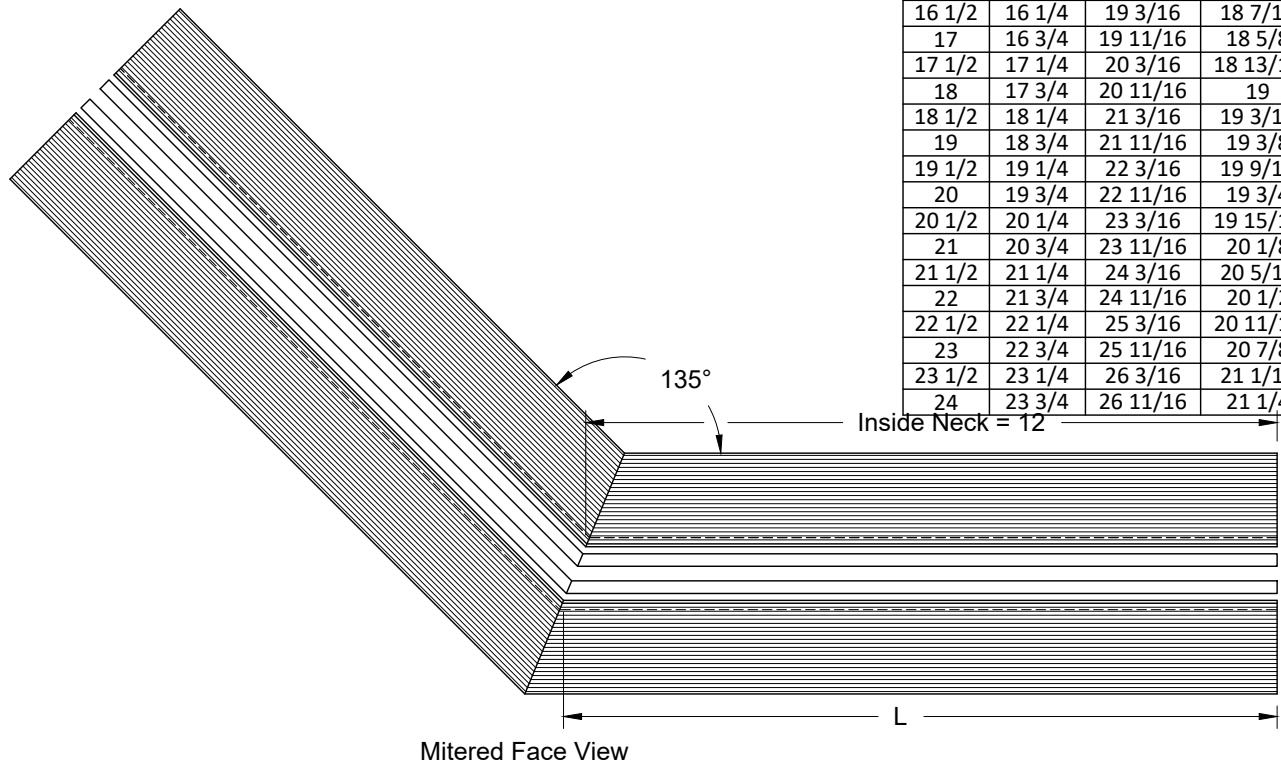

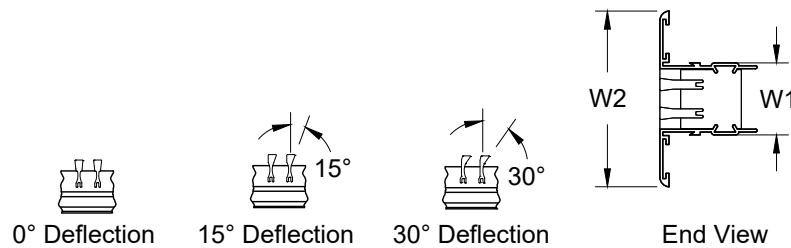


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	13
2	1 3/4	3 9/16	13 1/2
2 1/2	2 1/4	4 1/16	14
3	2 3/4	4 9/16	14 1/2
3 1/2	3 1/4	5 1/16	15
4	3 3/4	5 9/16	15 1/2
4 1/2	4 1/4	6 1/16	16
5	4 3/4	6 9/16	16 1/2
5 1/2	5 1/4	7 1/16	17
6	5 3/4	7 9/16	17 1/2
6 1/2	6 1/4	8 1/16	18
7	6 3/4	8 9/16	18 1/2
7 1/2	7 1/4	9 1/16	19
8	7 3/4	9 9/16	19 1/2
8 1/2	8 1/4	10 1/16	20
9	8 3/4	10 9/16	20 1/2
9 1/2	9 1/4	11 1/16	21
10	9 3/4	11 9/16	21 1/2
10 1/2	10 1/4	12 1/16	22
11	10 3/4	12 9/16	22 1/2
11 1/2	11 1/4	13 1/16	23
12	11 3/4	13 9/16	23 1/2

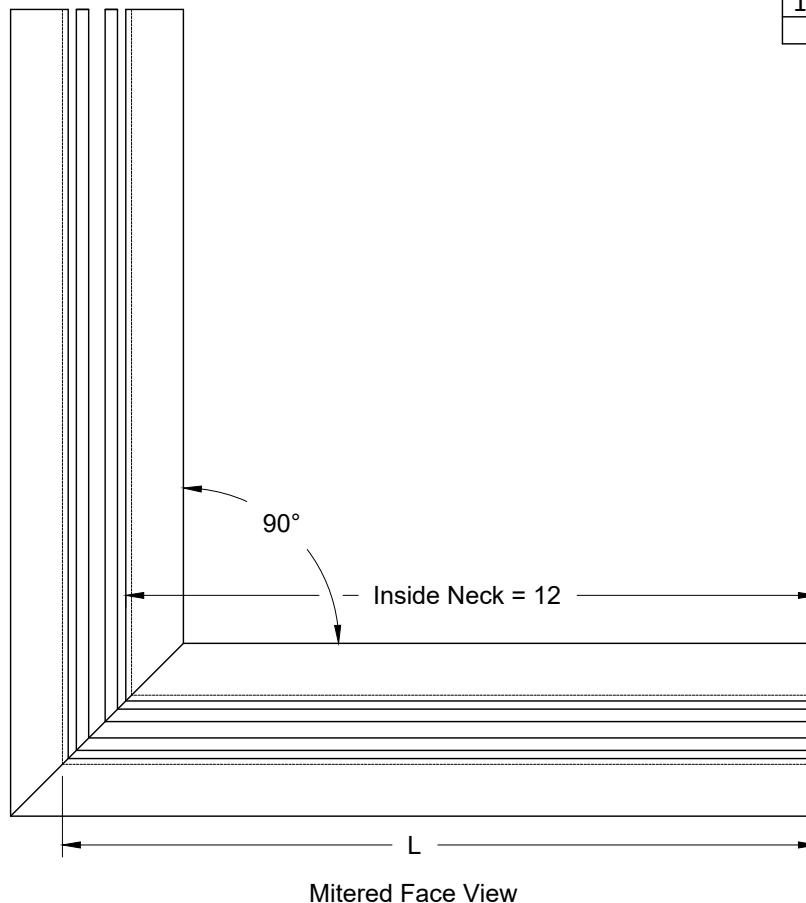


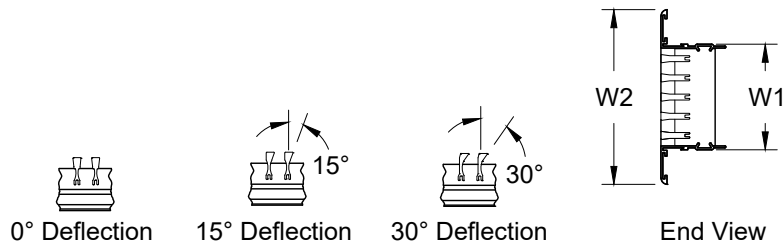


90° Vertical Inside		
Listed Width	Neck	Face
	W1	W2
1 1/2	1 1/4	3 1/16
2	1 3/4	3 9/16
2 1/2	2 1/4	4 1/16
3	2 3/4	4 9/16
3 1/2	3 1/4	5 1/16
4	3 3/4	5 9/16
4 1/2	4 1/4	6 1/16
5	4 3/4	6 9/16
5 1/2	5 1/4	7 1/16
6	5 3/4	7 9/16
6 1/2	6 1/4	8 1/16
7	6 3/4	8 9/16
7 1/2	7 1/4	9 1/16
8	7 3/4	9 9/16
8 1/2	8 1/4	10 1/16
9	8 3/4	10 9/16
9 1/2	9 1/4	11 1/16
10	9 3/4	11 9/16
10 1/2	10 1/4	12 1/16
11	10 3/4	12 9/16
11 1/2	11 1/4	13 1/16
12	11 3/4	13 9/16

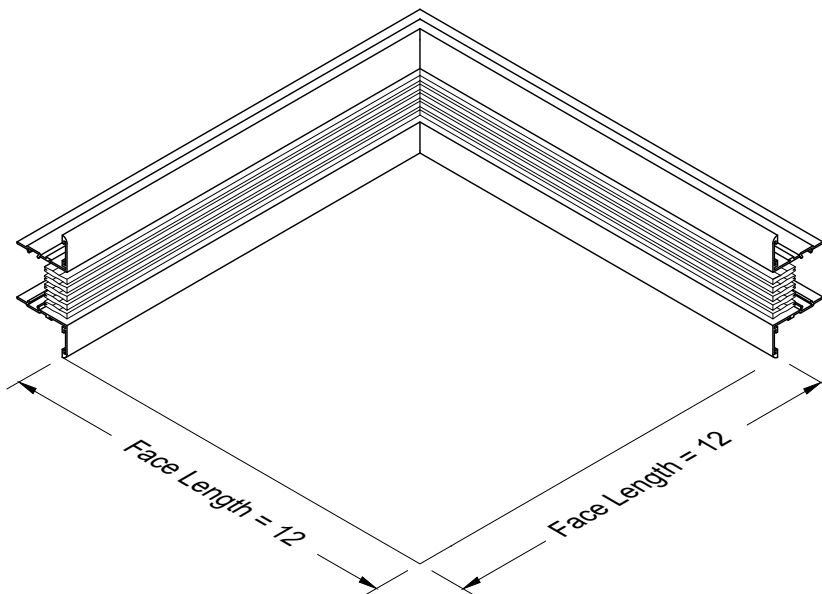


LBGMC-1-12B 90 Vertical Inside - Mitered Face View

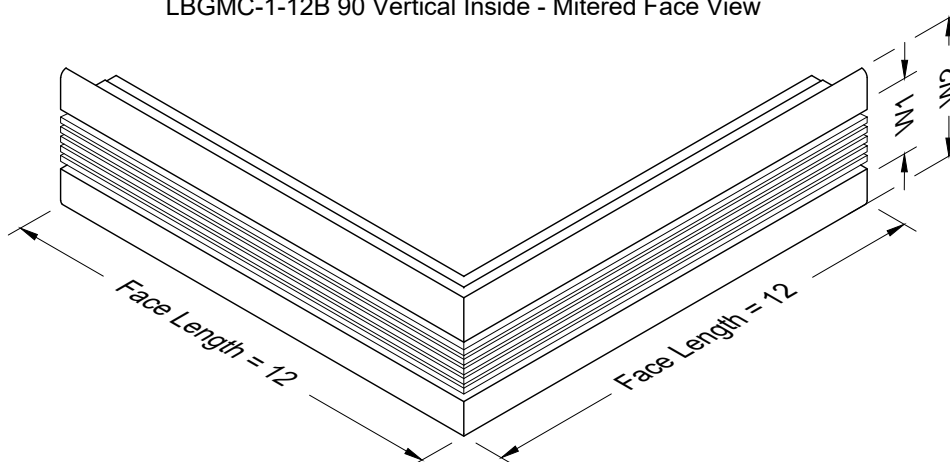



LBGMC-1-12B 90 Vertical Outside - Mitered Face View

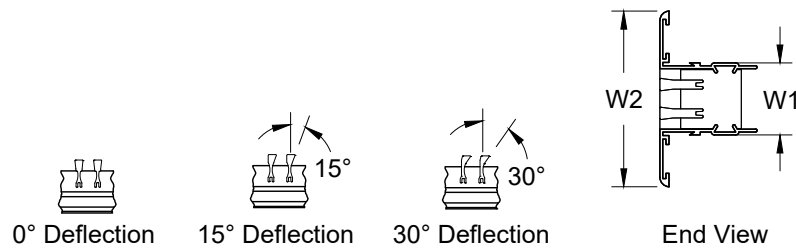


135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	12 7/16
2	1 3/4	3 9/16	12 5/8
2 1/2	2 1/4	4 1/16	12 13/16
3	2 3/4	4 9/16	13 1/16
3 1/2	3 1/4	5 1/16	13 1/4
4	3 3/4	5 9/16	13 7/16
4 1/2	4 1/4	6 1/16	13 11/16
5	4 3/4	6 9/16	13 7/8
5 1/2	5 1/4	7 1/16	14 1/16
6	5 3/4	7 9/16	14 1/4
6 1/2	6 1/4	8 1/16	14 1/2
7	6 3/4	8 9/16	14 11/16
7 1/2	7 1/4	9 1/16	14 7/8
8	7 3/4	9 9/16	15 1/8
8 1/2	8 1/4	10 1/16	15 5/16
9	8 3/4	10 9/16	15 1/2
9 1/2	9 1/4	11 1/16	15 3/4
10	9 3/4	11 9/16	15 15/16
10 1/2	10 1/4	12 1/16	16 1/8
11	10 3/4	12 9/16	16 3/8
11 1/2	11 1/4	13 1/16	16 9/16
12	11 3/4	13 9/16	16 3/4

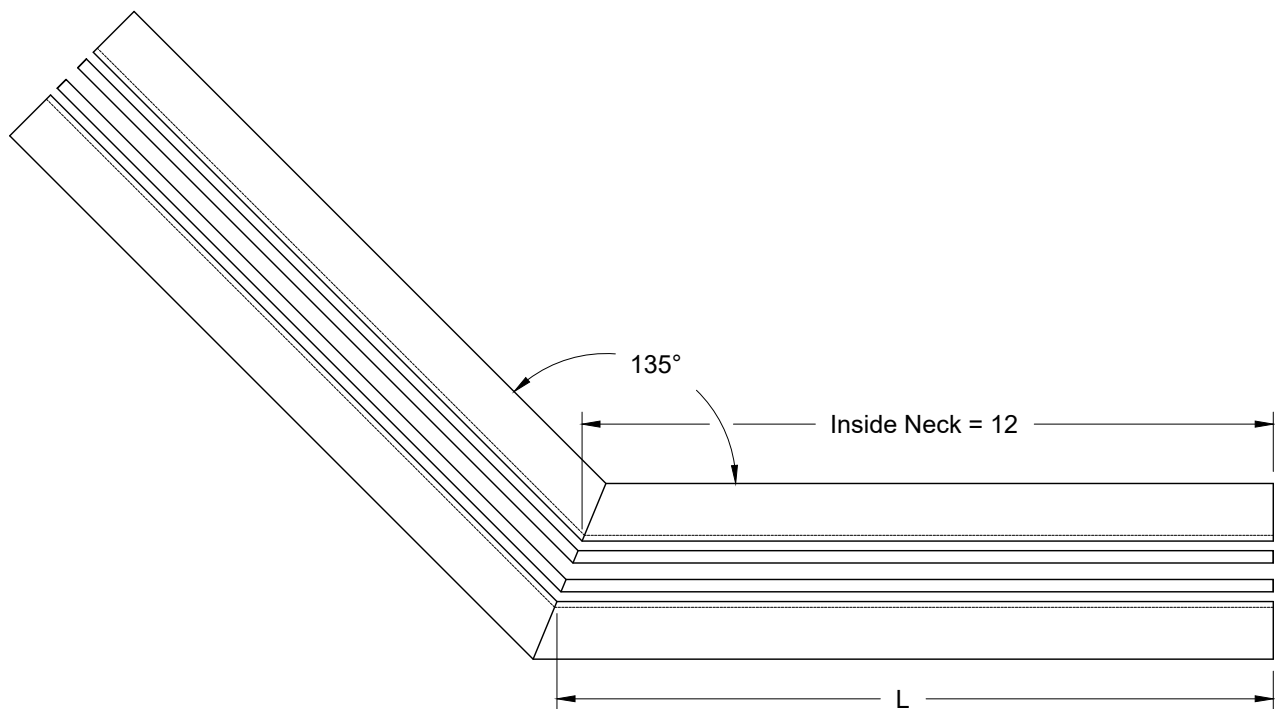




Mitered Face View

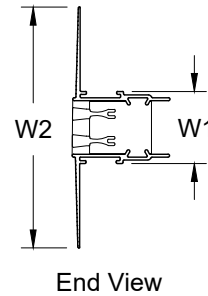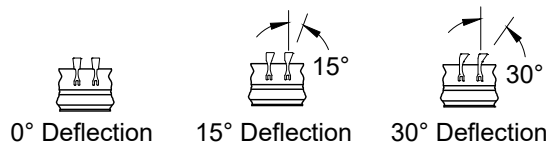


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	4 3/16	13 1/16
2	1 3/4	4 11/16	13 9/16
2 1/2	2 1/4	5 3/16	14 1/16
3	2 3/4	5 11/16	14 9/16
3 1/2	3 1/4	6 3/16	15 1/16
4	3 3/4	6 11/16	15 9/16
4 1/2	4 1/4	7 3/16	16 1/16
5	4 3/4	7 11/16	16 9/16
5 1/2	5 1/4	8 3/16	17 1/16
6	5 3/4	8 11/16	17 9/16
6 1/2	6 1/4	9 3/16	18 1/16
7	6 3/4	9 11/16	18 9/16
7 1/2	7 1/4	10 3/16	19 1/16
8	7 3/4	10 11/16	19 9/16
8 1/2	8 1/4	11 3/16	20 1/16
9	8 3/4	11 11/16	20 9/16
9 1/2	9 1/4	12 3/16	21 1/16
10	9 3/4	12 11/16	21 9/16
10 1/2	10 1/4	13 3/16	22 1/16
11	10 3/4	13 11/16	22 9/16
11 1/2	11 1/4	14 3/16	23 1/16
12	11 3/4	14 11/16	23 9/16

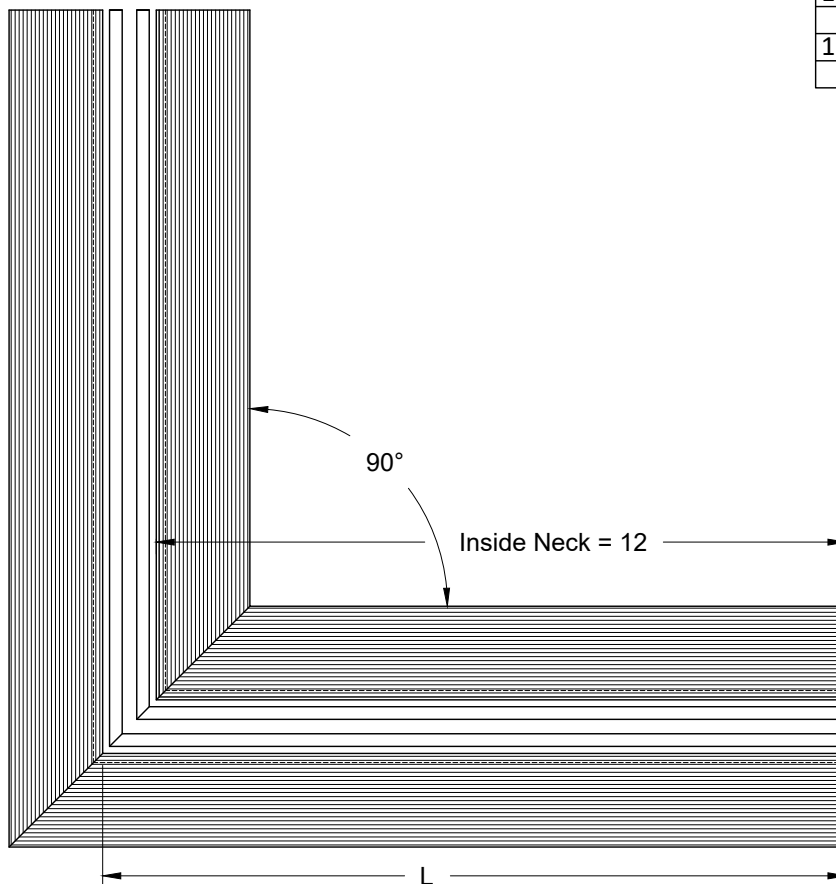

Mitered Face View

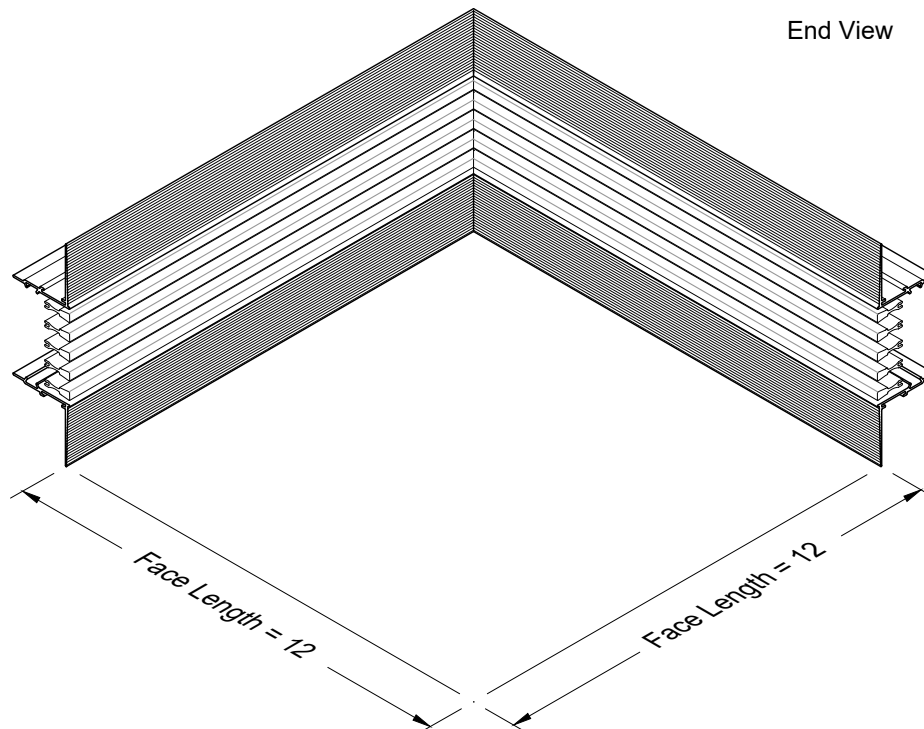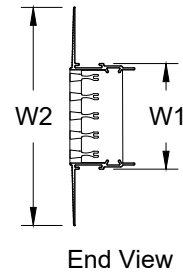
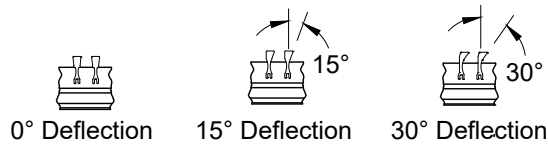


LBGMC-1-12B TS 90 Vertical Inside - Mitered Face View

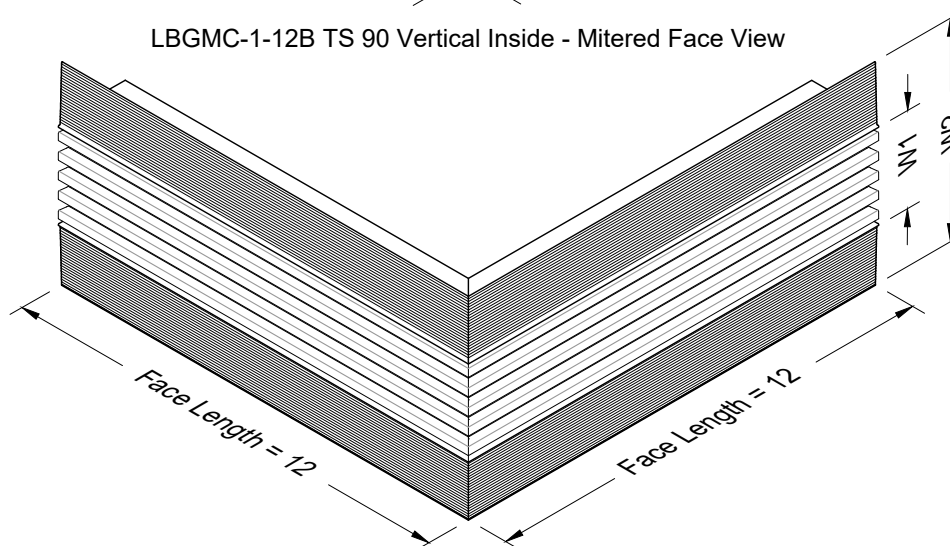



LBGMC-1-12B TS 90 Vertical Outside - Mitered Face View

90° Vertical Inside		
Listed Width	Neck	Face
	W1	W2
1 1/2	1 1/4	4 3/16
2	1 3/4	4 11/16
2 1/2	2 1/4	5 3/16
3	2 3/4	5 11/16
3 1/2	3 1/4	6 3/16
4	3 3/4	6 11/16
4 1/2	4 1/4	7 3/16
5	4 3/4	7 11/16
5 1/2	5 1/4	8 3/16
6	5 3/4	8 11/16
6 1/2	6 1/4	9 3/16
7	6 3/4	9 11/16
7 1/2	7 1/4	10 3/16
8	7 3/4	10 11/16
8 1/2	8 1/4	11 3/16
9	8 3/4	11 11/16
9 1/2	9 1/4	12 3/16
10	9 3/4	12 11/16
10 1/2	10 1/4	13 3/16
11	10 3/4	13 11/16
11 1/2	11 1/4	14 3/16
12	11 3/4	14 11/16

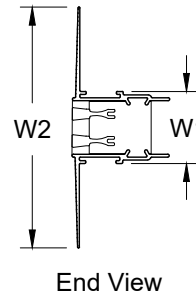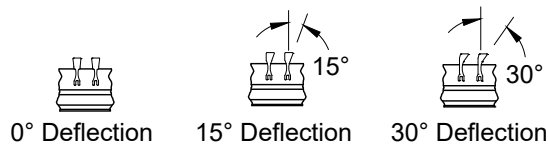


135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	4 3/16	12 7/16
2	1 3/4	4 11/16	12 5/8
2 1/2	2 1/4	5 3/16	12 7/8
3	2 3/4	5 11/16	13 1/16
3 1/2	3 1/4	6 3/16	13 1/4
4	3 3/4	6 11/16	13 1/2
4 1/2	4 1/4	7 3/16	13 11/16
5	4 3/4	7 11/16	13 7/8
5 1/2	5 1/4	8 3/16	14 1/8
6	5 3/4	8 11/16	14 5/16
6 1/2	6 1/4	9 3/16	14 1/2
7	6 3/4	9 11/16	14 11/16
7 1/2	7 1/4	10 3/16	14 15/16
8	7 3/4	10 11/16	15 1/8
8 1/2	8 1/4	11 3/16	15 5/16
9	8 3/4	11 11/16	15 9/16
9 1/2	9 1/4	12 3/16	15 3/4
10	9 3/4	12 11/16	15 15/16
10 1/2	10 1/4	13 3/16	16 3/16
11	10 3/4	13 11/16	16 3/8
11 1/2	11 1/4	14 3/16	16 9/16
12	11 3/4	14 11/16	16 13/16


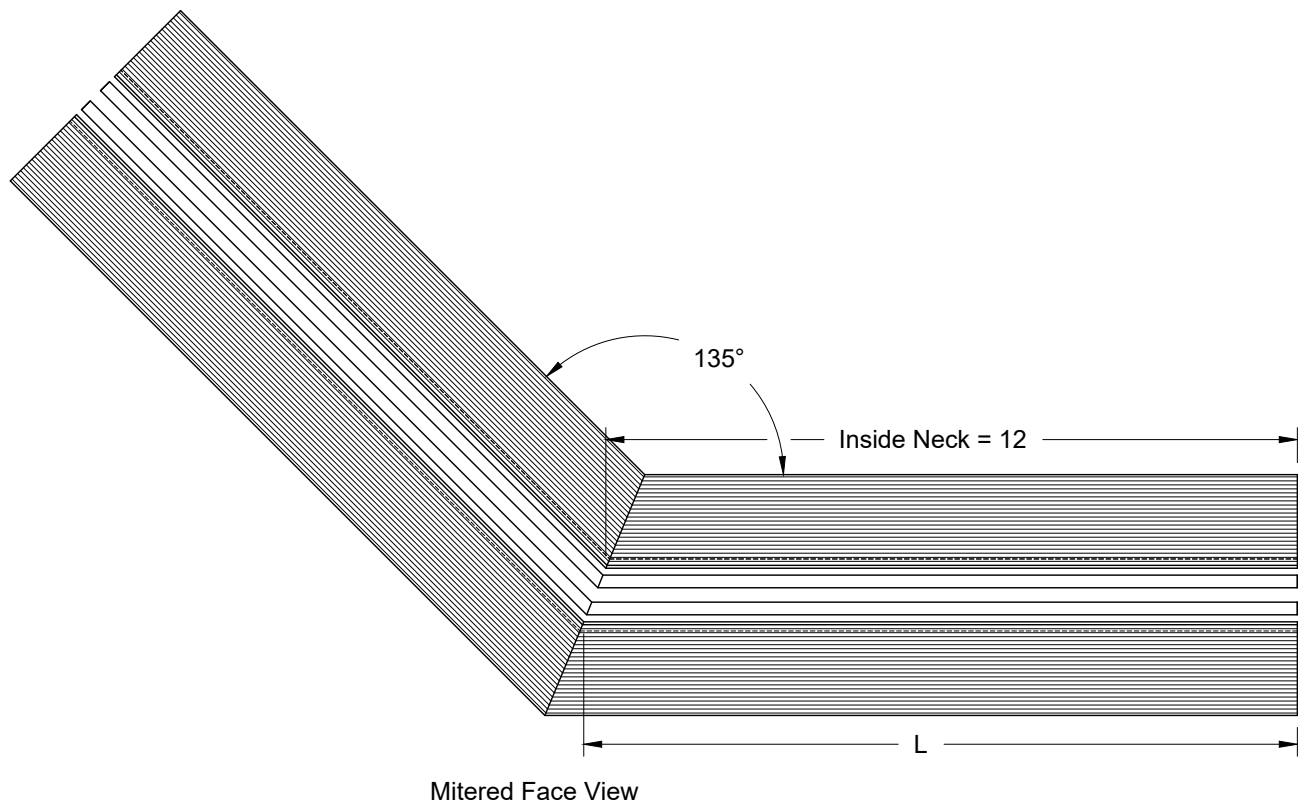


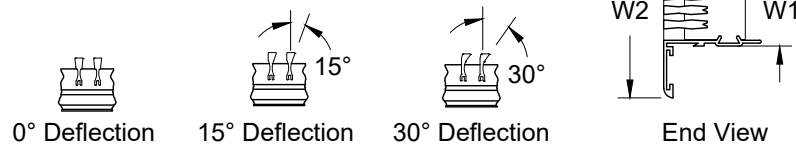


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	13
2	1 3/4	3 9/16	13 1/2
2 1/2	2 1/4	4 1/16	14
3	2 3/4	4 9/16	14 1/2
3 1/2	3 1/4	5 1/16	15
4	3 3/4	5 9/16	15 1/2
4 1/2	4 1/4	6 1/16	16
5	4 3/4	6 9/16	16 1/2
5 1/2	5 1/4	7 1/16	17
6	5 3/4	7 9/16	17 1/2
6 1/2	6 1/4	8 1/16	18
7	6 3/4	8 9/16	18 1/2
7 1/2	7 1/4	9 1/16	19
8	7 3/4	9 9/16	19 1/2
8 1/2	8 1/4	10 1/16	20
9	8 3/4	10 9/16	20 1/2
9 1/2	9 1/4	11 1/16	21
10	9 3/4	11 9/16	21 1/2
10 1/2	10 1/4	12 1/16	22
11	10 3/4	12 9/16	22 1/2
11 1/2	11 1/4	13 1/16	23
12	11 3/4	13 9/16	23 1/2

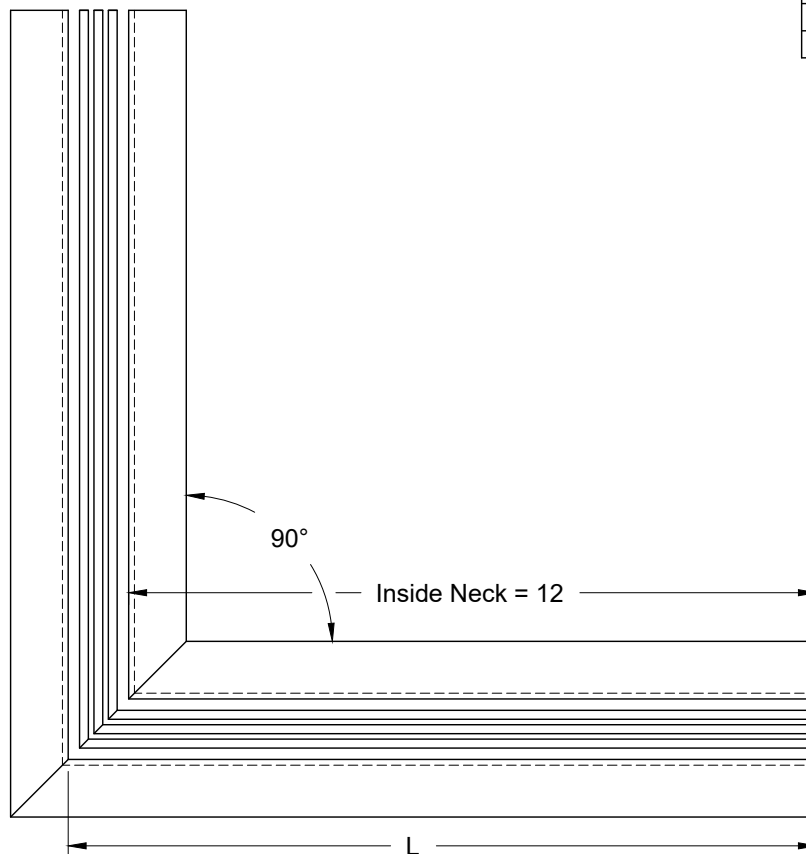


Mitered Face View

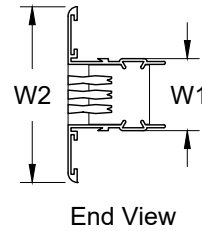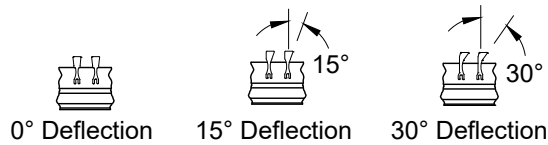


90° Vertical Inside		
Listed Width	Neck	Face
	W1	W2
1 1/2	1 1/4	3 1/16
2	1 3/4	3 9/16
2 1/2	2 1/4	4 1/16
3	2 3/4	4 9/16
3 1/2	3 1/4	5 1/16
4	3 3/4	5 9/16
4 1/2	4 1/4	6 1/16
5	4 3/4	6 9/16
5 1/2	5 1/4	7 1/16
6	5 3/4	7 9/16
6 1/2	6 1/4	8 1/16
7	6 3/4	8 9/16
7 1/2	7 1/4	9 1/16
8	7 3/4	9 9/16
8 1/2	8 1/4	10 1/16
9	8 3/4	10 9/16
9 1/2	9 1/4	11 1/16
10	9 3/4	11 9/16
10 1/2	10 1/4	12 1/16
11	10 3/4	12 9/16
11 1/2	11 1/4	13 1/16
12	11 3/4	13 9/16

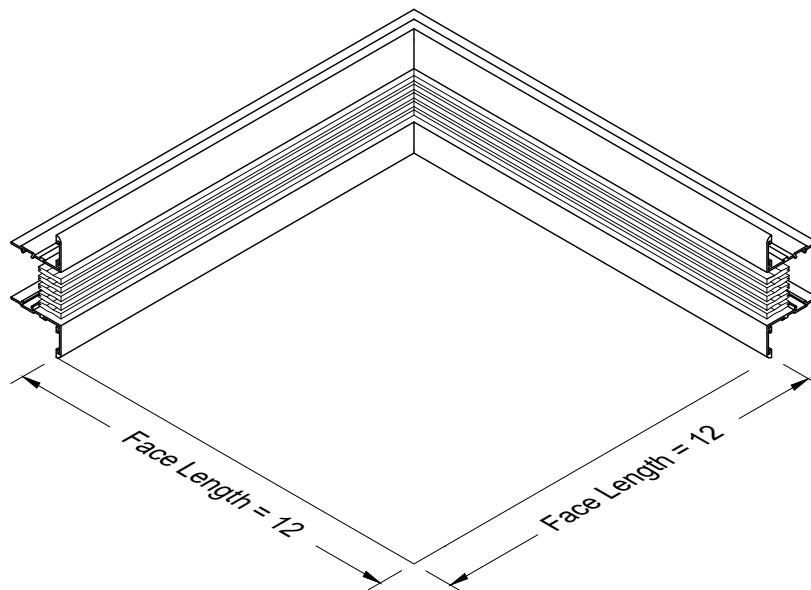


LBGMC-1-14B 90 Vertical Inside - Mitered Face View


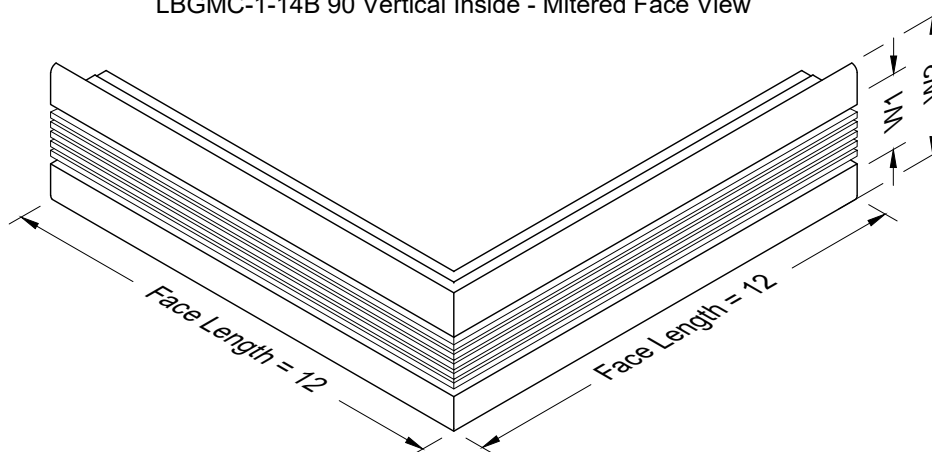


LBGMC-1-14B 90 Vertical Outside - Mitered Face View

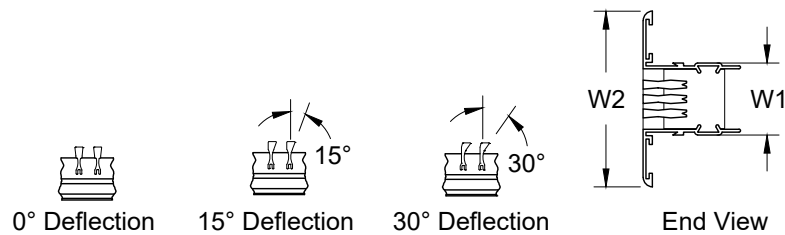




135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	12 7/16
2	1 3/4	3 9/16	12 5/8
2 1/2	2 1/4	4 1/16	12 13/16
3	2 3/4	4 9/16	13 1/16
3 1/2	3 1/4	5 1/16	13 1/4
4	3 3/4	5 9/16	13 7/16
4 1/2	4 1/4	6 1/16	13 11/16
5	4 3/4	6 9/16	13 7/8
5 1/2	5 1/4	7 1/16	14 1/16
6	5 3/4	7 9/16	14 1/4
6 1/2	6 1/4	8 1/16	14 1/2
7	6 3/4	8 9/16	14 11/16
7 1/2	7 1/4	9 1/16	14 7/8
8	7 3/4	9 9/16	15 1/8
8 1/2	8 1/4	10 1/16	15 5/16
9	8 3/4	10 9/16	15 1/2
9 1/2	9 1/4	11 1/16	15 3/4
10	9 3/4	11 9/16	15 15/16
10 1/2	10 1/4	12 1/16	16 1/8
11	10 3/4	12 9/16	16 3/8
11 1/2	11 1/4	13 1/16	16 9/16
12	11 3/4	13 9/16	16 3/4

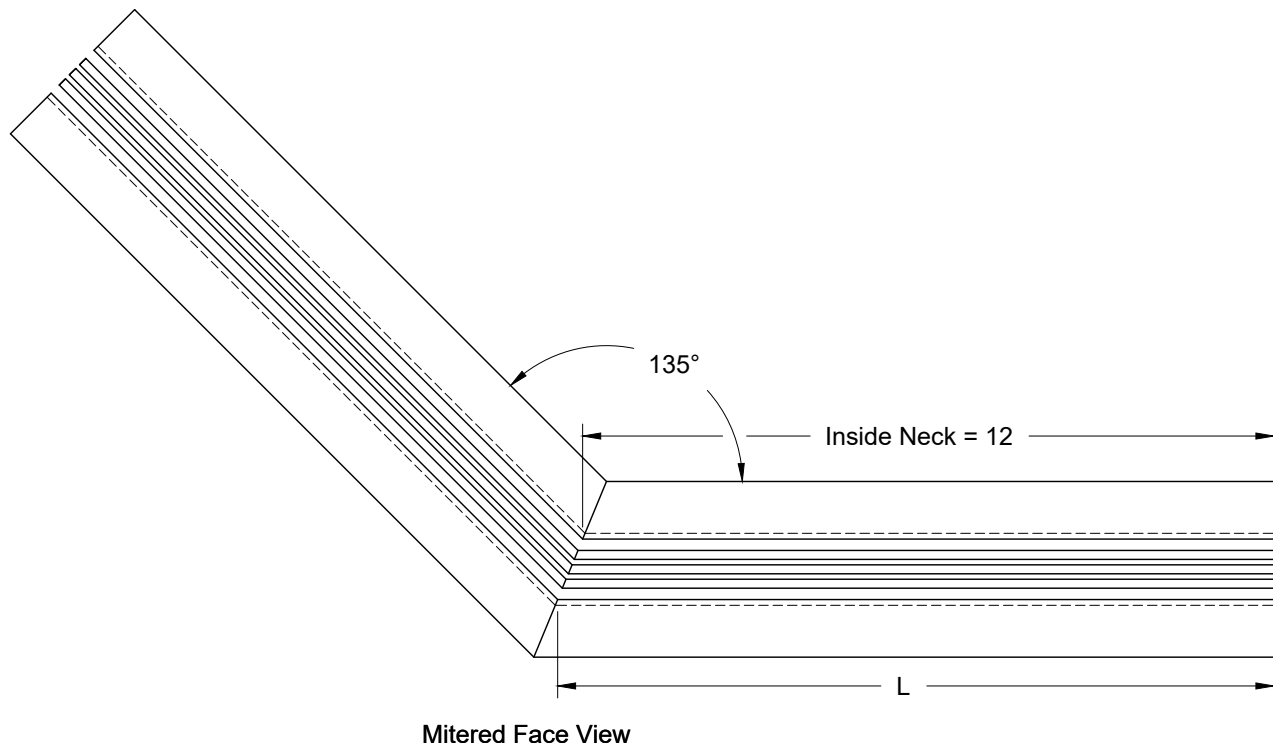

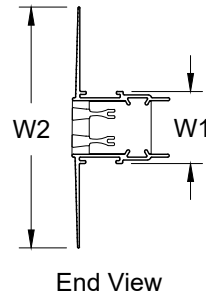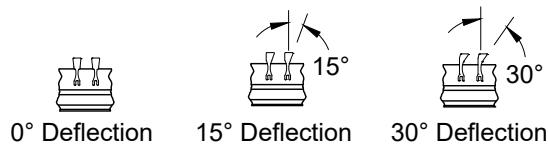


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	4 3/16	13 1/16
2	1 3/4	4 11/16	13 9/16
2 1/2	2 1/4	5 3/16	14 1/16
3	2 3/4	5 11/16	14 9/16
3 1/2	3 1/4	6 3/16	15 1/16
4	3 3/4	6 11/16	15 9/16
4 1/2	4 1/4	7 3/16	16 1/16
5	4 3/4	7 11/16	16 9/16
5 1/2	5 1/4	8 3/16	17 1/16
6	5 3/4	8 11/16	17 9/16
6 1/2	6 1/4	9 3/16	18 1/16
7	6 3/4	9 11/16	18 9/16
7 1/2	7 1/4	10 3/16	19 1/16
8	7 3/4	10 11/16	19 9/16
8 1/2	8 1/4	11 3/16	20 1/16
9	8 3/4	11 11/16	20 9/16
9 1/2	9 1/4	12 3/16	21 1/16
10	9 3/4	12 11/16	21 9/16
10 1/2	10 1/4	13 3/16	22 1/16
11	10 3/4	13 11/16	22 9/16
11 1/2	11 1/4	14 3/16	23 1/16
12	11 3/4	14 11/16	23 9/16

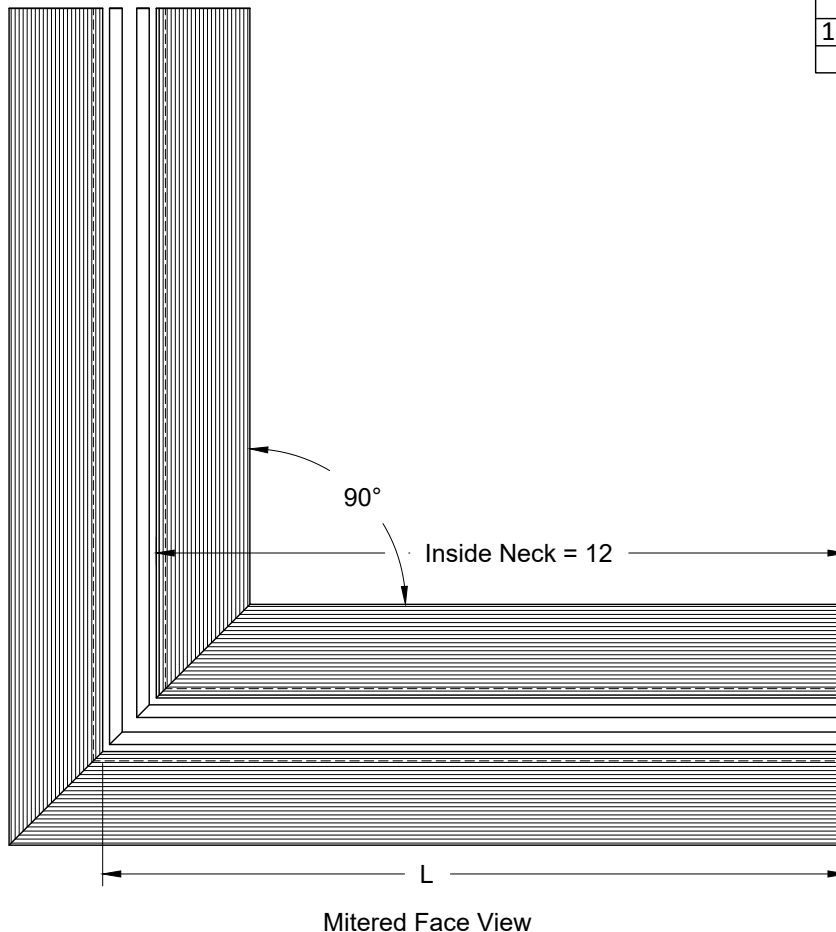


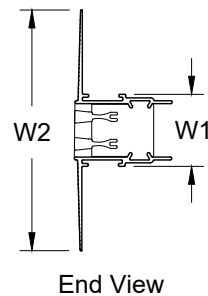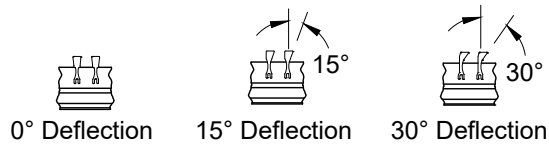


90° Vertical Inside		
Listed Width	Neck	Face
	W1	W2
1 1/2	1 1/4	4 3/16
2	1 3/4	4 11/16
2 1/2	2 1/4	5 3/16
3	2 3/4	5 11/16
3 1/2	3 1/4	6 3/16
4	3 3/4	6 11/16
4 1/2	4 1/4	7 3/16
5	4 3/4	7 11/16
5 1/2	5 1/4	8 3/16
6	5 3/4	8 11/16
6 1/2	6 1/4	9 3/16
7	6 3/4	9 11/16
7 1/2	7 1/4	10 3/16
8	7 3/4	10 11/16
8 1/2	8 1/4	11 3/16
9	8 3/4	11 11/16
9 1/2	9 1/4	12 3/16
10	9 3/4	12 11/16
10 1/2	10 1/4	13 3/16
11	10 3/4	13 11/16
11 1/2	11 1/4	14 3/16
12	11 3/4	14 11/16

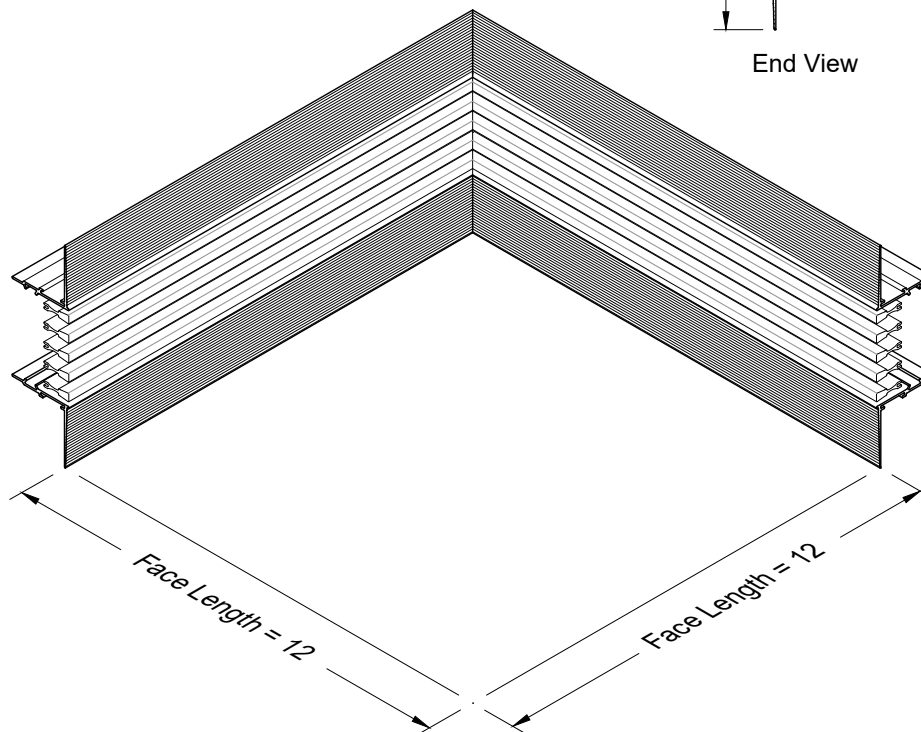


LBGMC-1-14B TS 90 Vertical Inside - Mitered Face View


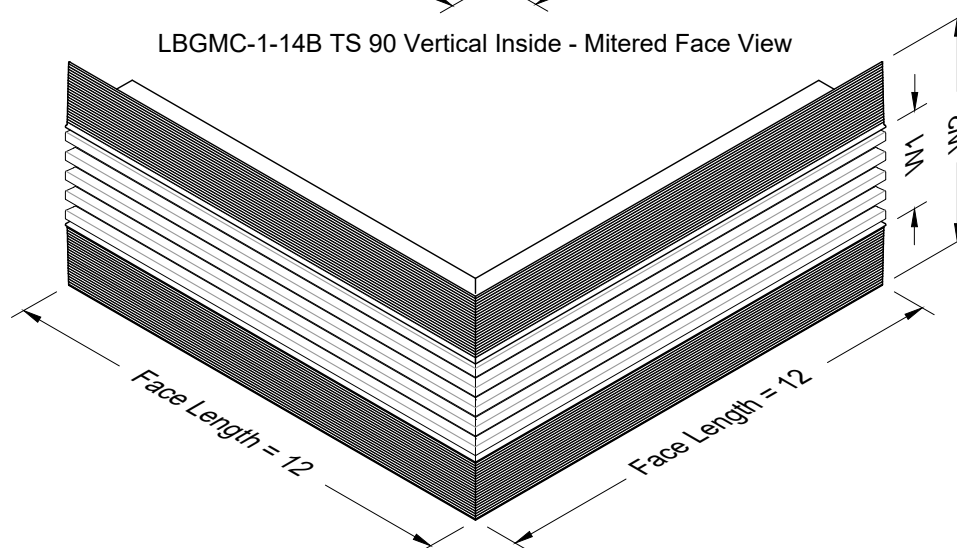


LBGMC-1-14B TS 90 Vertical Outside - Mitered Face View



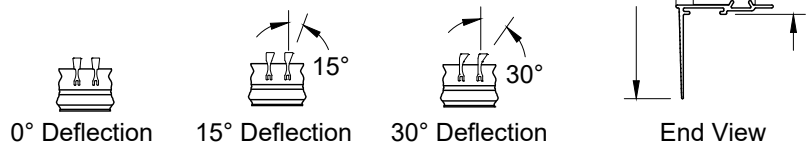


135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	4 3/16	12 7/16
2	1 3/4	4 11/16	12 5/8
2 1/2	2 1/4	5 3/16	12 7/8
3	2 3/4	5 11/16	13 1/16
3 1/2	3 1/4	6 3/16	13 1/4
4	3 3/4	6 11/16	13 1/2
4 1/2	4 1/4	7 3/16	13 11/16
5	4 3/4	7 11/16	13 7/8
5 1/2	5 1/4	8 3/16	14 1/8
6	5 3/4	8 11/16	14 5/16
6 1/2	6 1/4	9 3/16	14 1/2
7	6 3/4	9 11/16	14 11/16
7 1/2	7 1/4	10 3/16	14 15/16
8	7 3/4	10 11/16	15 1/8
8 1/2	8 1/4	11 3/16	15 5/16
9	8 3/4	11 11/16	15 9/16
9 1/2	9 1/4	12 3/16	15 3/4
10	9 3/4	12 11/16	15 15/16
10 1/2	10 1/4	13 3/16	16 3/16
11	10 3/4	13 11/16	16 3/8
11 1/2	11 1/4	14 3/16	16 9/16
12	11 3/4	14 11/16	16 13/16

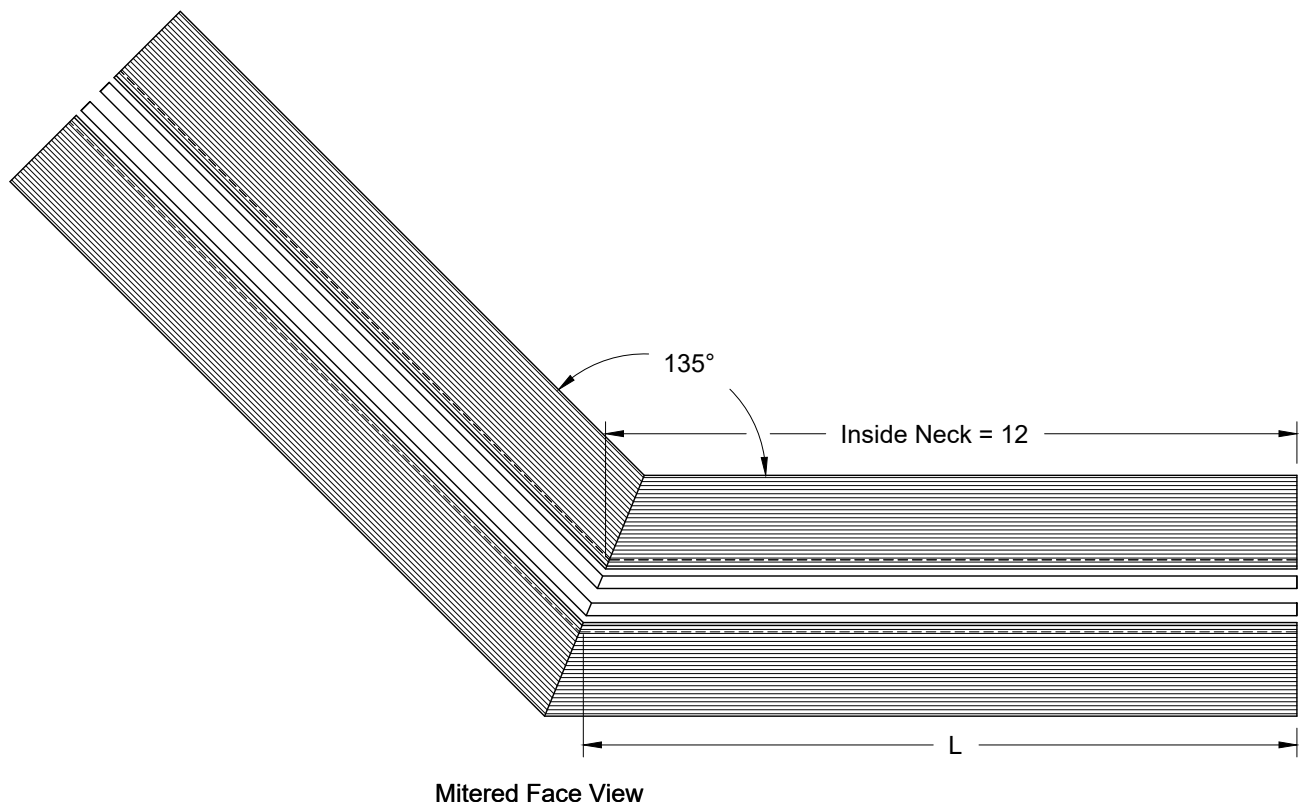


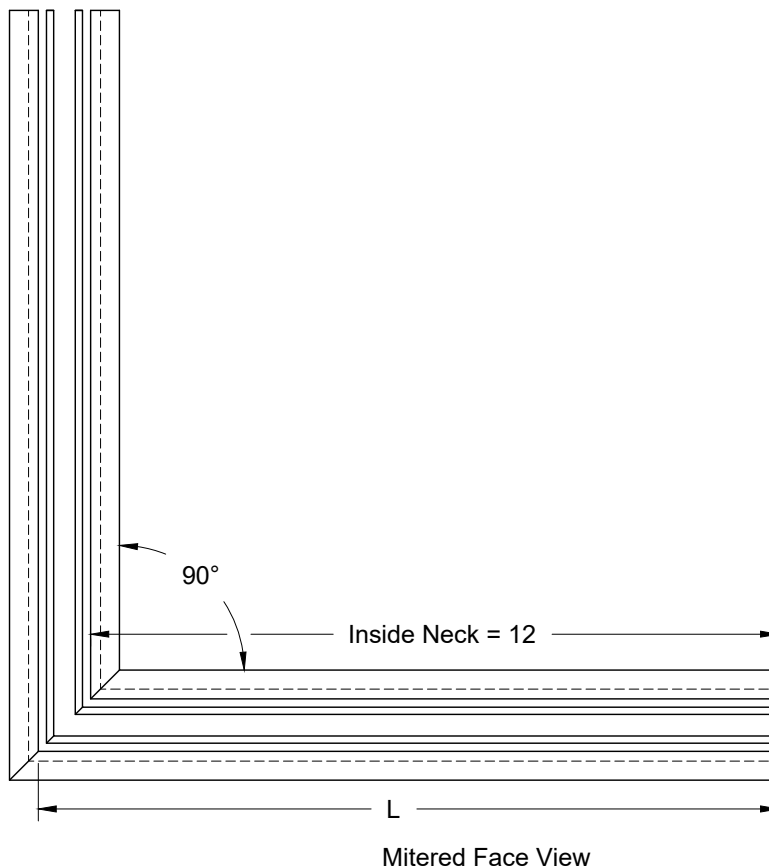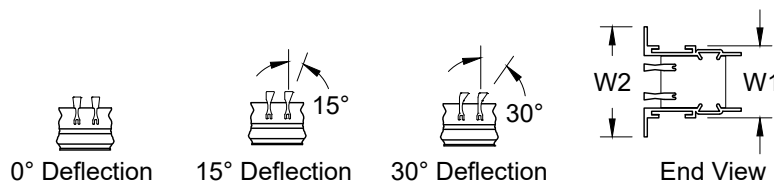

90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	1 3/4	13
2	1 3/4	2 1/4	13 1/2
2 1/2	2 1/4	2 3/4	14
3	2 3/4	3 1/4	14 1/2
3 1/2	3 1/4	3 3/4	15
4	3 3/4	4 1/4	15 1/2
4 1/2	4 1/4	4 3/4	16
5	4 3/4	5 1/4	16 1/2
5 1/2	5 1/4	5 3/4	17
6	5 3/4	6 1/4	17 1/2
6 1/2	6 1/4	6 3/4	18
7	6 3/4	7 1/4	18 1/2
7 1/2	7 1/4	7 3/4	19
8	7 3/4	8 1/4	19 1/2
8 1/2	8 1/4	8 3/4	20
9	8 3/4	9 1/4	20 1/2
9 1/2	9 1/4	9 3/4	21
10	9 3/4	10 1/4	21 1/2
10 1/2	10 1/4	10 3/4	22
11	10 3/4	11 1/4	22 1/2
11 1/2	11 1/4	11 3/4	23
12	11 3/4	12 1/4	23 1/2
12 1/2	12 1/4	12 3/4	24
13	12 3/4	13 1/4	24 1/2
13 1/2	13 1/4	13 3/4	25
14	13 3/4	14 1/4	25 1/2
14 1/2	14 1/4	14 3/4	26
15	14 3/4	15 1/4	26 1/2
15 1/2	15 1/4	15 3/4	27
16	15 3/4	16 1/4	27 1/2
16 1/2	16 1/4	16 3/4	28
17	16 3/4	17 1/4	28 1/2
17 1/2	17 1/4	17 3/4	29
18	17 3/4	18 1/4	29 1/2
18 1/2	18 1/4	18 3/4	30
19	18 3/4	19 1/4	30 1/2
19 1/2	19 1/4	19 3/4	31
20	19 3/4	20 1/4	31 1/2
20 1/2	20 1/4	20 3/4	32
21	20 3/4	21 1/4	32 1/2
21 1/2	21 1/4	21 3/4	33
22	21 3/4	22 1/4	33 1/2
22 1/2	22 1/4	22 3/4	34
23	22 3/4	23 1/4	34 1/2
23 1/2	23 1/4	23 3/4	35
24	23 3/4	24 1/4	35 1/2

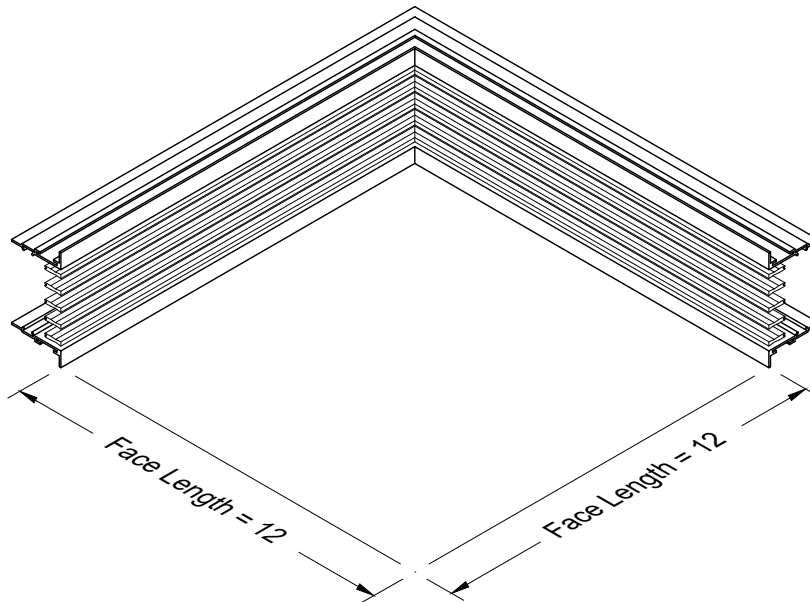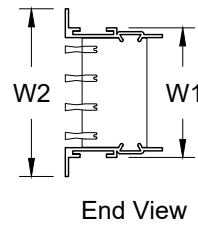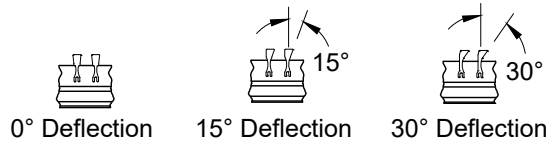


LBGMC-2-12A 90 Vertical Inside - Mitered Face View

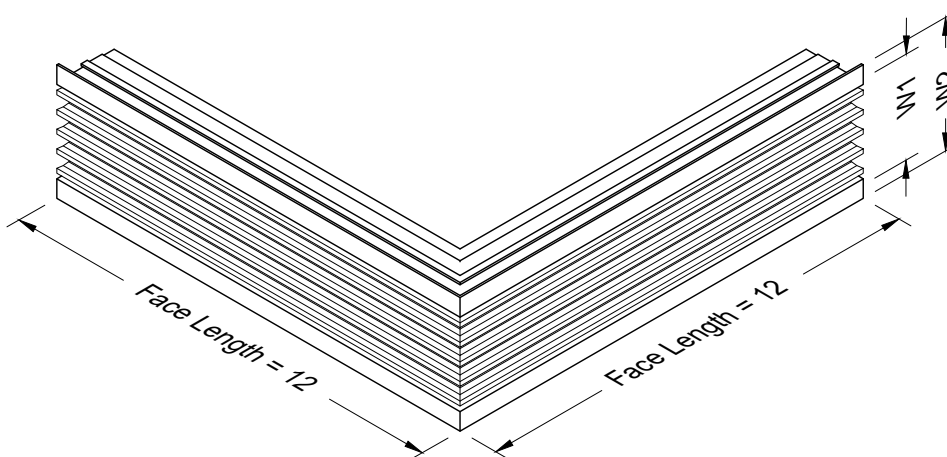


LBGMC-2-12A 90 Vertical Outside - Mitered Face View


90° Vertical Inside		
Listed Width	Neck W1	Face W2
1 1/2	1 1/4	1 1/4
2	1 3/4	1 3/4
2 1/2	2 1/4	2 1/4
3	2 3/4	2 3/4
3 1/2	3 1/4	3 1/4
4	3 3/4	3 3/4
4 1/2	4 1/4	4 1/4
5	4 3/4	4 3/4
5 1/2	5 1/4	5 1/4
6	5 3/4	5 3/4
6 1/2	6 1/4	6 1/4
7	6 3/4	6 3/4
7 1/2	7 1/4	7 1/4
8	7 3/4	7 3/4
8 1/2	8 1/4	8 1/4
9	8 3/4	8 3/4
9 1/2	9 1/4	9 1/4
10	9 3/4	9 3/4
10 1/2	10 1/4	10 1/4
11	10 3/4	10 3/4
11 1/2	11 1/4	11 1/4
12	11 3/4	11 3/4
12 1/2	12 1/4	12 1/4
13	12 3/4	12 3/4
13 1/2	13 1/4	13 1/4
14	13 3/4	13 3/4
14 1/2	14 1/4	14 1/4
15	14 3/4	14 3/4
15 1/2	15 1/4	15 1/4
16	15 3/4	15 3/4
16 1/2	16 1/4	16 1/4
17	16 3/4	16 3/4
17 1/2	17 1/4	17 1/4
18	17 3/4	17 3/4
18 1/2	18 1/4	18 1/4
19	18 3/4	18 3/4
19 1/2	19 1/4	19 1/4
20	19 3/4	19 3/4
20 1/2	20 1/4	20 1/4
21	20 3/4	20 3/4
21 1/2	21 1/4	21 1/4
22	21 3/4	21 3/4
22 1/2	22 1/4	22 1/4
23	22 3/4	22 3/4
23 1/2	23 1/4	23 1/4
24	23 3/4	23 3/4

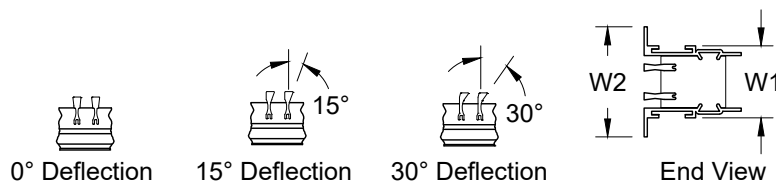


135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	1 3/4	12 7/16
2	1 3/4	2 1/4	12 5/8
2 1/2	2 1/4	2 3/4	12 13/16
3	2 3/4	3 1/4	13 1/16
3 1/2	3 1/4	3 3/4	13 1/4
4	3 3/4	4 1/4	13 7/16
4 1/2	4 1/4	4 3/4	13 11/16
5	4 3/4	5 1/4	13 7/8
5 1/2	5 1/4	5 3/4	14 1/16
6	5 3/4	6 1/4	14 1/4
6 1/2	6 1/4	6 3/4	14 1/2
7	6 3/4	7 1/4	14 11/16
7 1/2	7 1/4	7 3/4	14 7/8
8	7 3/4	8 1/4	15 1/8
8 1/2	8 1/4	8 3/4	15 5/16
9	8 3/4	9 1/4	15 1/2
9 1/2	9 1/4	9 3/4	15 3/4
10	9 3/4	10 1/4	15 15/16
10 1/2	10 1/4	10 3/4	16 1/8
11	10 3/4	11 1/4	16 3/8
11 1/2	11 1/4	11 3/4	16 9/16
12	11 3/4	12 1/4	16 3/4
12 1/2	12 1/4	12 3/4	16 15/16
13	12 3/4	13 1/4	17 1/8
13 1/2	13 1/4	13 3/4	17 5/16
14	13 3/4	14 1/4	17 1/2
14 1/2	14 1/4	14 3/4	17 11/16
15	14 3/4	15 1/4	17 7/8
15 1/2	15 1/4	15 3/4	18 1/16
16	15 3/4	16 1/4	18 1/4
16 1/2	16 1/4	16 3/4	18 7/16
17	16 3/4	17 1/4	18 5/8
17 1/2	17 1/4	17 3/4	18 13/16
18	17 3/4	18 1/4	19
18 1/2	18 1/4	18 3/4	19 3/16
19	18 3/4	19 1/4	19 3/8
19 1/2	19 1/4	19 3/4	19 9/16
20	19 3/4	20 1/4	19 3/4
20 1/2	20 1/4	20 3/4	19 15/16
21	20 3/4	21 1/4	20 1/8
21 1/2	21 1/4	21 3/4	20 5/16
22	21 3/4	22 1/4	20 1/2
22 1/2	22 1/4	22 3/4	20 11/16
23	22 3/4	23 1/4	20 7/8
23 1/2	23 1/4	23 3/4	21 1/16
24	23 3/4	24 1/4	21 1/4

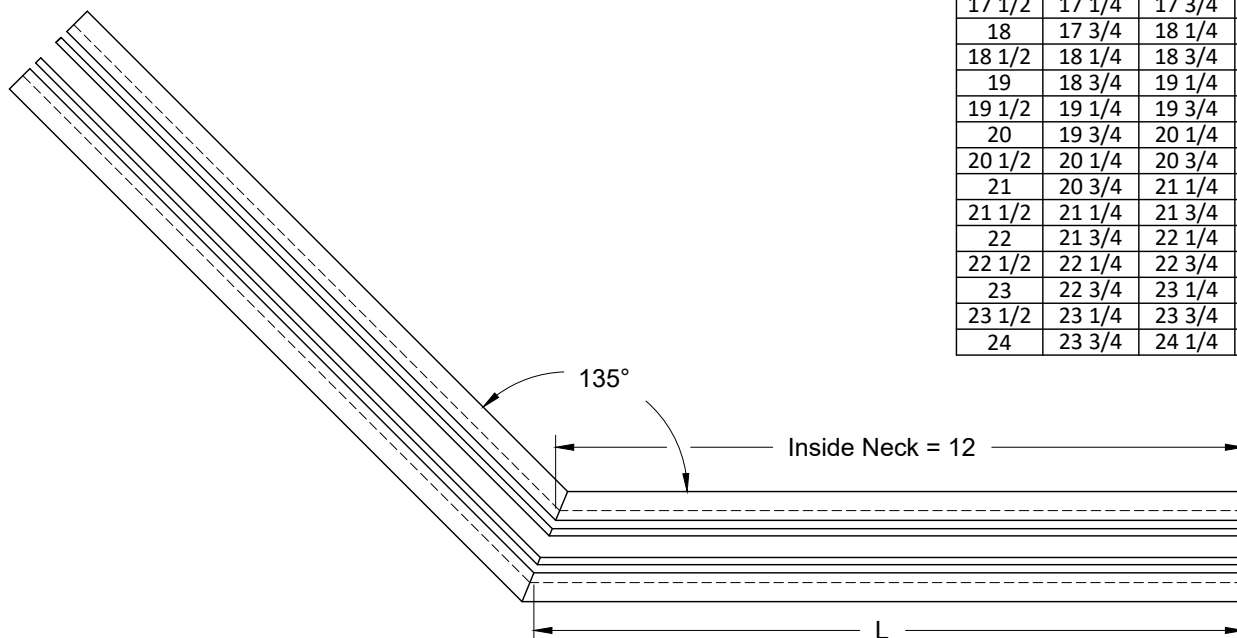


Mitered Face View

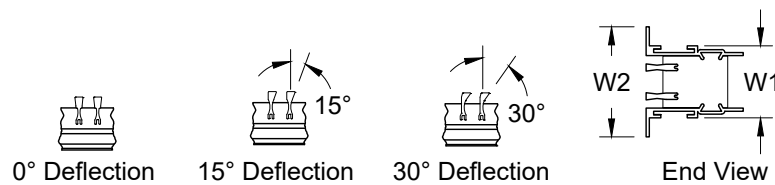


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	13
2	1 3/4	3 9/16	13 1/2
2 1/2	2 1/4	4 1/16	14
3	2 3/4	4 9/16	14 1/2
3 1/2	3 1/4	5 1/16	15
4	3 3/4	5 9/16	15 1/2
4 1/2	4 1/4	6 1/16	16
5	4 3/4	6 9/16	16 1/2
5 1/2	5 1/4	7 1/16	17
6	5 3/4	7 9/16	17 1/2
6 1/2	6 1/4	8 1/16	18
7	6 3/4	8 9/16	18 1/2
7 1/2	7 1/4	9 1/16	19
8	7 3/4	9 9/16	19 1/2
8 1/2	8 1/4	10 1/16	20
9	8 3/4	10 9/16	20 1/2
9 1/2	9 1/4	11 1/16	21
10	9 3/4	11 9/16	21 1/2
10 1/2	10 1/4	12 1/16	22
11	10 3/4	12 9/16	22 1/2
11 1/2	11 1/4	13 1/16	23
12	11 3/4	13 9/16	23 1/2

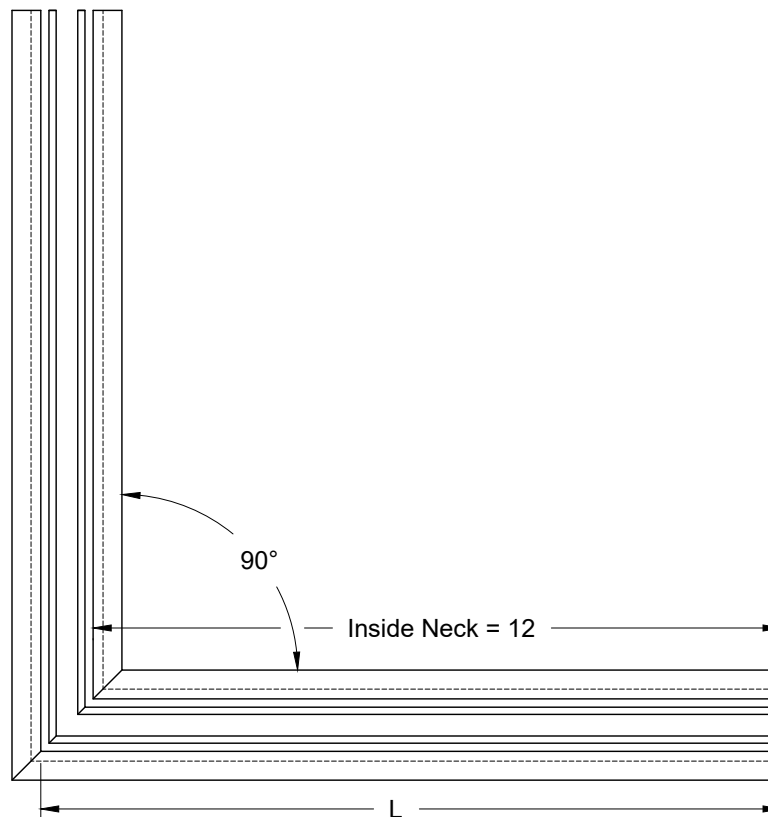


Mitered Face View

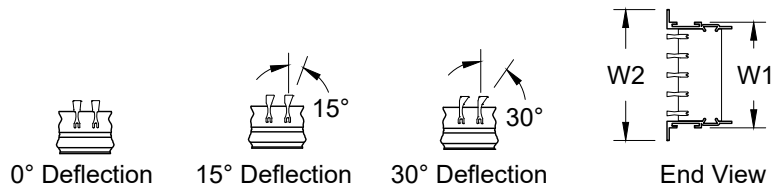


90° Vertical Inside		
Listed Width	Neck	Face
	W1	W2
1 1/2	1 1/4	3 1/16
2	1 3/4	3 9/16
2 1/2	2 1/4	4 1/16
3	2 3/4	4 9/16
3 1/2	3 1/4	5 1/16
4	3 3/4	5 9/16
4 1/2	4 1/4	6 1/16
5	4 3/4	6 9/16
5 1/2	5 1/4	7 1/16
6	5 3/4	7 9/16
6 1/2	6 1/4	8 1/16
7	6 3/4	8 9/16
7 1/2	7 1/4	9 1/16
8	7 3/4	9 9/16
8 1/2	8 1/4	10 1/16
9	8 3/4	10 9/16
9 1/2	9 1/4	11 1/16
10	9 3/4	11 9/16
10 1/2	10 1/4	12 1/16
11	10 3/4	12 9/16
11 1/2	11 1/4	13 1/16
12	11 3/4	13 9/16

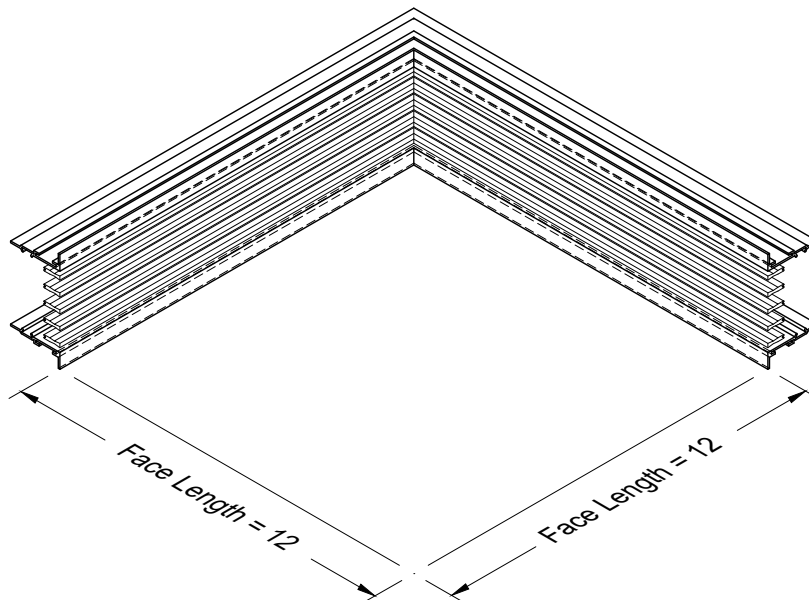


LBGMC-2-12B 90 Vertical Inside - Mitered Face View

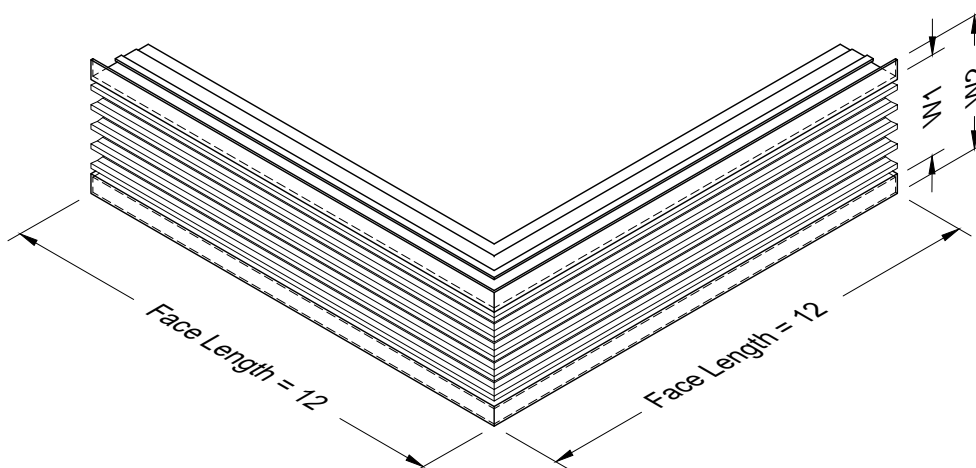


LBGMC-2-12B 90 Vertical Outside - Mitered Face View

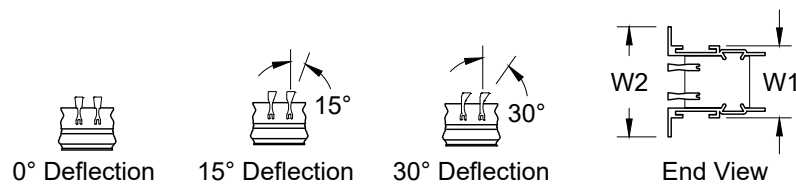


LBGMC 135			
135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	12 7/16
2	1 3/4	3 9/16	12 5/8
2 1/2	2 1/4	4 1/16	12 13/16
3	2 3/4	4 9/16	13 1/16
3 1/2	3 1/4	5 1/16	13 1/4
4	3 3/4	5 9/16	13 7/16
4 1/2	4 1/4	6 1/16	13 11/16
5	4 3/4	6 9/16	13 7/8
5 1/2	5 1/4	7 1/16	14 1/16
6	5 3/4	7 9/16	14 1/4
6 1/2	6 1/4	8 1/16	14 1/2
7	6 3/4	8 9/16	14 11/16
7 1/2	7 1/4	9 1/16	14 7/8
8	7 3/4	9 9/16	15 1/8
8 1/2	8 1/4	10 1/16	15 5/16
9	8 3/4	10 9/16	15 1/2
9 1/2	9 1/4	11 1/16	15 3/4
10	9 3/4	11 9/16	15 15/16
10 1/2	10 1/4	12 1/16	16 1/8
11	10 3/4	12 9/16	16 3/8
11 1/2	11 1/4	13 1/16	16 9/16
12	11 3/4	13 9/16	16 3/4

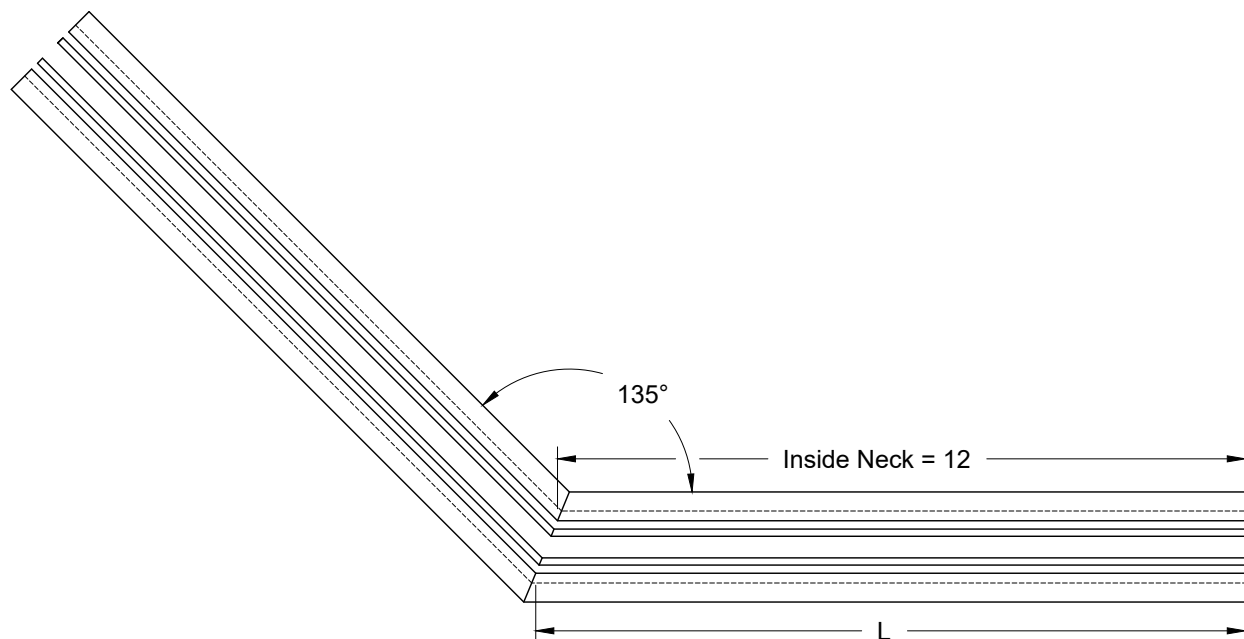


Mitered Face View

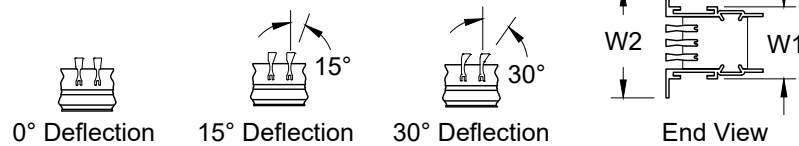


90 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	13
2	1 3/4	3 9/16	13 1/2
2 1/2	2 1/4	4 1/16	14
3	2 3/4	4 9/16	14 1/2
3 1/2	3 1/4	5 1/16	15
4	3 3/4	5 9/16	15 1/2
4 1/2	4 1/4	6 1/16	16
5	4 3/4	6 9/16	16 1/2
5 1/2	5 1/4	7 1/16	17
6	5 3/4	7 9/16	17 1/2
6 1/2	6 1/4	8 1/16	18
7	6 3/4	8 9/16	18 1/2
7 1/2	7 1/4	9 1/16	19
8	7 3/4	9 9/16	19 1/2
8 1/2	8 1/4	10 1/16	20
9	8 3/4	10 9/16	20 1/2
9 1/2	9 1/4	11 1/16	21
10	9 3/4	11 9/16	21 1/2
10 1/2	10 1/4	12 1/16	22
11	10 3/4	12 9/16	22 1/2
11 1/2	11 1/4	13 1/16	23
12	11 3/4	13 9/16	23 1/2

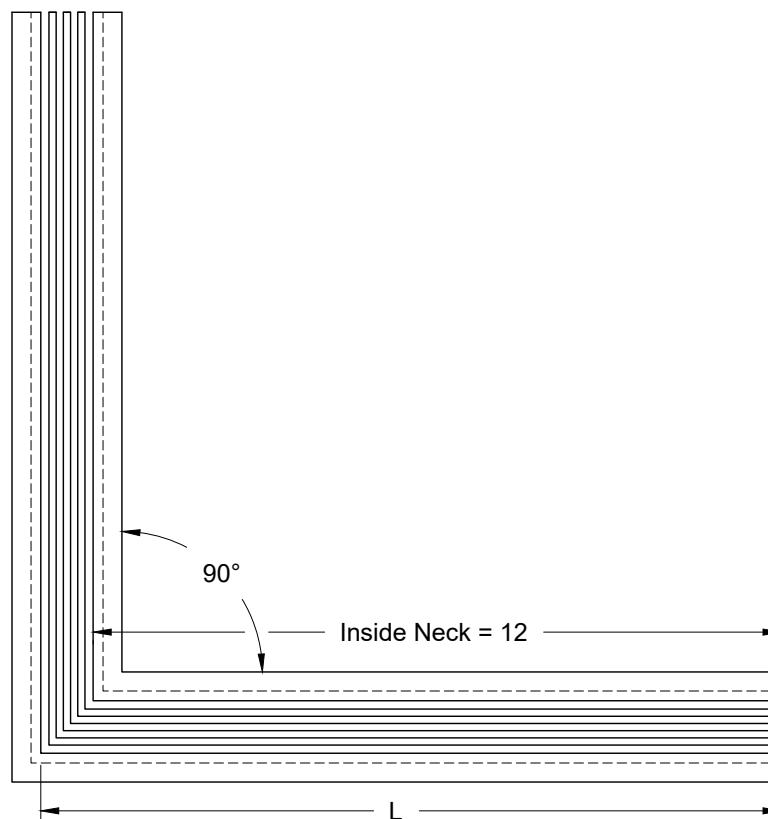


Mitered Face View

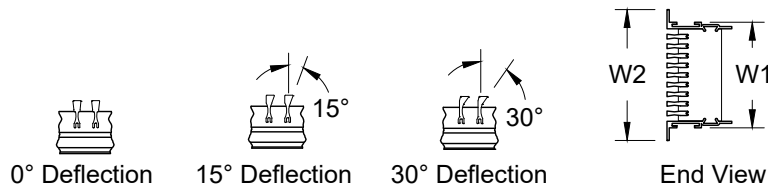


90° Vertical Inside		
Listed Width	Neck	Face
	W1	W2
1 1/2	1 1/4	3 1/16
2	1 3/4	3 9/16
2 1/2	2 1/4	4 1/16
3	2 3/4	4 9/16
3 1/2	3 1/4	5 1/16
4	3 3/4	5 9/16
4 1/2	4 1/4	6 1/16
5	4 3/4	6 9/16
5 1/2	5 1/4	7 1/16
6	5 3/4	7 9/16
6 1/2	6 1/4	8 1/16
7	6 3/4	8 9/16
7 1/2	7 1/4	9 1/16
8	7 3/4	9 9/16
8 1/2	8 1/4	10 1/16
9	8 3/4	10 9/16
9 1/2	9 1/4	11 1/16
10	9 3/4	11 9/16
10 1/2	10 1/4	12 1/16
11	10 3/4	12 9/16
11 1/2	11 1/4	13 1/16
12	11 3/4	13 9/16

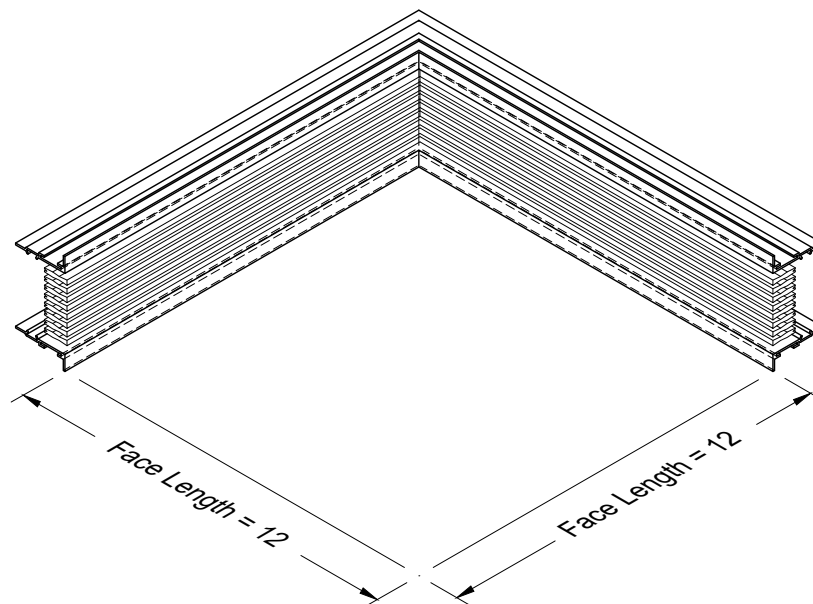


LBGMC-2-14B 90 Vertical Inside - Mitered Face View

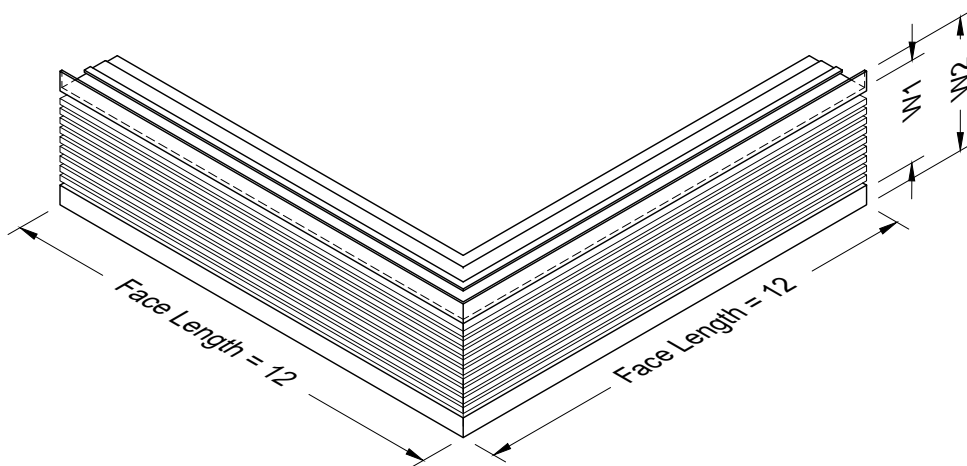

LBGMC-2-14B 90 Vertical Outside - Mitered Face View

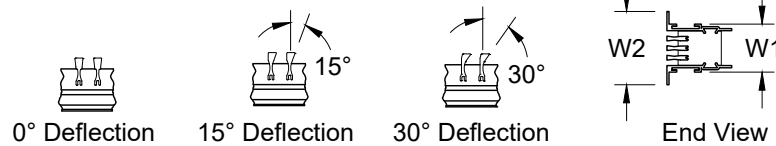

135 Degree			
Listed Width	Neck W1	Face W2	Face L
1 1/2	1 1/4	3 1/16	12 7/16
2	1 3/4	3 9/16	12 5/8
2 1/2	2 1/4	4 1/16	12 13/16
3	2 3/4	4 9/16	13 1/16
3 1/2	3 1/4	5 1/16	13 1/4
4	3 3/4	5 9/16	13 7/16
4 1/2	4 1/4	6 1/16	13 11/16
5	4 3/4	6 9/16	13 7/8
5 1/2	5 1/4	7 1/16	14 1/16
6	5 3/4	7 9/16	14 1/4
6 1/2	6 1/4	8 1/16	14 1/2
7	6 3/4	8 9/16	14 11/16
7 1/2	7 1/4	9 1/16	14 7/8
8	7 3/4	9 9/16	15 1/8
8 1/2	8 1/4	10 1/16	15 5/16
9	8 3/4	10 9/16	15 1/2
9 1/2	9 1/4	11 1/16	15 3/4
10	9 3/4	11 9/16	15 15/16
10 1/2	10 1/4	12 1/16	16 1/8
11	10 3/4	12 9/16	16 3/8
11 1/2	11 1/4	13 1/16	16 9/16
12	11 3/4	13 9/16	16 3/4

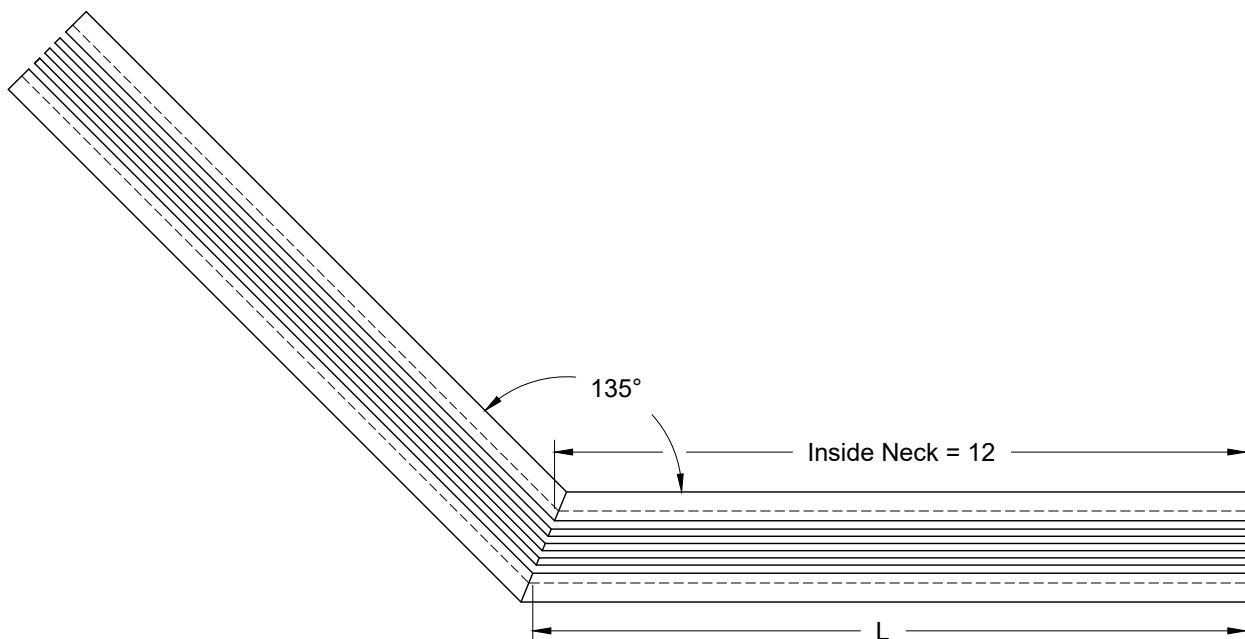

Mitered Face View