





Product Features:

- Available with 3/16" wide frames
- Available with 7/32" or 1/8" thick bars
- Pencil proof 17/64" bars available
- Available with 1/2" or 1/4" bar spacing
- Available for straight and curved applications
- Various frame types are available for different applications
 - H - Concealed Mounting Hanger
 - F - Floor Mounting
 - FP - Floor Mounting Pencil Proof
- Available in lengths up to 1200 in multiple sections
- Model LBG is available in widths from 1 1/2" to 24"
- Can come with hanger brackets for concealed mounting
- Available with sub-frames for specific applications
- Extruded aluminum construction


Finishes

CFD Throw Pattern Visualization

Optional Accessories:

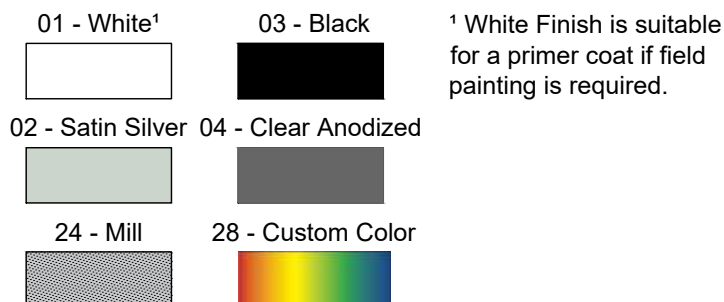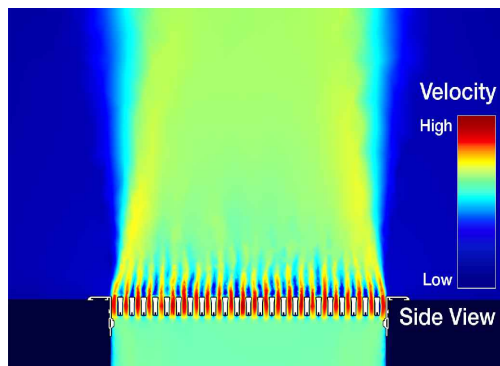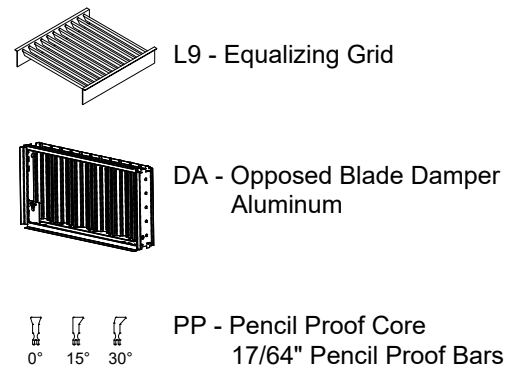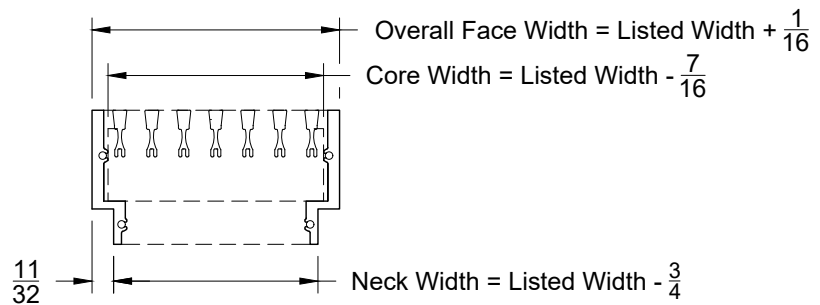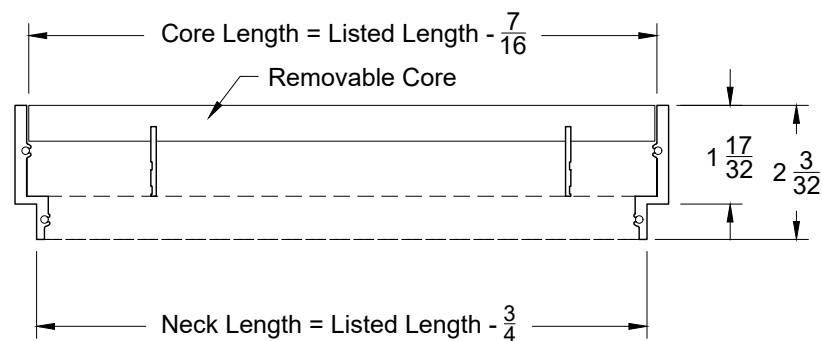


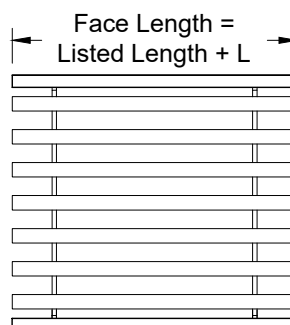
End View

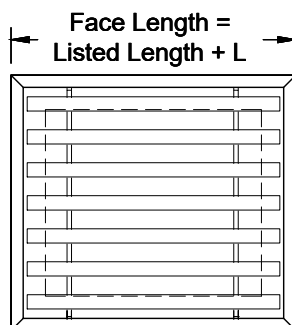


Side View




Mitered / Mitered	
Length	L = 1/16




Open / Open	
Length	L = 1/16

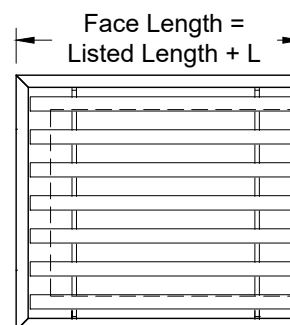


Mitered / Open	
Length	L = 1/16

 


0° Deflection

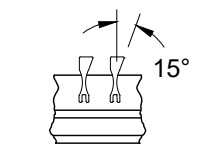


15° Deflection

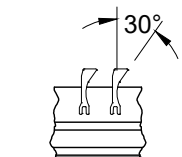


30° Deflection

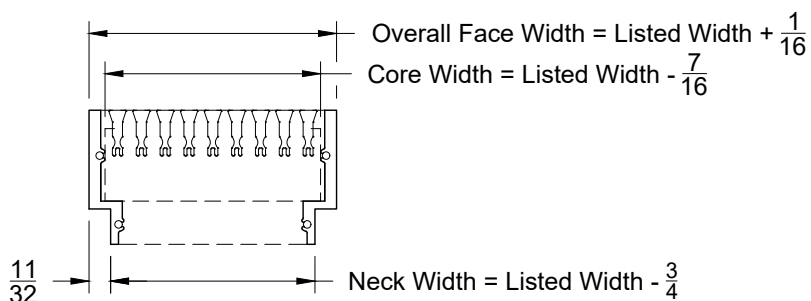


End View

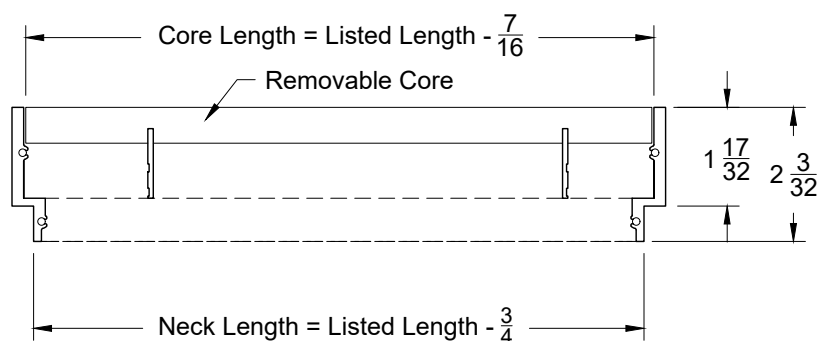


Side View

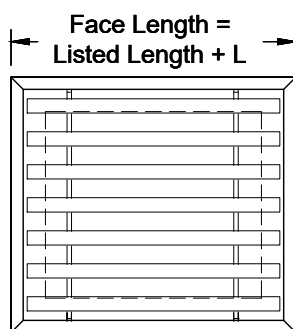


Mitered / Mitered	
Length	L = 1/16

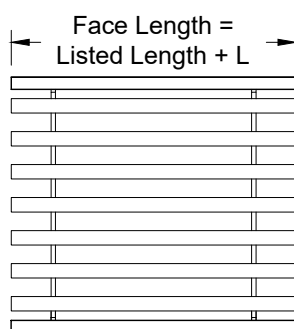


Open / Open	
Length	L = 1/16

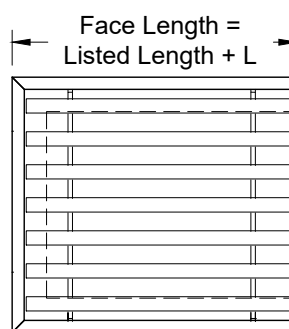


Mitered / Open	
Length	L = 1/16




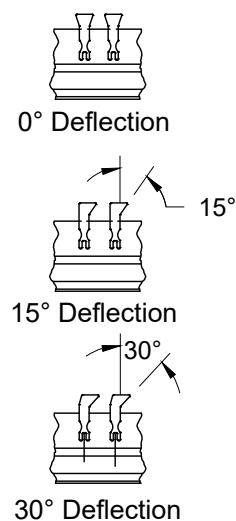


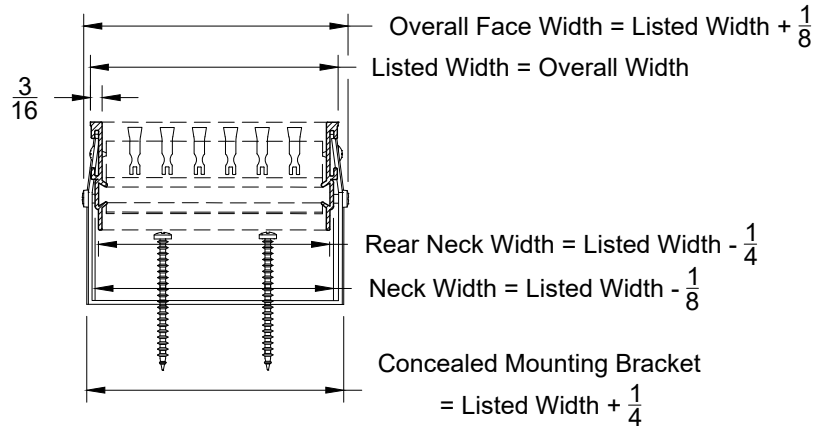


End View

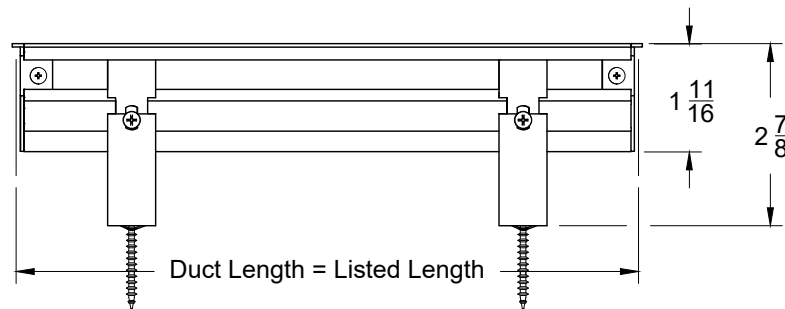


Side View

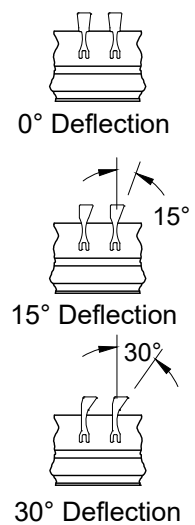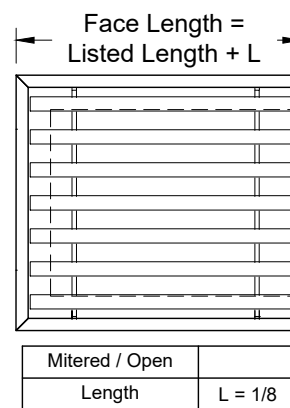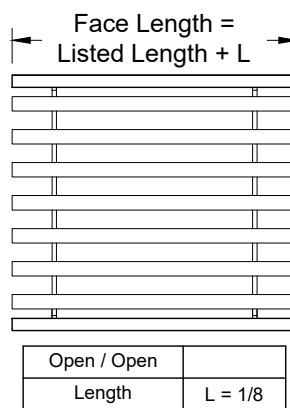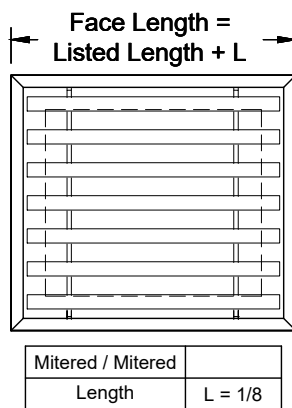


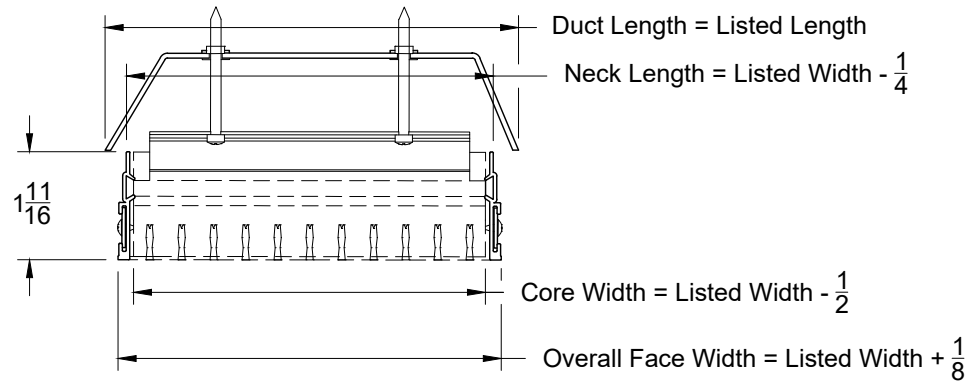


End View

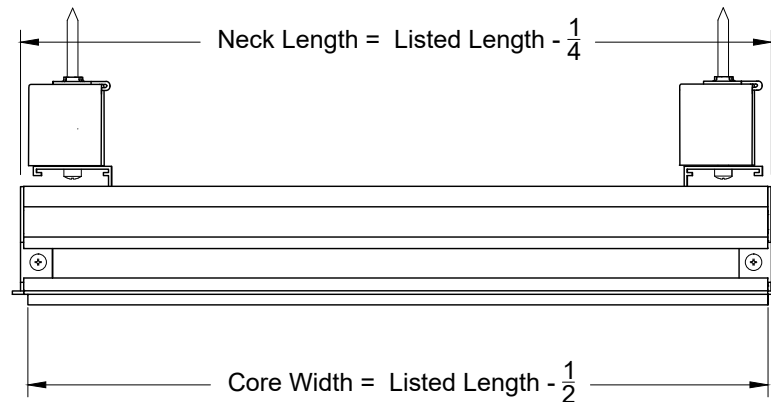


Side View

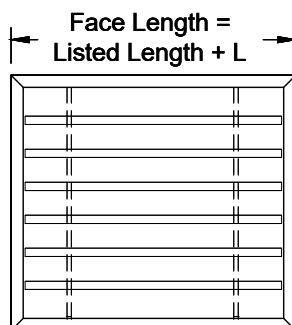


Mitered / Mitered	
Length	L = 1/8

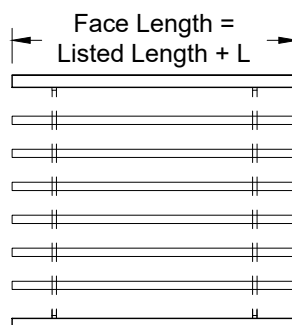


Open / Open	
Length	L = 0

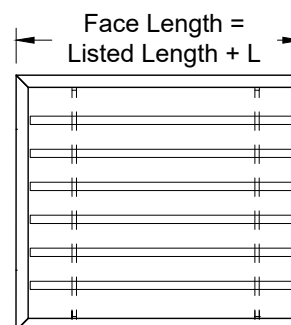


Mitered / Open	
Length	L = 1/16

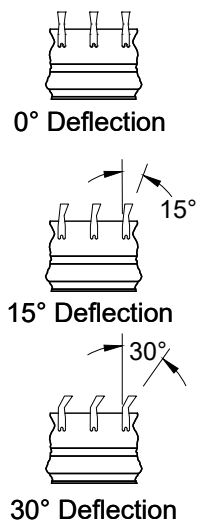

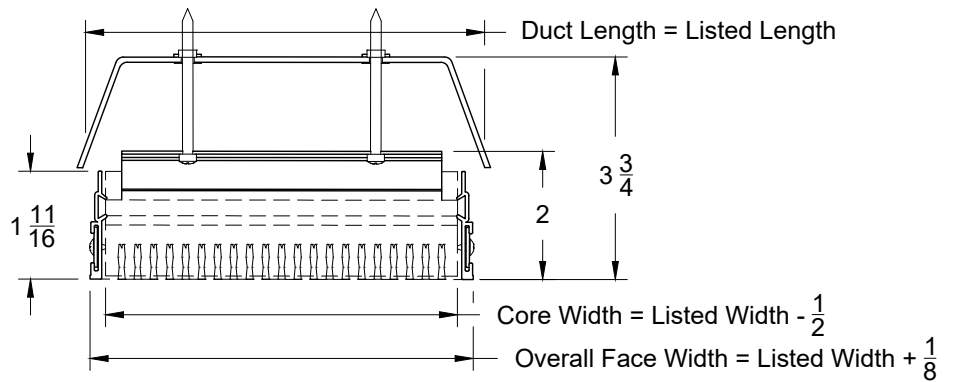

End View

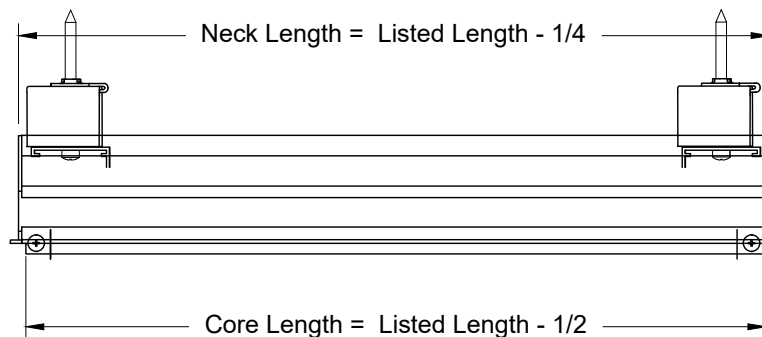

Side View

