

LBG Series Linear Bar Grille Selection Guide

Mounting Options


Model	Available Mounting Options										
	None	Floor Mounting (F)	Floor Mounting - Pencil Proof (FP)	Core Only (CO)	Core Only Pencil Proof (PCO)	Concealed Mounting - Hanger Brackets (H)	Spline Subframe (HP)	Combo Subframe (HC)	Narrow / Wall Subframe (HW)	Tape and Spackle (TS)	Available Mitered Corner Sections (MC)
LBG-3-12A		X	X			X					
LBG-3-12B						X					
LBG-3-14B						X					
LBG-2-12A	X					X	X	X	X		
LBG-2-14B	X					X	X	X	X		
LBG-2-12B	X					X	X	X	X		
LBG-1-12A	X	X	X			X	X			X	
LBG-1-14B	X	X				X	X			X	
LBG-1-12B	X					X	X			X	
LBGCO-12A				X	X						
LBGCO-14B				X	X						
LBGCO-12B				X	X						

Construction


Model	Bar Width		Bar Spacing on Centers		Border Width		
	7/32"	1/8"	1/4"	1/2"	3/16"	1/2"	1"
LBG-3-12A	X			X	X		
LBG-3-12B		X		X	X		
LBG-3-14B		X	X		X		
LBG-2-12A	X			X		X	
LBG-2-14B		X	X			X	
LBG-2-12B		X		X		X	
LBG-1-12A	X			X			X
LBG-1-14B		X	X				X
LBG-1-12B		X		X			X
LBGCO-12A	X			X			
LBGCO-14B		X	X				
LBGCO-12B		X		X			

Mounting Options – Dimensional Drawings


Note: Not all mounting options below are available on every LBG series product. Please see the “Mounting Options” table in the previous section for all available mounting options per product family.

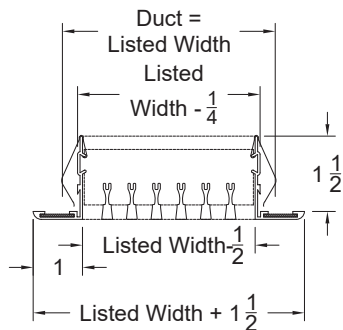


Flush Surface Mount
Non-Removable Core (LBG-1-12A model shown)

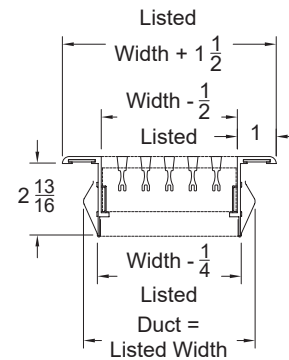


Floor, Wall or Sill Mounting –
Removable Core (LBG-1-12A-F model shown)

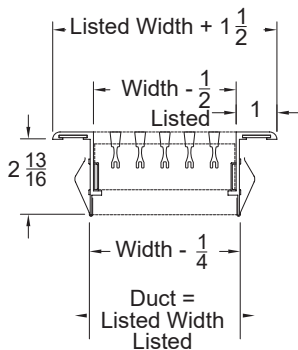


Pencil Proof Floor, Wall or Sill Mounting
(LBG-1-12A-FP model shown)

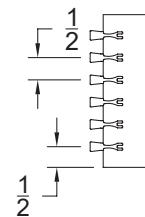


Core Only
(LBGCO-1-12A model shown)

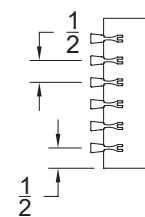


Pencil Proof Core Only
(LBGCO-1-12A-PP model shown)

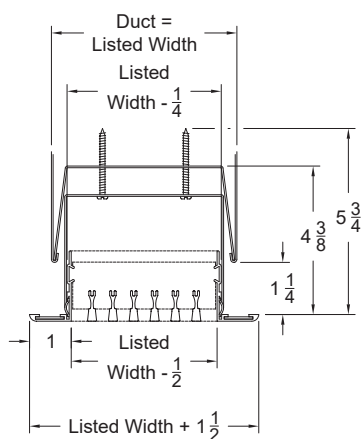


Concealed Mounting Hanger Brackets
(LBG-1-12A-H model shown)

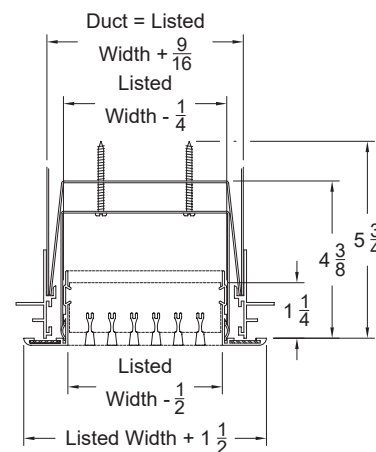


Spline Subframe for Plaster Wall and Ceiling
(LBG-1-12A-HP model shown)

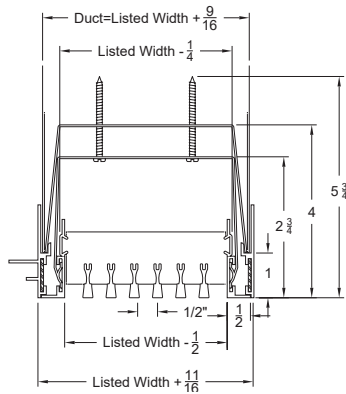

Combination Narrow Wall / Spline Mounting
(LBG-2-12A-HC model shown)

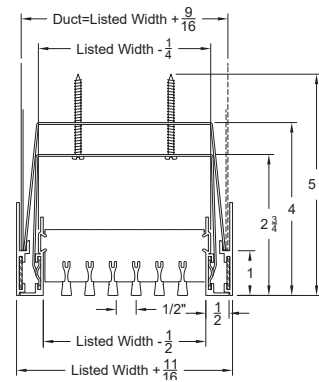


Narrow / Wall Subframe Mounting
(LBG-2-12A-HW model shown)

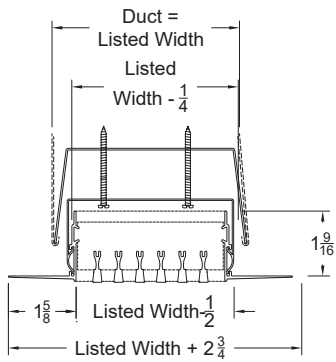


Tape and Spackle Mounting
(LBG-1-14B-TS model shown)

Deflection Options

0° Deflection

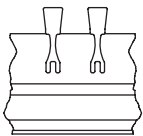

15° Deflection

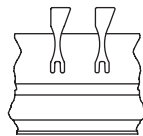

30° Deflection

