 

Product Features:

- Model SDPF-C offers a curved frame style that fits a specific duct diameter
- Available in steel or aluminum construction
- Units can come with air scoop for airflow adjustment
- Features a perforated face panel to optimize airflow
- Includes foam gasket to provide a tight fit onto round duct work

Finishes
01 - White¹

03 - Black



¹ White Finish is suitable for a primer coat if field painting is required.

02 - Satin Silver



 
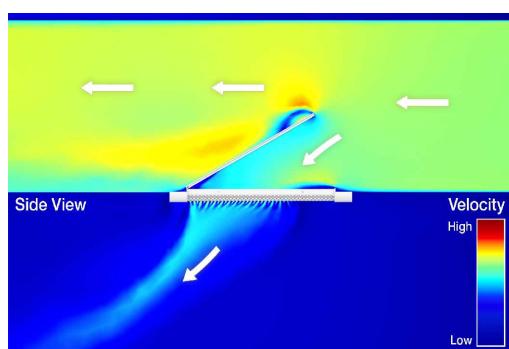
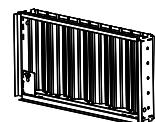
04 - Clear Anodized



28 - Custom Color



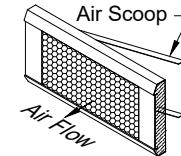
24 - Mill


CFD Throw Pattern Visualization

Optional Accessories:


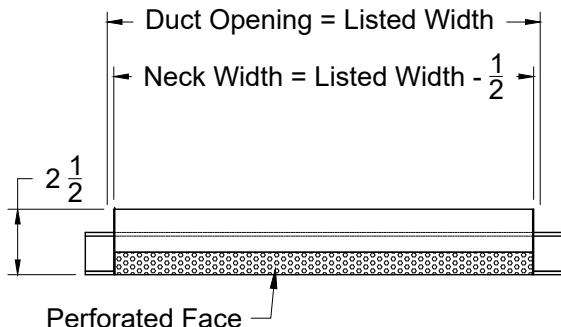
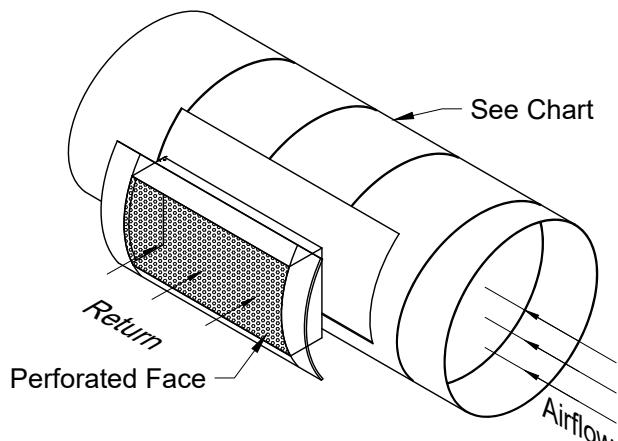
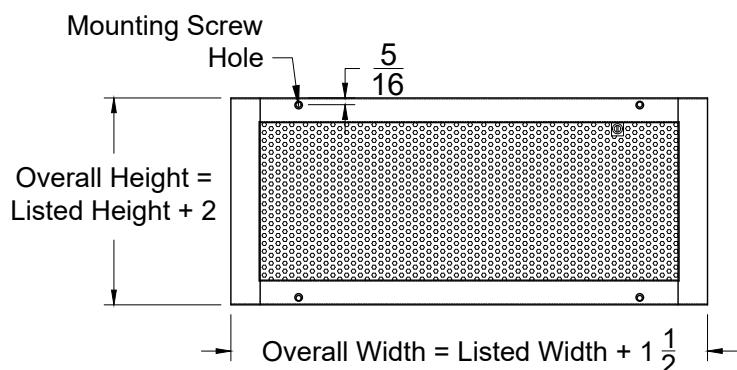
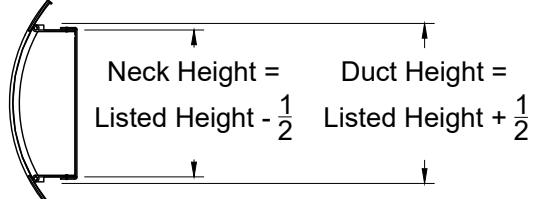
OBDE - Extruded Aluminum Opposed Blade Damper



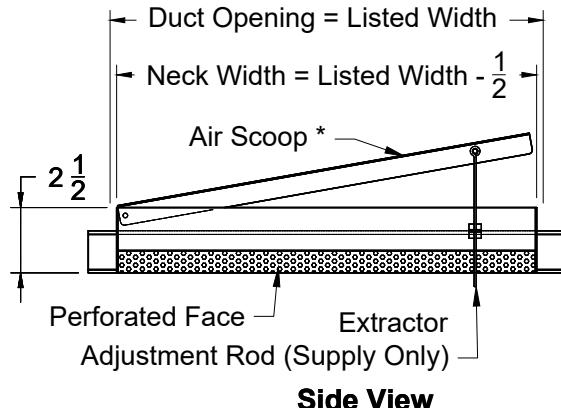
OBDA - Aluminum Opposed Blade Damper



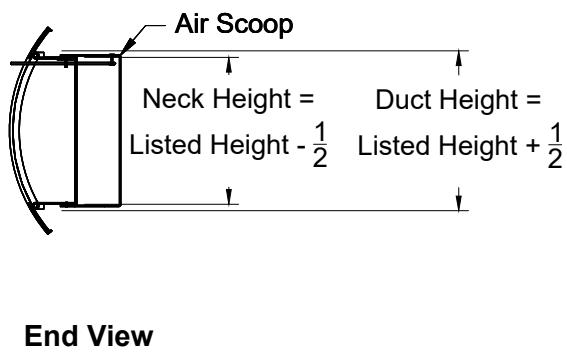
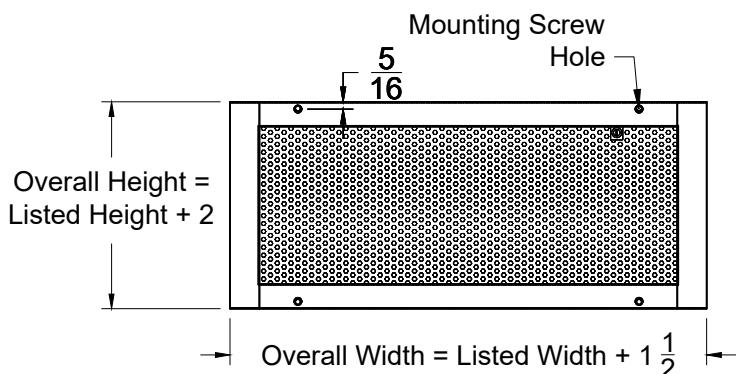
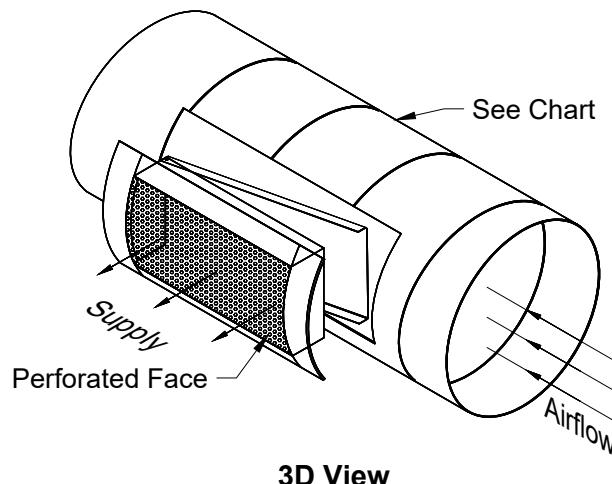
AS - Air Scoop (Supply Only)


Side View

3D View

Face View

End View

Curved Flange Table		
Listed Height	Duct Diameter Range (inches)	
	Minimum	Maximum
3	6	16
4	8	36
6	10	36
8	10	36
10	14	36
12	16	36

SDPF-C-AL - Industrial Spiral Duct Grille
Aluminum, Perforated Face, Curved Flange - Supply


* Air Scoop is Standard construction on Supply Only



Curved Flange Table		
Listed Height	Duct Diameter Range (inches)	
	Minimum	Maximum
3	6	16
4	8	36
6	10	36
8	10	36
10	14	36
12	16	36