



### Product Features:

- Model SDPF-U offers a universal frame style that fits a range of duct diameters
- Features a perforated face panel to optimize airflow
- Available in steel or aluminum construction
- Includes foam gasket to provide a tight fit onto round duct work
- Units can come with air scoop for airflow adjustment

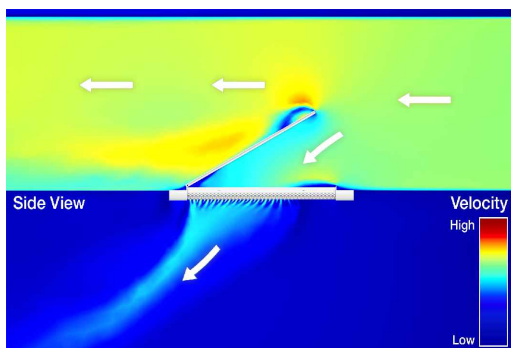
### Finishes



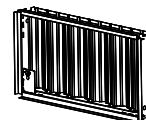
<sup>1</sup> White Finish is suitable for a primer coat if field painting is required.

\* Mill Finish only available for aluminum construction

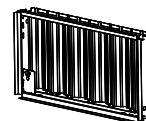
### CFD Throw Pattern Visualization



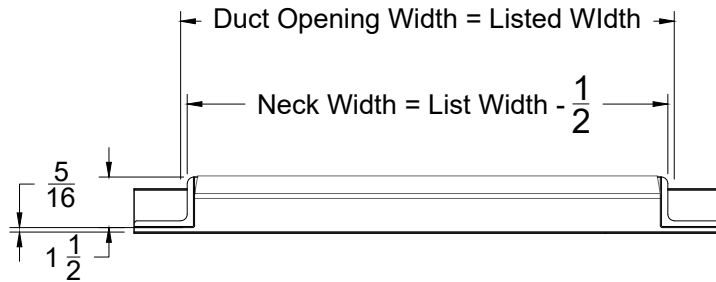
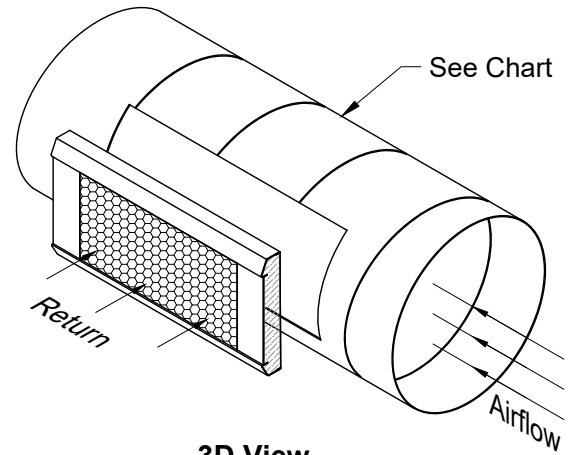
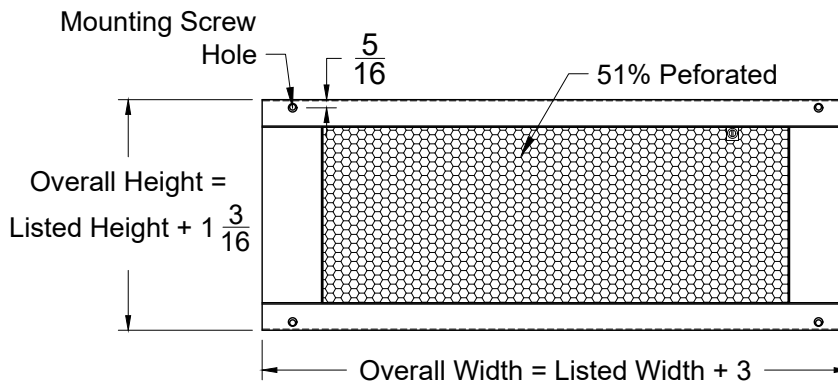
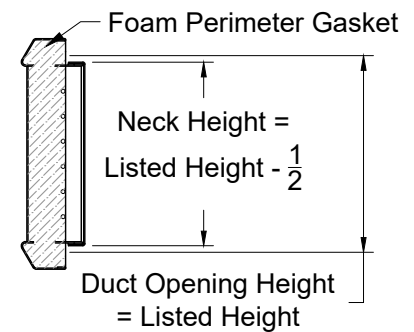
### Optional Accessories:



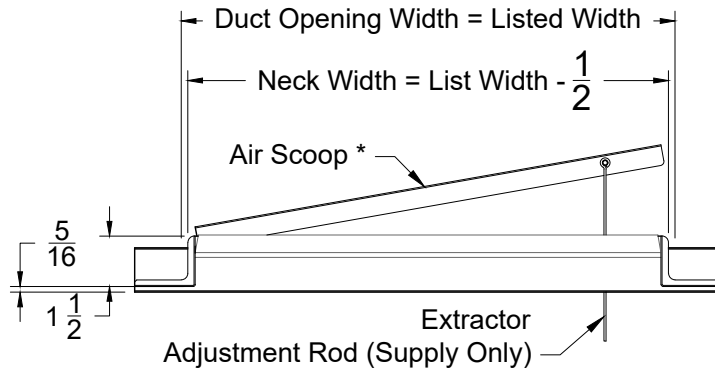
OBDE - Extruded Aluminum Opposed Blade Damper



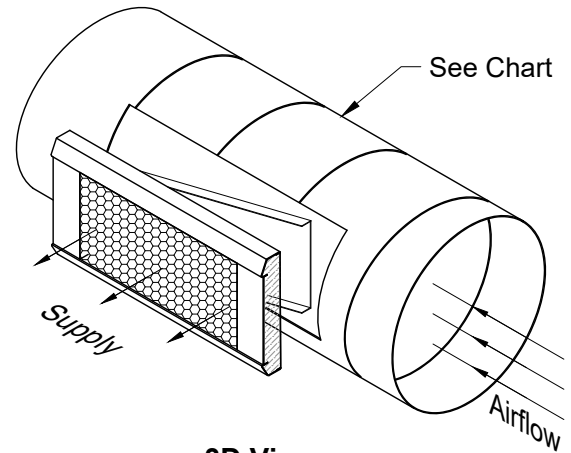
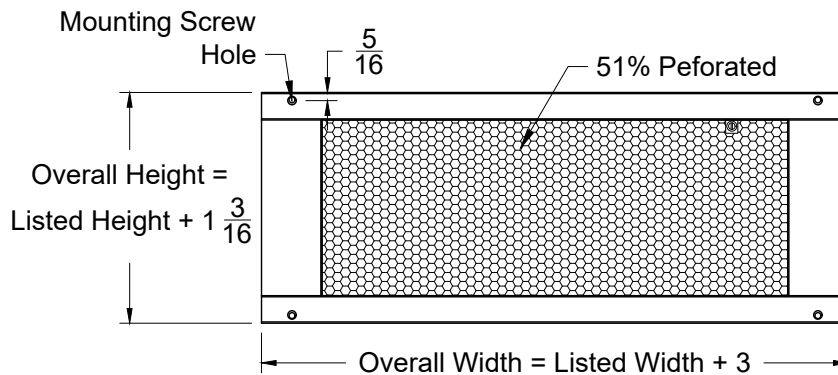
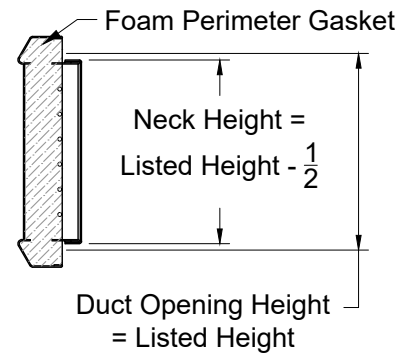
OBDA - Aluminum Opposed Blade Damper


**Side View**

**3D View**

**Face View**

**End View**

Universal Spiral Table		
Listed Height	Duct Diameter Range (inches)	
	Minimum	Maximum
3	6	24
4	8	24
6	12	24
8	20	36
10	30	48
12	42	48


**Side View**

\* Air Scoop is Standard construction on Supply Only


**3D View**

**Face View**

**End View**

Universal Spiral Table		
Listed Height	Duct Diameter Range (inches)	
	Minimum	Maximum
3	6	24
4	8	24
6	12	24
8	20	36
10	30	48
12	42	48