


MAT: 17793596 30AGO24

S/N



GFC-00118OT3E56Z-S
W01 TO0IC0X0X

PH 3 HP (kW)1.0(075)
Hz 60 V208-230/460
RPM1755 A3.44-3.35/1.67
FR56YZ DESA
IP21 ENCL ODP
AMB 40 °C CODE M
SF 1.0-1.15 INS F
SFA PF 0.72
DUTY CONT
NEMA NOM. EFF. 84.0%

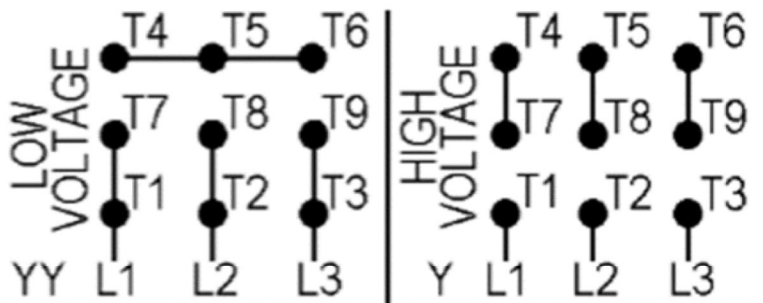

T1-BLU T2-WHT T3-ORG T4-YEL T5-BLK
T6-GRY T7-PNK T8-RED T9-BRK RED

ALT. RATING: 190-220/380-415V 50Hz
1.0 HP 4.04-3.49/1.89-1.99 A 1460RPM S.F.1.0

Inverter Duty Motor
For 60Hz use on VPWM 1000:1VT; 5:1CT